

REBAR GROUNDING CLAMP, PARALLEL

CATALOG NUMBER

EK16



FEATURES

Universal use for rebar, rods or pipes

Lay-in feature cuts installation time

Bronze alloy construction with Stainless Steel 304 screws

Approved for direct burial in earth and concrete

PRODUCT ATTRIBUTES

Material: Bronze;Stainless Steel 304 (EN 1.4301)

Connection Type: Parallel

Conductor Size: #10 Solid - #2 Solid;5.5 mm² Stranded - 25 mm² Stranded


Ground Rod Diameter, Actual: 0.500" – 1.000"

Water Pipe Size: 1/2" – 1"

Rebar Size, US: #4 – #8

Rebar Size, Canada: 10M – 25M

DIAGRAMS

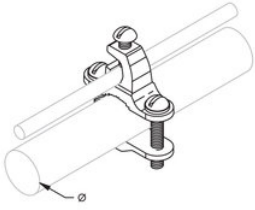

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2022 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.