



Quality Products. Service Excellence.


Inner Panels *EP Series*

Eclipse Series Enclosures



Features

- Larger than standard NEMA panel used in same sized enclosure.
- 12gauge steel construction.
- Larger sizes have 2 or 4 formed flanges for added strength.
- Slotted corner design for easier mounting.
- Finished in white or unpainted galvanized.

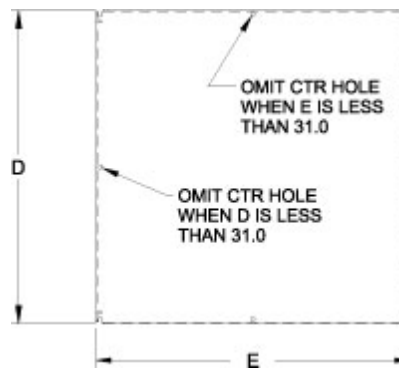

| Mild Steel | | Galvanized | | Size | | Gauge |
|------------|----------|------------|-------|------|--|-------|
| Part No. | Part No. | D | E | | | |
| EP1210 | EPG1210 | 10.20 | 8.20 | | | 12 |
| EP1212 | EPG1212 | 10.20 | 10.20 | | | 12 |
| EP1224 | EPG1224 | 10.20 | 22.20 | | | 12 |
| EP1612 | EPG1612 | 14.20 | 10.20 | | | 12 |
| EP1616 | EPG1616 | 14.20 | 14.20 | | | 12 |
| EP1620 | EPG1620 | 14.20 | 18.20 | | | 12 |
| EP2012 | EPG2012 | 18.20 | 10.20 | | | 12 |
| EP2016 | EPG2016 | 18.20 | 14.20 | | | 12 |
| EP2020 | EPG2020 | 18.20 | 18.20 | | | 12 |
| EP2024 | EPG2024 | 18.20 | 22.20 | | | 12 |
| EP2412 | EPG2412 | 22.20 | 10.20 | | | 12 |
| EP2416 | EPG2416 | 22.20 | 14.20 | | | 12 |
| EP2420 | EPG2420 | 22.20 | 18.20 | | | 12 |
| EP2424 | EPG2424 | 22.20 | 22.20 | | | 12 |
| EP2430 | EPG2430 | 22.20 | 28.20 | | | 12 |
| EP2442 | EPG2442 | 22.20 | 40.20 | | | 12 |
| EP2448 | EPG2448 | 22.20 | 46.20 | | | 12 |
| EP3012 | EPG3012 | 28.20 | 10.20 | | | 12 |
| EP3016 | EPG3016 | 28.20 | 14.20 | | | 12 |
| EP3020 | EPG3020 | 28.20 | 18.20 | | | 12 |
| EP3024 | EPG3024 | 28.20 | 22.20 | | | 12 |

| Mild Steel | | Galvanized | | Size | | Gauge |
|------------|----------|------------|-------|------|--|-------|
| Part No. | Part No. | D | E | | | |
| EP3030 | EPG3030 | 28.20 | 28.20 | | | 12 |

| Part No. | Mild Steel Galvanized Part No. | Size | | Gauge |
|----------|--------------------------------|-------|-------|-------|
| | | D | E | |
| EP3036 | EPG3036 | 28.20 | 34.20 | 12 |
| EP3042 | EPG3042 | 28.20 | 40.20 | 12 |
| EP3048 | EPG3048 | 28.20 | 46.20 | 12 |
| EP3060 | EPG3060 | 28.20 | 58.20 | 12 |
| EP3624 | EPG3624 | 34.20 | 22.20 | 12 |
| EP3630 | EPG3630 | 34.20 | 28.20 | 12 |
| EP3636 | EPG3636 | 34.20 | 34.20 | 12 |
| EP3642 | EPG3642 | 34.20 | 40.20 | 12 |
| EP3648 | EPG3648 | 34.20 | 46.20 | 12 |
| EP3660 | EPG3660 | 34.20 | 58.20 | 12 |
| EP4224 | EPG4224 | 40.20 | 22.20 | 12 |
| EP4230 | EPG4230 | 40.20 | 28.20 | 12 |
| EP4236 | EPG4236 | 40.20 | 34.20 | 12 |
| EP4824 | EPG4824 | 46.20 | 22.20 | 12 |
| EP4830 | EPG4830 | 46.20 | 28.20 | 12 |
| EP4836 | EPG4836 | 46.20 | 34.20 | 12 |
| EP4848 | EPG4848 | 46.20 | 46.20 | 12 |
| EP6036 | EPG6036 | 58.20 | 34.20 | 12 |
| EP7230 | EPG7230 | 70.20 | 28.20 | 12 |
| EP7236 | EPG7236 | 70.20 | 34.20 | 12 |

Tags: inner panel, galvanized, steel, Eclipse, EN4SD, EP

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.



Quality Products. Service Excellence.


Inner Panels *EP Series*

Eclipse Series Enclosures



Features

- Larger than standard NEMA panel used in same sized enclosure.
- 12gauge steel construction.
- Larger sizes have 2 or 4 formed flanges for added strength.
- Slotted corner design for easier mounting.
- Finished in white or unpainted galvanized.

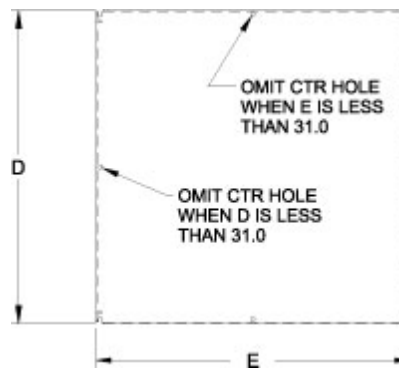

| Mild Steel | | Galvanized | | Size | | Gauge |
|------------|----------|------------|-------|-------|-------|-------|
| Part No. | Part No. | D | E | D | E | |
| EP1210 | EPG1210 | 10.20 | 8.20 | 10.20 | 8.20 | 12 |
| EP1212 | EPG1212 | 10.20 | 10.20 | 10.20 | 10.20 | 12 |
| EP1224 | EPG1224 | 10.20 | 22.20 | 10.20 | 22.20 | 12 |
| EP1612 | EPG1612 | 14.20 | 10.20 | 14.20 | 10.20 | 12 |
| EP1616 | EPG1616 | 14.20 | 14.20 | 14.20 | 14.20 | 12 |
| EP1620 | EPG1620 | 14.20 | 18.20 | 14.20 | 18.20 | 12 |
| EP2012 | EPG2012 | 18.20 | 10.20 | 18.20 | 10.20 | 12 |
| EP2016 | EPG2016 | 18.20 | 14.20 | 18.20 | 14.20 | 12 |
| EP2020 | EPG2020 | 18.20 | 18.20 | 18.20 | 18.20 | 12 |
| EP2024 | EPG2024 | 18.20 | 22.20 | 18.20 | 22.20 | 12 |
| EP2412 | EPG2412 | 22.20 | 10.20 | 22.20 | 10.20 | 12 |
| EP2416 | EPG2416 | 22.20 | 14.20 | 22.20 | 14.20 | 12 |
| EP2420 | EPG2420 | 22.20 | 18.20 | 22.20 | 18.20 | 12 |
| EP2424 | EPG2424 | 22.20 | 22.20 | 22.20 | 22.20 | 12 |
| EP2430 | EPG2430 | 22.20 | 28.20 | 22.20 | 28.20 | 12 |
| EP2442 | EPG2442 | 22.20 | 40.20 | 22.20 | 40.20 | 12 |
| EP2448 | EPG2448 | 22.20 | 46.20 | 22.20 | 46.20 | 12 |
| EP3012 | EPG3012 | 28.20 | 10.20 | 28.20 | 10.20 | 12 |
| EP3016 | EPG3016 | 28.20 | 14.20 | 28.20 | 14.20 | 12 |
| EP3020 | EPG3020 | 28.20 | 18.20 | 28.20 | 18.20 | 12 |
| EP3024 | EPG3024 | 28.20 | 22.20 | 28.20 | 22.20 | 12 |

| Mild Steel | | Galvanized | | Size | | Gauge |
|------------|----------|------------|-------|-------|-------|-------|
| Part No. | Part No. | D | E | D | E | |
| EP3030 | EPG3030 | 28.20 | 28.20 | 28.20 | 28.20 | 12 |

| Part No. | Mild Steel Galvanized Part No. | Size | | |
|----------|--------------------------------|-------|-------|-------|
| | | D | E | Gauge |
| EP3036 | EPG3036 | 28.20 | 34.20 | 12 |
| EP3042 | EPG3042 | 28.20 | 40.20 | 12 |
| EP3048 | EPG3048 | 28.20 | 46.20 | 12 |
| EP3060 | EPG3060 | 28.20 | 58.20 | 12 |
| EP3624 | EPG3624 | 34.20 | 22.20 | 12 |
| EP3630 | EPG3630 | 34.20 | 28.20 | 12 |
| EP3636 | EPG3636 | 34.20 | 34.20 | 12 |
| EP3642 | EPG3642 | 34.20 | 40.20 | 12 |
| EP3648 | EPG3648 | 34.20 | 46.20 | 12 |
| EP3660 | EPG3660 | 34.20 | 58.20 | 12 |
| EP4224 | EPG4224 | 40.20 | 22.20 | 12 |
| EP4230 | EPG4230 | 40.20 | 28.20 | 12 |
| EP4236 | EPG4236 | 40.20 | 34.20 | 12 |
| EP4824 | EPG4824 | 46.20 | 22.20 | 12 |
| EP4830 | EPG4830 | 46.20 | 28.20 | 12 |
| EP4836 | EPG4836 | 46.20 | 34.20 | 12 |
| EP4848 | EPG4848 | 46.20 | 46.20 | 12 |
| EP6036 | EPG6036 | 58.20 | 34.20 | 12 |
| EP7230 | EPG7230 | 70.20 | 28.20 | 12 |
| EP7236 | EPG7236 | 70.20 | 34.20 | 12 |

Tags: inner panel, galvanized, steel, Eclipse, EN4SD, EP

Data subject to change without notice

© 2025. Hammond Manufacturing Ltd. All rights reserved.