

DESCRIPTION:

The ET400RATSB is a Non-IC, AIR-TITE™ remodel housing designed for use with small aperture trims. The shallow height allows it to be used in spaces where vertical height is limited. The ET400RATSB is installed from below the ceiling. For use in non-insulated ceilings. If ceiling insulation is present, it must be kept 3" from the fixtures on all sides.

| | | |
|-------------|--|------|
| Catalog # | | Type |
| Project | | |
| Comments | | Date |
| Prepared by | | |

SPECIFICATION FEATURES

Housing

Die-formed CRS with powder coat finish.

Remodel Clips

Four remodel clips secure housing and accommodate 1/2" and 5/8" ceiling thickness.

Junction Box

- Seven conduit knockouts are uniform 1/2" size with true pryout slots.
- Four pryouts with integral strain relief simplify "NM" non-metallic sheathed cable installation.
- Three quick connect wire connectors included.

Socket

Adjustable position porcelain socket with nickel plated brass screw shell provides flexibility in lamp positioning.

Thermal Protector

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.

Labels

- UL/cUL Listed 1598 Luminaire
- UL/cUL Listed for Damp Location
- UL/cUL Listed for Feed Through
- UL/cUL Listed for Wet Location, covered ceiling
- Certified Under ASTM-E283 for air tight construction





ET400RATSB

4" Non-Insulated Ceiling AIR-TITE™ Remodel Housing with Adjustable Socket Bracket

4" TRIMS

FOR USE IN EXISTING CEILINGS

FOR USE IN NON-INSULATED CEILINGS OR INSULATED CEILINGS BUT INSULATION MUST BE KEPT 3" FROM ALL SIDES OF FIXTURE

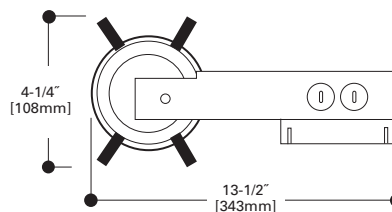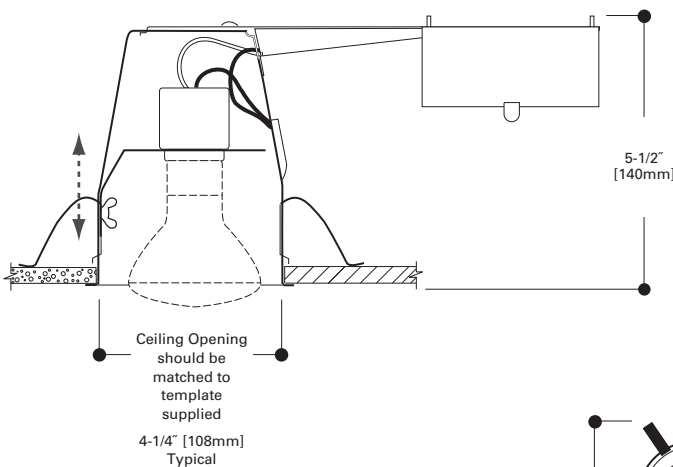

ADJUSTABLE SOCKET

TRIMS

ORDERING INFORMATION

SAMPLE NUMBER: ET400RATSB-ERT403

Order housing, and trim separately.

Housing



ET400RATSB=4" Non-Insulated
Ceiling AIR-TITE™
Small Aperture
Remodel Housing
with Adjustable
Socket Bracket

Trims



ERT403

Reflector Cone**50W PAR20, 50W R20, 40W A19, 40W R16**

ERT403=Specular Clear Reflector, Gloss White Trim Ring

OD: 4 3/4" (120mm)




ERT401

Step Baffle**50W PAR20, 50W R20, 40W R16**

ERT401=Black Plastic Baffle, Gloss White Trim Ring

ERT401WHT=White Plastic Baffle with Gloss White Trim Ring

 OD: 4 3/4" (120mm)



ERT410

Metal Baffle**50W PAR20, 50W R20, 40W R16**

ERT410=Black Metal Baffle, Gloss White Trim Ring

ERT410WHT=Gloss White Metal Baffle, Gloss White Trim Ring

OD: 5" (127mm)



ERT402

Eyeball**40W R16, 60W PAR16**

ERT402=Gloss White Eyeball

OD: 4 3/4" (120mm)



ERT455

Prismatic Glass Lens Shower Light**50W PAR20, 50W R20, 40W A19**

ERT455=Shower Light, Gloss White Trim Ring,

Prismatic Flat Glass Lens

OD: 4 3/4" (120mm)

