



GE
Lighting

66346 - F28T8/XL/SPX65/ECO

F28 T8 6500K Product Line Extension



GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight Linear
Bulb	T8
Base	Medium Bi-Pin (G13)
Rated Life (NOM)	45000.0 h
Rated Life (instant start) @ Time	24000 h @ 3 h
Rated Life (rapid start) @ Time	34000 h @ 12 h
	45000.0 @ 3.0/50000.0 @ 12.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	2.95 mg
Picograms of Mercury (NOM)	26.86703 pg
Primary Application	Energy Saving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	2600.0
Mean Lumens (NOM)	2440.0
Nominal Initial Lumens per Watt (NOM)	92.85714
Color Temperature (NOM)	6500.0 K
Color Rendering Index (CRI) (NOM)	80.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	28.0
---------------	------

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	48.000 in(1219.2 mm)
Nominal Length (NOM)	48.000 in(1219.2 mm)
Bulb Diameter (DIA) (NOM)	1.000 in(25.4 mm)

PRODUCT INFORMATION


Product Code	66346
Description	F28T8/XL/SPX65/ECO
Standard Package	Case
Standard Package GTIN	10043168663462
Standard Package Quantity	36
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	36
UPC	043168663465



GE
Lighting

66346 - F28T8/XL/SPX65/ECO

F28 T8 6500K Product Line Extension

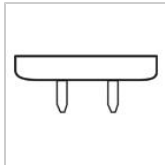

GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight Linear
Bulb	T8
Base	Medium Bi-Pin (G13)
Rated Life (NOM)	45000.0 h
Rated Life (instant start) @ Time	24000 h @ 3 h
Rated Life (rapid start) @ Time	34000 h @ 12 h
	45000.0 @ 3.0/50000.0 @ 12.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	2.95 mg
Picograms of Mercury (NOM)	26.86703 pg
Primary Application	Energy Saving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	2600.0
Mean Lumens (NOM)	2440.0
Nominal Initial Lumens per Watt (NOM)	92.85714
Color Temperature (NOM)	6500.0 K
Color Rendering Index (CRI) (NOM)	80.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	28.0
---------------	------

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	48.000 in(1219.2 mm)
Nominal Length (NOM)	48.000 in(1219.2 mm)
Bulb Diameter (DIA) (NOM)	1.000 in(25.4 mm)

PRODUCT INFORMATION

Product Code	66346
Description	F28T8/XL/SPX65/ECO
Standard Package	Case
Standard Package GTIN	10043168663462
Standard Package Quantity	36
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	36
UPC	043168663465