




GE
Lighting

66474 - F34/CX41/WM/ECO

F34/CX41/WM/ECO-T8-SPP NEW TECHNICAL LAMPS

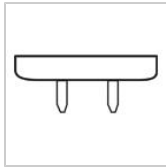

GENERAL CHARACTERISTICS

| | |
|----------------------------|--------------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T12 |
| Base | Medium Bi-Pin (G13) |
| Rated Life | 20000.0 hrs |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 15.0 °C |
| LEED-EB MR Credit | 114 picograms Hg per mean lumen hour |
| Primary Application | Energy Saving |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|----------|
| Initial Lumens | 2500.0 |
| Mean Lumens | 2200.0 |
| Nominal Initial Lumens per Watt | 73 |
| Color Temperature | 4100.0 K |
| Color Rendering Index (CRI) | 87.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|------|
| Wattage | 34.0 |
|---------|------|

DIMENSIONS

| | |
|------------------------------|-----------------------|
| Maximum Overall Length (MOL) | 48.0000 in(1219.2 mm) |
| Nominal Length | 48.000 in(1219.2 mm) |
| Bulb Diameter (DIA) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION


| | |
|----------------------------------|-----------------|
| Product Code | 66474 |
| Description | F34/CX41/WM/ECO |
| Standard Package | Case |
| Standard Package GTIN | 10043168664742 |
| Standard Package Quantity | 30 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 30 |
| UPC | 043168664745 |



GE
Lighting

66474 - F34/CX41/WM/ECO

F34/CX41/WM/ECO-T8-SPP NEW TECHNICAL LAMPS

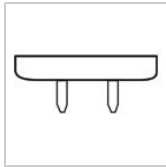

GENERAL CHARACTERISTICS

| | |
|----------------------------|--------------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T12 |
| Base | Medium Bi-Pin (G13) |
| Rated Life | 20000.0 hrs |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 15.0 °C |
| LEED-EB MR Credit | 114 picograms Hg per mean lumen hour |
| Primary Application | Energy Saving |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|----------|
| Initial Lumens | 2500.0 |
| Mean Lumens | 2200.0 |
| Nominal Initial Lumens per Watt | 73 |
| Color Temperature | 4100.0 K |
| Color Rendering Index (CRI) | 87.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------|------|
| Wattage | 34.0 |
|---------|------|

DIMENSIONS

| | |
|------------------------------|-----------------------|
| Maximum Overall Length (MOL) | 48.0000 in(1219.2 mm) |
| Nominal Length | 48.000 in(1219.2 mm) |
| Bulb Diameter (DIA) | 1.500 in(38.1 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|-----------------|
| Product Code | 66474 |
| Description | F34/CX41/WM/ECO |
| Standard Package | Case |
| Standard Package GTIN | 10043168664742 |
| Standard Package Quantity | 30 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 30 |
| UPC | 043168664745 |