

DROP IN™ Floor Box Kits

NEW!
more on
reverse

FIVE MINUTE installation with SINGLE Hole Saw • Low Profile Covers



**REDUCES
INSTALLATION
From 30 MINUTES
to 5 MINUTES!**

DROP IN Box
brass cover
FLB4360MB

NEW

Arlington's LISTED **DROP IN™** Floor Box Kits are the fastest way to install a BOX nearly flush in an EXISTING floor.

Designed for flush, neat installations and TIME-SAVINGS these floor boxes install with a SINGLE hole saw and sit just 1/8" off the floor!

DROPIN box accommodates most 3.5" standard covers, but Arlington's round **low profile** covers seat flush into the non-metallic ring, reducing trip hazards.

- BRASS OR NICKEL-PLATED BRASS Metal Covers have two gasketed flip lids that keep water out and protect the box.



nickel-plated cover FLB4360NL



Fastest box installation!



1 Determine box location, taking care to avoid structural framing members. Using hole saw cut 4-1/4" diameter opening through floor and subfloor.



2 Insert mounting bracket. Using indicator marks align bracket for proper receptacle orientation. Tighten (3) wing screws to secure bracket to floor.

Non-metallic Blank Covers



All kits come with matching Non-Metallic Carpet Ring

DROPIN kits are also available with **NON-METALLIC Blank Covers**. They're perfect for covering unused receptacles. To use the receptacle simply remove the blank cover.

- Five decorator colors: dark brown, light almond, gray, caramel, black – each with a matching non-metallic mounting bracket, gasket and carpet ring.



3 Pull cable. Install in box with supplied cable connector. Attach box to bracket with (3) #8 x 1/2" sheet metal screws (supplied) through the U-shaped cut outs in the box flange.



4 Wire receptacle. Install in box. Attach supplied gasket support plate to receptacle with #6 x 1/2" screw.



Cover Installation
Install gasket. Attach metal or non-metallic blank cover to box with (3) #8 x 1/2" flathead machine screws. *When using the in-use non-metallic cover, substitute the colored in-use plate for the black gasket support plate.*



Arlington



Patent pending

Arlington

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

DROP IN™ Floor Box Kits



Metal or Non-metallic Covers • FASTEST Installation in Existing Floor



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION FINISH, COVER STYLE	UNIT PKG	STD PKG
----------------	---------------------------	---------------------------------	----------	---------

DROP IN™ BOX KITS with METAL COVERS

FLB4360MB	00760	Round non-metallic box, Brass cover w flip lids	1	1
FLB4360NL	00761	Round non-metallic box, Nickel-plated Brass cover w flip lids	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

FLB4360MB and FLB4360NL DROP IN BOX Kits include non-metallic box, round 4" diameter metal cover with two flip lids, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



FLB4360MB

FLB4360NL

FLB4360NL
nickel-plated
brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	COLOR STYLE / COLOR	UNIT PKG	STD PKG
----------------	---------------------------	-------------	---------------------	----------	---------

DROP IN™ BOX KITS with NON-METALLIC BLANK COVERS

FLB4360BR	00763	Round non-metallic box	Blank, Dark Brown	1	1
FLB4360LA	00766	Round non-metallic box	Blank, Light Almond	1	1
FLB4360GY	00765	Round non-metallic box	Blank, Gray	1	1
FLB4360CA	00764	Round non-metallic box	Blank, Caramel	1	1
FLB4360BL	00762	Round non-metallic box	Blank, Black	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)


DROP IN BOX Kits with BLANK NON-METALLIC COVERS include non-metallic box, round 4" diameter non-metallic cover blank, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



COVERS, CARPET RINGS, GASKETS
IN 5 COLORS



1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

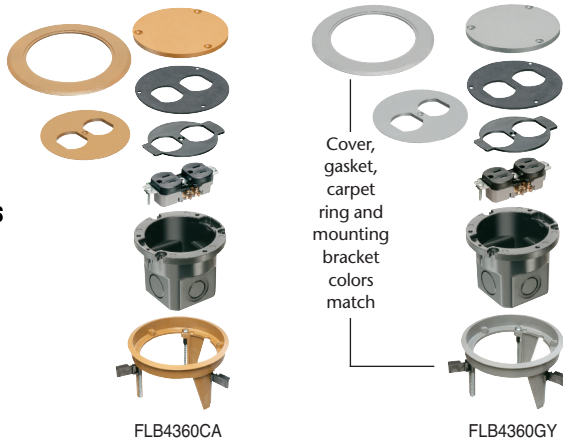

FLB4360CA

FLB4360GY



FLB4360GY
Installed

Distributed by

DROP IN™ Floor Box Kits

NEW!
more on
reverse

FIVE MINUTE installation with SINGLE Hole Saw • Low Profile Covers



**REDUCES
INSTALLATION
From 30 MINUTES
to 5 MINUTES!**

DROP IN Box
brass cover
FLB4360MB

NEW

Arlington's LISTED **DROP IN™** Floor Box Kits are the fastest way to install a BOX nearly flush in an EXISTING floor.

Designed for flush, neat installations and TIME-SAVINGS these floor boxes install with a SINGLE hole saw and sit just 1/8" off the floor!

DROP IN box accommodates most 3.5" standard covers, but Arlington's round **low profile** covers seat flush into the non-metallic ring, reducing trip hazards.

- BRASS OR NICKEL-PLATED BRASS Metal Covers have two gasketed flip lids that keep water out and protect the box.



nickel-plated cover FLB4360NL



Fastest box installation!



1 Determine box location, taking care to avoid structural framing members. Using hole saw cut 4-1/4" diameter opening through floor and subfloor.



2 Insert mounting bracket. Using indicator marks align bracket for proper receptacle orientation. Tighten (3) wing screws to secure bracket to floor.

Non-metallic Blank Covers



All kits come with matching Non-Metallic Carpet Ring

DROP IN kits are also available with **NON-METALLIC Blank Covers**. They're perfect for covering unused receptacles. To use the receptacle simply remove the blank cover.

- Five decorator colors: dark brown, light almond, gray, caramel, black – each with a matching non-metallic mounting bracket, gasket and carpet ring.



3 Pull cable. Install in box with supplied cable connector. Attach box to bracket with (3) #8 x 1/2" sheet metal screws (supplied) through the U-shaped cut outs in the box flange.



4 Wire receptacle. Install in box. Attach supplied gasket support plate to receptacle with #6 x 1/2" screw.



Cover Installation
Install gasket. Attach metal or non-metallic blank cover to box with (3) #8 x 1/2" flathead machine screws. *When using the in-use non-metallic cover, substitute the colored in-use plate for the black gasket support plate.*



Patent pending

Arlington

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

DROP IN™ Floor Box Kits



Metal or Non-metallic Covers • FASTEST Installation in Existing Floor



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION FINISH, COVER STYLE	UNIT PKG	STD PKG
----------------	---------------------------	---------------------------------	----------	---------

DROP IN™ BOX KITS with METAL COVERS

FLB4360MB	00760	Round non-metallic box, Brass cover w flip lids	1	1
FLB4360NL	00761	Round non-metallic box, Nickel-plated Brass cover w flip lids	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

FLB4360MB and FLB4360NL DROP IN BOX Kits include non-metallic box, round 4" diameter metal cover with two flip lids, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



FLB4360MB

FLB4360NL

FLB4360MB
brass cover

FLB4360NL
nickel-plated
brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	COLOR STYLE / COLOR	UNIT PKG	STD PKG
----------------	---------------------------	-------------	---------------------	----------	---------

DROP IN™ BOX KITS with NON-METALLIC BLANK COVERS


FLB4360BR	00763	Round non-metallic box	Blank, Dark Brown	1	1
FLB4360LA	00766	Round non-metallic box	Blank, Light Almond	1	1
FLB4360GY	00765	Round non-metallic box	Blank, Gray	1	1
FLB4360CA	00764	Round non-metallic box	Blank, Caramel	1	1
FLB4360BL	00762	Round non-metallic box	Blank, Black	1	1

ADD SUFFIX 'GC' to order with Ground Clip (Canada)

DROP IN BOX Kits with BLANK NON-METALLIC COVERS include non-metallic box, round 4" diameter non-metallic cover blank, non-metallic gasket support plate, gasket, carpet ring, UL Listed 15 amp TR duplex receptacle, mounting bracket, NM94 and NM95 cable connectors, (3) #8 x 1/2" flathead screws and (1) #6 x 1/2" screw.



COVERS, CARPET RINGS, GASKETS
IN 5 COLORS

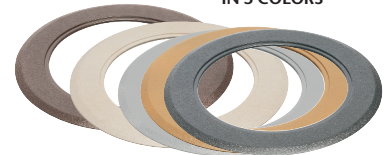

FLB4360CA



FLB4360GY

Cover, gasket, carpet ring and mounting bracket colors match



FLB4360GY
Installed

Distributed by



Arlington

1 Stauffer Industrial Park
Scranton, PA 18517

800/233.4717

Fax 570/562.0646

www.aifittings.com

Patent pending FLB4360 0716 REV0916/15M