



GE
Lighting


25186 - FLE20HT3/2/841

GE Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

a product of
ecomagination



High Color Rendering
cUL Listed
Energy Savings
UL Listed

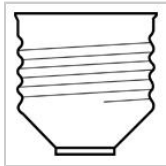

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

Warning

- Risk of Electric Shock
 - Do not open - no user serviceable parts inside.
 - Do not use where directly exposed to water.

GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	75.0 W
Rated Life	8000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	188 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1200.0
Mean Lumens	1000.0
Nominal Initial Lumens per Watt	60
Color Temperature	4100.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	20.0
Input Voltage	120.0 V
Input Current	0.3000 A

DIMENSIONS

Maximum Overall Length (MOL)	4.7000 in(119.4 mm)
Nominal Length	4.700 in(119.4 mm)

PRODUCT INFORMATION

Product Code	25186
Description	FLE20HT3/2/841
Standard Package	Case
Standard Package GTIN	10043168251867
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168251860



GE
Lighting


25186 - FLE20HT3/2/841

GE Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

a product of
ecomagination



High Color Rendering
cUL Listed
Energy Savings
UL Listed

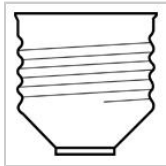

GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	75.0 W
Rated Life	8000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	188 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1200.0
Mean Lumens	1000.0
Nominal Initial Lumens per Watt	60
Color Temperature	4100.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	20.0
Input Voltage	120.0 V
Input Current	0.3000 A

DIMENSIONS

Maximum Overall Length (MOL)	4.7000 in(119.4 mm)
Nominal Length	4.700 in(119.4 mm)

PRODUCT INFORMATION

Product Code	25186
Description	FLE20HT3/2/841
Standard Package	Case
Standard Package GTIN	10043168251867
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168251860

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

Warning

- Risk of Electric Shock
 - Do not open - no user serviceable parts inside.
 - Do not use where directly exposed to water.