
 


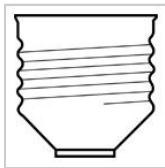

GE
Lighting

80889 - FLE23HT3/2/XL827

GE Soft White Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant



GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	90.0 W
Rated Life	12000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	182 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1600.0
Mean Lumens	1280.0
Nominal Initial Lumens per Watt	69
Color Temperature	2700.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	23.0
Input Voltage	120.0 V

DIMENSIONS

Maximum Overall Length (MOL)	5.1000 in(129.5 mm)
Nominal Length	5.100 in(129.5 mm)

PRODUCT INFORMATION

Product Code	80889
Description	FLE23HT3/2/XL827
Standard Package	Case
Standard Package GTIN	10043168808894
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168808897

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

Warning


 
- Risk of Electric Shock
 - Do not open - no user serviceable parts inside.
 - Do not use where directly exposed to water.



GE
Lighting

80889 - FLE23HT3/2/XL827

GE Soft White Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

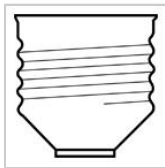

GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	90.0 W
Rated Life	12000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	182 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1600.0
Mean Lumens	1280.0
Nominal Initial Lumens per Watt	69
Color Temperature	2700.0 K
Color Rendering Index (CRI)	82.0

ELECTRICAL CHARACTERISTICS

Wattage	23.0
Input Voltage	120.0 V

DIMENSIONS

Maximum Overall Length (MOL)	5.1000 in(129.5 mm)
Nominal Length	5.100 in(129.5 mm)

PRODUCT INFORMATION

Product Code	80889
Description	FLE23HT3/2/XL827
Standard Package	Case
Standard Package GTIN	10043168808894
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168808897

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Remove and install by grasping only plastic portion of the lamp.

Warning

- Risk of Electric Shock
 - Do not open - no user serviceable parts inside.
 - Do not use where directly exposed to water.