


# LED Catalog

Lamps & Fixtures • 2017

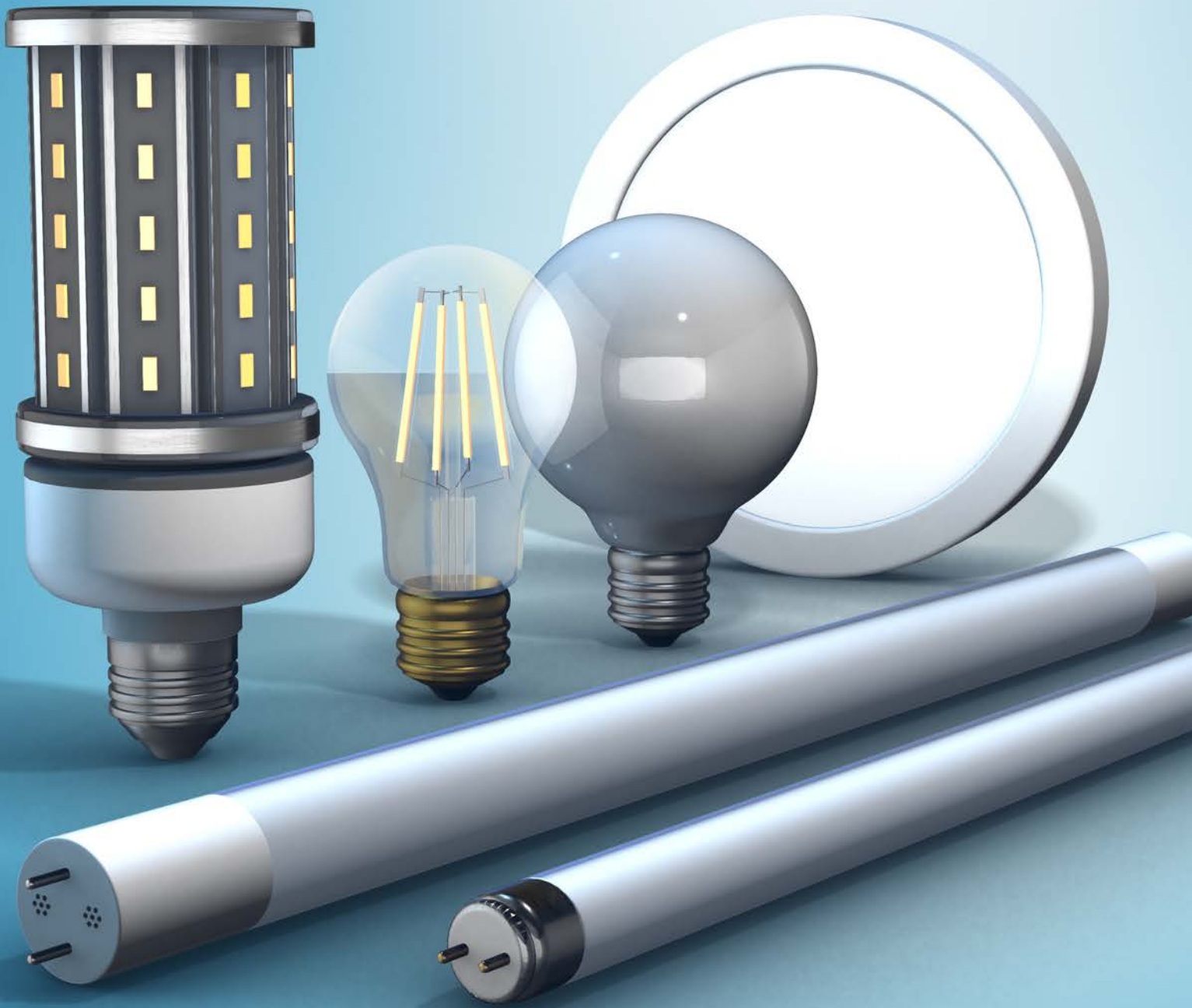

**EIKO**   
CERTIFIED GREEN

**LITESPANLED** 

selection. solutions. simplicity. [eiko.com](http://eiko.com)

# Contents

<b>LED Replacement Lamps .....</b>	<b>2</b>
HID Replacement Lamps.....	2
PLL Replacement Lamps.....	5
Linear Tubes.....	6
Filament Dimmable Decorative Lamps .....	9
PL CFL Replacement Lamps.....	10
A19/A21 Replacement Lamps .....	12
Decorative Replacement Lamps .....	15
BR Replacement Lamps.....	16
PAR Replacement Lamps.....	18
Miniature Reflector Replacement Lamps .....	20
G4 & G9 Replacement Lamps .....	22
High Bay Fixtures .....	24
<b>LED Fixtures .....</b>	<b>24</b>
High Bay Fixtures .....	24
Linear Fixtures.....	26
Troffer & Panel Fixtures .....	27
Downlight Fixtures.....	28
Outdoor Fixtures.....	30
Wallpack Fixtures.....	32
Canopy Fixtures.....	34
<b>Miniature LED .....</b>	<b>36</b>
Miniature LED.....	36
<b>LitespanLED® Wire Rack Display Merchandiser .....</b>	<b>37</b>
<b>Ordering Information, Terms &amp; Conditions .....</b>	<b>38</b>



## HID Replacement Lamps

- LED HID replacement lamps for high wattage HID fixtures
- Consumes a fraction of the energy of HID systems
- Lasts many times longer than HID
- Available in a wide range of wattages and sizes
- Eliminates maintenance costs for over 10 years
- State-of-the-art LED light sources deliver ultra-high lpw
- Medium base and mogul base styles available
- Choice of color temperatures

### HID Replacement : Small : Medium Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	LDL
09632	LED15WPT30KMED-G7	1,875	15W	3000K	80+	100-277V	50K	E26	50W	1	
09390	LED15WPT40KMED-G7	1,875	15W	4000K	80+	100-277V	50K	E26	50W	1	✘
09391	LED15WPT50KMED-G7	1,950	15W	5000K	80+	100-277V	50K	E26	50W	1	✘
09633	LED19WPT30KMED-G7	2,375	19W	3000K	80+	100-277V	50K	E26	70W	1	
09392	LED19WPT40KMED-G7	2,375	19W	4000K	80+	100-277V	50K	E26	70W	1	✘
09393	LED19WPT50KMED-G7	2,470	19W	5000K	80+	100-277V	50K	E26	70W	1	✘
09634	LED24WPT30KMED-G7	3,000	24W	3000K	80+	100-277V	50K	E26	100W	1	
09394	LED24WPT40KMED-G7	3,000	24W	4000K	80+	100-277V	50K	E26	100W	1	✘
09395	LED24WPT50KMED-G7	3,120	24W	5000K	80+	100-277V	50K	E26	100W	1	✘

### HID Replacement : Medium : Medium Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	LDL
09635	LED27WPT30KMED-G7	3,510	27W	3000K	80+	100-277V	50K	E26	125W	2	
09374	LED27WPT40KMED-G7	3,510	27W	4000K	80+	100-277V	50K	E26	125W	2	✘
09376	LED27WPT50KMED-G7	3,645	27W	5000K	80+	100-277V	50K	E26	125W	2	
09637	LED36WPT30KMED-G7	4,860	36W	3000K	80+	100-277V	50K	E26	150W	2	
09378	LED36WPT40KMED-G7	4,860	36W	4000K	80+	100-277V	50K	E26	150W	2	✘
09380	LED36WPT50KMED-G7	4,860	36W	5000K	80+	100-277V	50K	E26	150W	2	
09639	LED45WPT30KMED-G7	5,850	45W	3000K	80+	100-277V	50K	E26	175W	2	
09382	LED45WPT40KMED-G7	5,850	45W	4000K	80+	100-277V	50K	E26	175W	2	✘

Continued on next page >>>



### HID Replacement : Medium : Medium Base (Continued)

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	LDL
09384	LED45WPT50KMED-G7	6,075	45W	5000K	80+	100-277V	50K	E26	175W	2	✘
09641	LED54WPT30KMED-G7	7,020	54W	3000K	80+	100-277V	50K	E26	200W	2	
09386	LED54WPT40KMED-G7	7,020	54W	4000K	80+	100-277V	50K	E26	250W	2	✘
09388	LED54WPT50KMED-G7	7,290	54W	5000K	80+	100-277V	50K	E26	250W	2	

### HID Replacement : Medium : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	DLC v4.1
09636	LED27WPT30KMOG-G7	3,510	27W	3000K	80+	100-277V	50K	EX39	125W	2	✓
09375	LED27WPT40KMOG-G7	3,510	27W	4000K	80+	100-277V	50K	EX39	125W	2	✓
09377	LED27WPT50KMOG-G7	3,645	27W	5000K	80+	100-277V	50K	EX39	125W	2	✓
09638	LED36WPT30KMOG-G7	4,860	36W	3000K	80+	100-277V	50K	EX39	150W	2	✓
09379	LED36WPT40KMOG-G7	4,860	36W	4000K	80+	100-277V	50K	EX39	150W	2	✓
09381	LED36WPT50KMOG-G7	4,860	36W	5000K	80+	100-277V	50K	EX39	150W	2	✓
09640	LED45WPT30KMOG-G7	5,850	45W	3000K	80+	100-277V	50K	EX39	175W	2	✓
09383	LED45WPT40KMOG-G7	5,850	45W	4000K	80+	100-277V	50K	EX39	175W	2	✓
09385	LED45WPT50KMOG-G7	6,075	45W	5000K	80+	100-277V	50K	EX39	175W	2	✓
09642	LED54WPT30KMOG-G7	7,020	54W	3000K	80+	100-277V	50K	EX39	200W	2	✓
09387	LED54WPT40KMOG-G7	7,020	54W	4000K	80+	100-277V	50K	EX39	200W	2	✓
09389	LED54WPT50KMOG-G7	7,290	54W	5000K	80+	100-277V	50K	EX39	200W	2	✓
09428	LED54WPT40KMOG-347V-G7*	6,480	54W	4000K	80+	120-347V	50K	EX39	175-250W	2	✓
09450	LED54WPT50KMOG-347V-G7*	6,750	54W	5000K	80+	120-347V	50K	EX39	175-250W	2	✓

### HID Replacement : Large : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	DLC v4.1
09346	LED80WPT40KMOG-G6	9,300	80W	4000K	80+	100-277V	50K	EX39	320W HID	3	✓
09347	LED80WPT50KMOG-G6	9,300	80W	5000K	80+	100-277V	50K	EX39	320W HID	3	✓
09661	LED100WPT30KMOG-G6	11,900	100W	3000K	80+	100-277V	50K	EX39	400W HID	3	✓
09348	LED100WPT40KMOG-G6	11,900	100W	4000K	80+	100-277V	50K	EX39	400W HID	3	✓
09153	LED100WPT50KMOG-G6	11,900	100W	5000K	80+	100-277V	50K	EX39	400W HID	3	✓
09451	LED100WPT40KMOG-347V-G7*	11,900	100W	4000K	80+	120-347V	50K	EX39	250-400W	3	
09452	LED100WPT50KMOG-347V-G7*	11,900	100W	5000K	80+	120-347V	50K	EX39	250-400W	3	
09349	LED120WPT40KMOG-G6	14,300	120W	4000K	80+	100-277V	50K	EX39	600W HID	3	✓
09154	LED120WPT50KMOG-G6	14,300	120W	5000K	80+	100-277V	50K	EX39	600W HID	3	✓

### HID Replacement : Horizontal : Medium Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Bm	Replaces HID	Photo #
09652	LED20WPT/180/30KMED-G7	2,700	20W	3000K	80+	100-277V	50K	E26	180°	100W	4
09653	LED20WPT/180/40KMED-G7	2,700	20W	4000K	80+	100-277V	50K	E26	180°	100W	4
09654	LED20WPT/180/50KMED-G7	2,800	20W	5000K	80+	100-277V	50K	E26	180°	100W	4
09655	LED30WPT/180/30KMED-G7	4,050	30W	3000K	80+	100-277V	50K	E26	180°	175W	4
09656	LED30WPT/180/40KMED-G7	4,050	30W	4000K	80+	100-277V	50K	E26	180°	175W	4
09657	LED30WPT/180/50KMED-G7	4,200	30W	5000K	80+	100-277V	50K	E26	180°	175W	4
09658	LED40WPT/180/30KMED-G7	5,400	40W	3000K	80+	100-277V	50K	E26	180°	250W	4

Continued on next page >>>





HID Replacement : Horizontal : Medium Base (Continued)

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Bm	Replaces HID	Photo #
09659	LED40WPT/180/40KMED-G7	5,400	40W	4000K	80+	100-277V	50K	E26	180°	250W	4
09660	LED40WPT/180/50KMED-G7	5,600	40W	5000K	80+	100-277V	50K	E26	180°	250W	4

HID Replacement : Horizontal : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Bm	Replaces HID	Photo #	DLC v4.1
09402	LED20WPT/180/40KMOG-G7	2,700	20W	4000K	80+	100-277V	50K	E39	180°	100W	4	✓
09403	LED20WPT/180/50KMOG-G7	2,800	20W	5000K	80+	100-277V	50K	E39	180°	100W	4	✓
09404	LED30WPT/180/40KMOG-G7	4,050	30W	4000K	80+	100-277V	50K	E39	180°	175W	4	✓
09405	LED30WPT/180/50KMOG-G7	4,200	30W	5000K	80+	100-277V	50K	E39	180°	175W	4	✓
09406	LED40WPT/180/40KMOG-G7	5,400	40W	4000K	80+	100-277V	50K	E39	180°	250W	4	✓
09407	LED40WPT/180/50KMOG-G7	5,600	40W	5000K	80+	100-277V	50K	E39	180°	250W	4	✓

HID Replacement : Omnidirectional : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #
08773	LED36WPT40KMOG-G5†	4,000	36W	4000K	80+	100-277V	50K	E39	100-150W/HID	5
09030	LED100WPT40KMOG-G5†	12,500	100W	4000K	80+	100-277V	50K	E39	250-400W/HID	5

HID Replacement : Area Light : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	DLC v4.1
09643	LED80WAL30KMOG-G7	10,400	80W	3000K	80+	120-277V	50K	EX39	400W	7	✓
09644	LED80WAL40KMOG-G7	10,400	80W	4000K	80+	120-277V	50K	EX39	400W	7	✓
09645	LED80WAL50KMOG-G7	10,400	80W	5000K	80+	120-277V	50K	EX39	400W	7	✓
09646	LED110WAL30KMOG-G7	14,300	110W	3000K	80+	120-277V	50K	EX39	600W	7	✓
09647	LED110WAL40KMOG-G7	14,300	110W	4000K	80+	120-277V	50K	EX39	600W	7	✓
09648	LED110WAL50KMOG-G7	14,300	110W	5000K	80+	120-277V	50K	EX39	600W	7	✓

HID Replacement : Temporary Work Light : Hook Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Replaces HID	Photo #	DLC v4.1
09649	TMP-3C-50K-U	6,900	60W	5000K	80+	100-277V	50K	250W	8	✓
09650	TMP-4C-50K-U	9,200	80W	5000K	80+	100-277V	50K	320W	8	✓
09651	TMP-5C-50K-U	11,500	100W	5000K	80+	100-277V	50K	400W	8	✓

HID Replacement : Highbay / Lowbay : Mogul Base

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Base	Replaces HID	Photo #	DLC v4.1
09698	LED115WB40KMOG-G7	12,000	115W	4000K	80+	120-277V	50K	EX39	250W	9	✓
09699	LED115WB50KMOG-G7	12,000	115W	5000K	80+	120-277V	50K	EX39	400W	9	✓




PLL Replacement Lamps

- Solid state replacement for 2' 40W PLL compact fluorescent lamps with 2G11 base
- Frosted lens for uniform diffuse appearance
- Ultra-high performance LEDs deliver 100 lpw
- Lifetime exceeds 50,000 hrs
- Up to 50% instant energy savings
- Choice of 3000K, 3500K, 4000K, and 5000K CCT
- Instant-on with no warm up like fluorescents

PLL Replacement : Direct Fit : Electronic Ballast Compatible : 2G11

Order Code	Item	Length	Lm	W	CCT	CRI	V	Bm	Life/Hrs L70	Base	Photo #
60461	LED23W/PLL/830-G7DR	22"	2,600	23W	3000K	80+	120-277V, 347V	120°	50K	2G11	1
60462	LED23W/PLL/835-G7DR	22"	2,600	23W	3500K	80+	120-277V, 347V	120°	50K	2G11	1
60463	LED23W/PLL/840-G7DR	22"	2,800	23W	4000K	80+	120-277V, 347V	120°	50K	2G11	1
60464	LED23W/PLL/850-G7DR	22"	2,800	23W	5000K	80+	120-277V, 347V	120°	50K	2G11	1

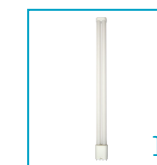



## Linear Tubes

- Solid state replacement for T5, T8 and T12 linear fluorescent
- Available in line voltage/ballast bypass, direct fit, and hybrid dual mode for a range of installation options
- Ultra-high performance LEDs deliver exceptional lpw
- Available in shatterproof nano-polycarbonate and PET-coated versions
- Choice of 3500K, 4000K or 5000K CCT
- Instant-on with no warm up like fluorescents

Visit [eiko.com](http://eiko.com) to view complete ballast compatibility information.

### T8 LED Dual Mode : Ballast Bypass/Electronic Instant Start Ballast Compatible

Order Code	Item	Length	Lm	Nominal Lamp W	System W w/ Ballast	V (Ballast Dependent)	CCT	CRI	Glass Tube	Bm	Life/Hrs	Photo #
09291	LED15WT8F/48/840K-G7DM	4'	1,800	15W	175W	120-277V	4000K	80+	Frosted	220°	50K	1
09292	LED15WT8F/48/850K-G7DM	4'	1,800	15W	175W	120-277V	5000K	80+	Frosted	220°	50K	1

### T8 LED Direct Fit : Electronic Ballast Compatible Dimmable/Emergency Tubes

Order Code	Item	Length	Lm	Nominal Lamp W	System W (Ballast Dependent)	V (Ballast Dependent)	CCT	CRI	Glass Tube	Bm	Life/Hrs	Photo #
09356	LED14T8F/36/835-G6DR	3'	1,400	11W	13W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2
09269	LED14T8F/36/840-G6DR	3'	1,450	11W	13W	120-277V, 347V	4000K	80+	Frosted	220°	50K	2
09357	LED14T8F/36/850-G6DR	3'	1,450	11W	13W	120-277V, 347V	5000K	80+	Frosted	220°	50K	2
09167	LED18T8F/48/835-G6DR	4'	1,700	14W	17W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2
09168	LED18T8F/48/840-G6DR	4'	1,800	14W	17W	120-277V, 347V	4000K	80+	Frosted	220°	50K	2
09169	LED18T8F/48/850-G6DR	4'	1,800	14W	17W	120-277V, 347V	5000K	80+	Frosted	220°	50K	2
09355	LED22T8F/48/835-G6DR†	4'	2,200	17W	19.5W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2
09177	LED22T8F/48/850-G6DR†	4'	2,200	17W	19.5W	120-277V, 347V	5000K	80+	Frosted	220°	50K	2
09302	LED22T8F/48/835-G6DR-M*	1160mm	2,200	17W	20W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2
09290	LED22T8F/48/840-G6DR-M*	1160mm	2,200	17W	20W	120-277V, 347V	4000K	80+	Frosted	220°	50K	2



5 YEAR WARRANTY

C **UL** US

CLASSIFIED **UL** US

**DLC** LISTED

### T8 LED Direct Fit : Electronic Ballast Compatible Tubes

Order Code	Item	Length	Lm	Nominal W	V (Ballast Dependent)	CCT	CRI	Glass Tube	Bm	Life/Hrs	Photo #	DLC v4.1
60440	LED8WT8/24/835-G7DR	2'	1,200	8W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2	✓
60441	LED8WT8/24/840-G7DR	2'	1,250	8W	120-277V, 347V	4000K	80+	Frosted	220°	50K	2	✓
60442	LED8WT8/24/850-G7DR	2'	1,250	8W	120-277V, 347V	5000K	80+	Frosted	220°	50K	2	✓
60443	LED11.5WT8/48/835-G7DR	4'	1,700	11.5W	120-277V, 347V	3500K	80+	Frosted	220°	50K	2	✓
60444	LED11.5WT8/48/840-G7DR	4'	1,800	11.5W	120-277V, 347V	4000K	80+	Frosted	220°	50K	2	✓
60445	LED11.5WT8/48/850-G7DR	4'	1,800	11.5W	120-277V, 347V	5000K	80+	Frosted	220°	50K	2	✓

### T8 LED Direct Fit U-Bend : Electronic Ballast Compatible

Order Code	Item	Length	Lm	Nominal Lamp W	System W	V (Ballast Dependent)	CCT	CRI	Glass Tube	Bm	Life/Hrs	Photo #
09113	LED18T8F/U6/835-G5DR	2' U-Bend 6"	1,700	12W	15W	120-277V, 347V	3500K	80+	Frosted	220°	50K	3
09114	LED18T8F/U6/840-G5DR	2' U-Bend 6"	1,800	12W	15W	120-277V, 347V	4000K	80+	Frosted	220°	50K	3
09116	LED18T8F/U6/850-G5DR	2' U-Bend 6"	1,800	12W	15W	120-277V, 347V	5000K	80+	Frosted	220°	50K	3
60458	LED12WT8/U1/835-G7DR	2' U-Bend 1-5/8"	1,700	12W	15W	120-277V, 347V	3500K	80+	Frosted	210°	50K	4
60459	LED12WT8/U1/840-G7DR	2' U-Bend 1-5/8"	1,800	12W	15W	120-277V, 347V	4000K	80+	Frosted	210°	50K	4
60460	LED12WT8/U1/850-G7DR	2' U-Bend 1-5/8"	1,800	12W	15W	120-277V, 347V	5000K	80+	Frosted	210°	50K	4


### T8 LED Line Voltage : Bypass Nano-Polycarbonate Tubes

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Envelope	Bm	Life/Hrs	Photo #	DLC v4.1
09368	LED9WT8/P/24/835-G7D	2'	1,100	9W	3500K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09369	LED9WT8/P/24/840-G7D	2'	1,150	9W	4000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09370	LED9WT8/P/24/850-G7D	2'	1,150	9W	5000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09359	LED14WT8/P/48/835-G7D	4'	1,700	14W	3500K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09360	LED14WT8/P/48/840-G7D	4'	1,800	14W	4000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09361	LED14WT8/P/48/850-G7D	4'	1,800	14W	5000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09362	LED17WT8/P/48/835-G7D	4'	2,100	17W	3500K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09363	LED17WT8/P/48/840-G7D	4'	2,200	17W	4000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓
09364	LED17WT8/P/48/850-G7D	4'	2,200	17W	5000K	80+	Frosted	Nano-Polycarb	210°	50K	5	✓

### T8 LED Line Voltage : Bypass Glass Tubes

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Envelope	Bm	Life/Hrs	Photo #	DLC v4.1
09322	LED9WT8F/24/835K-G7D	2'	1,100	9W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09323	LED9WT8F/24/840K-G7D	2'	1,150	9W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09324	LED9WT8F/24/850K-G7D	2'	1,150	9W	5000K	80+	Frosted	Glass	210°	50K	6	✓
09319	LED12WT8F/36/835K-G7D	3'	1,400	12W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09320	LED12WT8F/36/840K-G7D	3'	1,450	12W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09321	LED12WT8F/36/850K-G7D	3'	1,450	12W	5000K	80+	Frosted	Glass	210°	50K	6	✓
09666	LED11.5WT8/48/835-G7D	4'	1,700	11.5W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09667	LED11.5WT8/48/840-G7D	4'	1,800	11.5W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09668	LED11.5WT8/48/850-G7D	4'	1,800	11.5W	5000K	80+	Frosted	Glass	210°	50K	6	✓
09669	LED11.5WT8/48/835-PET-G7D	4'	1,700	11.5W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09670	LED11.5WT8/48/840-PET-G7D	4'	1,800	11.5W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09671	LED11.5WT8/48/850-PET-G7D	4'	1,800	11.5W	5000K	80+	Frosted	Glass	210°	50K	6	✓

Continued on next page >>>

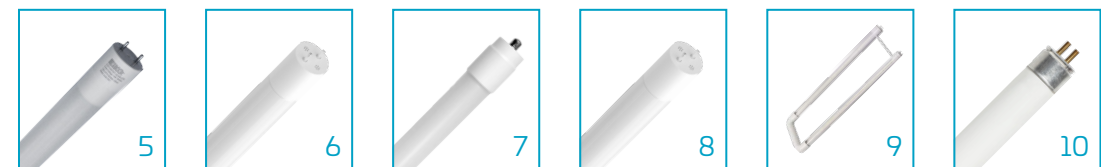



T8 LED Line Voltage : Bypass Glass Tubes (Continued)

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Envelope	Bm	Life/Hrs	Photo #	DLC v4.1
09371	LED12WT8/PRM/48/835-G7D	4'	1,700	12.5W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09372	LED12WT8/PRM/48/840-G7D	4'	1,800	12.5W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09373	LED12WT8/PRM/48/850-G7D	4'	1,800	12.5W	5000K	80+	Frosted	Glass	210°	50K	6	✓
09288	LED15WT8F/48/835K-G7D	4'	1,700	15W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09278	LED15WT8F/48/840K-G7D	4'	1,800	15W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09279	LED15WT8F/48/850K-G7D	4'	1,800	15W	5000K	80+	Frosted	Glass	210°	50K	6	✓
09396	LED18WT8F/48/835K-G7D	4'	2,100	18W	3500K	80+	Frosted	Glass	210°	50K	6	✓
09397	LED18WT8F/48/840K-G7D	4'	2,200	18W	4000K	80+	Frosted	Glass	210°	50K	6	✓
09398	LED18WT8F/48/850K-G7D	4'	2,200	18W	5000K	80+	Frosted	Glass	210°	50K	6	✓

T8 LED Line Voltage : Bypass Glass Tubes : 8'

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Envelope	Life/ Hrs	Photo #
09567	LED43WT8/96/840-DBL-G7D	8'	5,500	43W	4000K	80+	Frosted	Glass	50K	7
09568	LED43WT8/96/850-DBL-G7D	8'	5,500	43W	5000K	80+	Frosted	Glass	50K	7

NOTE: \$1500 minimum total order required for paid freight when purchasing any 8' T8 products. Product ships on 8' pallet in case quantities only.

T8 LED Line Voltage : Bypass Glass Tubes : Double-Ended

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Envelope	Bm	Life/Hrs	Photo #	DLC v4.1
09598	LED9WT8/24/840-DBL-G7D	2'	1,150	9W	4000K	80+	Frosted	Glass	210°	50K	8	✓
09599	LED9WT8/24/850-DBL-G7D	2'	1,150	9W	5000K	80+	Frosted	Glass	210°	50K	8	✓
09600	LED12WT8/36/835-DBL-G7D	3'	1,400	12W	3500K	80+	Frosted	Glass	210°	50K	8	
09601	LED12WT8/36/840-DBL-G7D	3'	1,450	12W	4000K	80+	Frosted	Glass	210°	50K	8	
09602	LED12WT8/36/850-DBL-G7D	3'	1,450	12W	5000K	80+	Frosted	Glass	210°	50K	8	
09594	LED14WT8/48/835-DBL-G7D	4'	1,700	14W	3500K	80+	Frosted	Glass	210°	50K	8	✓
09595	LED14WT8/48/840-DBL-G7D	4'	1,700	14W	4000K	80+	Frosted	Glass	210°	50K	8	✓
09603	LED14WT8/48/850-DBL-G7D	4'	1,700	14W	5000K	80+	Frosted	Glass	210°	50K	8	✓
09604	LED17WT8/48/835-DBL-G7D	4'	2,100	17W	3500K	80+	Frosted	Glass	210°	50K	8	✓
09605	LED17WT8/48/840-DBL-G7D	4'	2,200	17W	4000K	80+	Frosted	Glass	210°	50K	8	✓
09606	LED17WT8/48/850-DBL-G7D	4'	2,200	17W	5000K	80+	Frosted	Glass	210°	50K	8	✓

T8 LED Line Voltage U-Bend : Bypass

Order Code	Item	Length	Lm	W	CCT	CRI	Appearance	Life/ Hrs	Photo #
08585	LEDP-18T8FU6/41K	2'	1,800	18	4100K	80+	Frosted	50K	9
08587	LEDP-18T8FU6/50K	2'	1,800	18	5000K	80+	Frosted	50K	9

T5 LED Direct Fit : Electronic Ballast Compatible Dimmable/Emergency Tubes

Order Code	Item	Length	Lm	Nominal Lamp W	V (Ballast Dependent)	CCT	CRI	Glass Tube	Bm	Life/Hrs	Photo #	DLC v4.1
09553	LED11WT5HO/22/835-G7DR	2'	1,350	11W	120-277V	3500K	80+	Frosted	185°	50K	10	
09554	LED11WT5HO/22/840-G7DR	2'	1,400	11W	120-277V	4000K	80+	Frosted	185°	50K	10	
09555	LED11WT5HO/22/850-G7DR	2'	1,400	11W	120-277V	5000K	80+	Frosted	185°	50K	10	
09556	LED12.5WT5HE/46/835-G7DR	4'	1,700	12.5W	120-277V	3500K	80+	Frosted	185°	50K	10	
09557	LED12.5WT5HE/46/840-G7DR	4'	1,800	12.5W	120-277V	4000K	80+	Frosted	185°	50K	10	
09558	LED12.5WT5HE/46/850-G7DR	4'	1,800	12.5W	120-277V	5000K	80+	Frosted	185°	50K	10	
09549	LED25WT5HO/46/835-G7DR	4'	3,200	25W	120-277V	3500K	80+	Frosted	185°	50K	10	✓
09550	LED25WT5HO/46/840-G7DR	4'	3,500	25W	120-277V	4000K	80+	Frosted	185°	50K	10	✓
09551	LED25WT5HO/46/850-G7DR	4'	3,500	25W	120-277V	5000K	80+	Frosted	185°	50K	10	✓
09475	LED32T5HO/46/835-G6DR†	46"	3,200	25W	120-277V, 347V	3500K	80+	Frosted	185°	50K	10	
09178	LED32T5HO/46/840-G6DR†	46"	3,200	25W	120-277V, 347V	4000K	80+	Frosted	185°	50K	10	



Filament Dimmable Decorative Lamps

- LED lamp with the same vintage look and feel as nostalgic incandescent filament lamps
- 80% more efficient and 20x longer life than incandescent
- 320° omni-directional light source adds warm ambient glow to room décor
- 2200K amber and 2700K clear available in decorative shapes
- Compatible with a wide array of leading edge TRIAC dimmers
- Suitable for use in damp locations
- Suitable for use in totally enclosed fixtures
- Contains no lead or mercury; RoHS compliant
- 3 year limited warranty

Filament Decorative : Dimmable : Medium/Candelabra Base

Order Code	Item	Lm	W	CCT	CRI	Color	MOL	Life/Hrs	Base	Replaces Incandescent	Photo #
09308	LED5WA19/FIL/822K-DIM-G6	400	5W	2200K	80+	Amber	4.25"	15K	E26	40W A19 Amber	1
09314	LED5WG40/FIL/822K-DIM-G6	400	5W	2200K	80+	Amber	6.69"	15K	E26	40W G40 Amber	2
09315	LED5WST19/FIL/822K-DIM-G6	400	5W	2200K	80+	Amber	5.04"	15K	E26	40W ST19 Amber	3
09441	LED7WA19/FIL/SB/827K-DIM-G7	800	7W	2700K	80+	Silver Bowl	4.25"	15K	E26	60W A19 Silver Bowl	5
09309	LED7WA19/FIL/827K-DIM-G6	800	7W	2700K	80+	Clear	4.25"	15K	E26	60W A19	4
09310	LED4WB11E12/FIL/827K-DIM-G6	400	4W	2700K	80+	Clear	3.86"	15K	E12	40W B11	6
09311	LED5WB11E26/FIL/827K-DIM-G6	450	5W	2700K	80+	Clear	3.71"	15K	E26	40W B11	7
09312	LED4WBA11E12/FIL/827K-DIM-G6	400	4W	2700K	80+	Clear	4.72"	15K	E12	40W BA11	8
09313	LED6WG25/FIL/827K-DIM-G6	400	5.5W	2700K	80+	Clear	4.41"	15K	E26	40W G25	9





## PL CFL Replacement Lamps


- Directly replaces PL compact fluorescent lamps
- Direct fit plug-and-play solution
- Available in horizontal or vertical orientation
- Choice of 2700K, 3000K, 3500K and 4000K CCT
- Instant-on with no warmup, unlike compact fluorescent
- Shatter-resistant for reduced risk of injury and breakage
- Dimmable models available (ballast dependent)
- Environmentally friendly; contains no glass, lead or mercury

### PL Replacement : Direct Fit : Magnetic Ballast Compatible : 2-Pin


Order Code	Item	Lm	W	CCT	CRI	Orientation	Life/Hrs L70	Base	Replaces	Photo #
09526	LED5W2PH/G23/827-G7*	475	5W	2700K	80+	Horizontal	50K	G23	5W/7W/9W 2 pin dual	1
09527	LED5W2PH/G23/835-G7*	475	5W	3500K	80+	Horizontal	50K	G23	5W/7W/9W 2 pin dual	1
09528	LED5W2PH/G23/840-G7*	500	5W	4000K	80+	Horizontal	50K	G23	5W/7W/9W 2 pin dual	1
09529	LED5W2PH/G23/850-G7*	500	5W	5000K	80+	Horizontal	50K	G23	5W/7W/9W 2 pin dual	1
09530	LED7W2PH/GX23/827-G7*	650	7W	2700K	80+	Horizontal	50K	GX23	13W 2 pin dual & quad	2
09531	LED7W2PH/GX23/835-G7*	650	7W	3500K	80+	Horizontal	50K	GX23	13W 2 pin dual & quad	2
09532	LED7W2PH/GX23/840-G7*	700	7W	4000K	80+	Horizontal	50K	GX23	13W 2 pin dual & quad	2
09533	LED7W2PH/GX23/850-G7*	700	7W	5000K	80+	Horizontal	50K	GX23	13W 2 pin dual & quad	2

### PL Replacement : Direct Fit : Magnetic Ballast Compatible : 2-Pin

Order Code	Item	Lm	W	CCT	CRI	Orientation	Life/Hrs L70	Base	Replaces	Photo #
09332	LED9W2PH/827DR-G6	850	9W	2700K	80+	Horizontal	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	3
09250	LED9W2PH/830DR-G6	850	9W	3000K	80+	Horizontal	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	3
09251	LED9W2PH/835DR-G6	850	9W	3500K	80+	Horizontal	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	3
09252	LED9W2PH/840DR-G6	900	9W	4000K	80+	Horizontal	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	3
09334	LED9W2PV/827DR-G6	850	9W	2700K	80+	Vertical	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	4
09253	LED9W2PV/830DR-G6	850	9W	3000K	80+	Vertical	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	4
09254	LED9W2PV/835DR-G6	850	9W	3500K	80+	Vertical	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	4
09255	LED9W2PV/840DR-G6	900	9W	4000K	80+	Vertical	50K	G24d-3, GX24d-3	26W 2-pin quad & triple	4

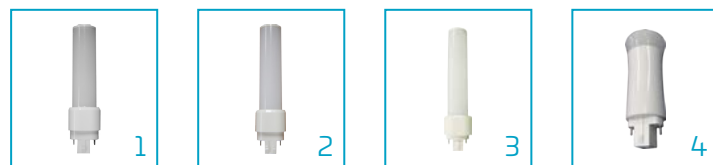

5 YEAR WARRANTY

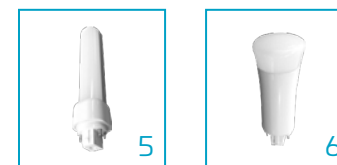

### PL Replacement : Direct Fit : Electronic Ballast Compatible : 4-Pin

Order Code	Item	Lm	W	CCT	CRI	Orientation	Life/Hrs L70	Base	Replaces	Photo #	LDL
09331	LED9W4PH/827DR-G6	850	9W	2700K	80+	Horizontal	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	5	
09244	LED9W4PH/830DR-G6	850	9W	3000K	80+	Horizontal	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	5	✘
09245	LED9W4PH/835DR-G6	850	9W	3500K	80+	Horizontal	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	5	✘
09246	LED9W4PH/840DR-G6	900	9W	4000K	80+	Horizontal	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	5	✘
09333	LED9W4PV/827DR-G6	850	9W	2700K	80+	Vertical	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	6	
09247	LED9W4PV/830DR-G6	850	9W	3000K	80+	Vertical	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	6	✘
09248	LED9W4PV/835DR-G6	850	9W	3500K	80+	Vertical	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	6	✘
09249	LED9W4PV/840DR-G6	900	9W	4000K	80+	Vertical	50K	G24q-3, GX24q-3, GX24q-4	26/32/42W 4-pin quad & triple	6	✘



## A19/A21 Replacement Lamps

- Direct replacement for incandescent A lamps
- 300° omni beam angle is ideal for table lamps, wall sconces, and luminous globe fixtures
- 80% more efficient and 30x longer life than incandescent
- Compatible with a wide array of dimmers
- Instant-on with no warm up, unlike CFLs
- Available in 2700K, 3000K, and 4000K CCT
- Shatter-resistant for reduced risk of injury and breakage

### A19/A21 : Omnidirectional : Dimmable : Medium Base (Sold in 2-Packs)

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
60421	LED6WA19/OMN/827K-DIM-G7 2PK	470	6W	2700K	80+	Omni	15K	40W A19	1	★
60422	LED6WA19/OMN/830K-DIM-G7 2PK	470	6W	3000K	80+	Omni	15K	40W A19	1	★
60423	LED6WA19/OMN/840K-DIM-G7 2PK	470	6W	4000K	80+	Omni	15K	40W A19	1	★
60424	LED9WA19/OMN/827K-DIM-G7 2PK	800	9W	2700K	80+	Omni	15K	60W A19	1	★
60425	LED9WA19/OMN/830K-DIM-G7 2PK	800	9W	3000K	80+	Omni	15K	60W A19	1	★
60426	LED9WA19/OMN/840K-DIM-G7 2PK	800	9W	4000K	80+	Omni	15K	60W A19	1	★
60427	LED9WA19/OMN/827K-DEC-G7 2PK*	800	9W	2700K	80+	Omni	15K	60W A19	1	★
60428	LED9WA19/OMN/830K-DEC-G7 2PK*	800	9W	3000K	80+	Omni	15K	60W A19	1	★
60429	LED9WA19/OMN/840K-DEC-G7 2PK*	800	9W	4000K	80+	Omni	15K	60W A19	1	★
60430	LED11WA19/OMN/827K-DIM-G7 2PK	1,100	11W	2700K	80+	Omni	15K	75W A19	1	★
60431	LED11WA19/OMN/830K-DIM-G7 2PK	1,100	11W	3000K	80+	Omni	15K	75W A19	1	★
60432	LED11WA19/OMN/840K-DIM-G7 2PK	1,100	11W	4000K	80+	Omni	15K	75W A19	1	★
60433	LED15WA21/OMN/827K-DIM-G7 2PK	1,600	15W	2700K	80+	Omni	15K	100W A21	2	★
60434	LED15WA21/OMN/830K-DIM-G7 2PK	1,600	15W	3000K	80+	Omni	15K	100W A21	2	★
60435	LED15WA21/OMN/840K-DIM-G7 2PK	1,600	15W	4000K	80+	Omni	15K	100W A21	2	★
60436	LED15WA21/OMN/850K-DIM-G7 2PK	1,600	15W	5000K	80+	Omni	15K	100W A21	2	★
09413	LED15WA21/3WAY/827K-DIM-G7 2PK**	1,600	15W	2700K	80+	Omni	15K	100W A21	2	★



### A19/A21 : Omnidirectional : Dimmable : GU24 Base (Sold in 2-Packs)

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09442	LED9WA19/OMN/827GU24DIMG7 2PK	800	9W	2700K	80+	Omni	15K	60W A19	3	★
09443	LED9WA19/OMN/830GU24DIMG7 2PK	800	9W	3000K	80+	Omni	15K	60W A19	3	★
09444	LED9WA19/OMN/840GU24DIMG7 2PK	800	9W	4000K	80+	Omni	15K	60W A19	3	★
09445	LED11WA19/OMN/827GU24DIMG7 2PK	1,100	11W	2700K	80+	Omni	15K	75W A19	3	★
09446	LED11WA19/OMN/830GU24DIMG7 2PK	1,100	11W	3000K	80+	Omni	15K	75W A19	3	★
09447	LED11WA19/OMN/840GU24DIMG7 2PK	1,100	11W	4000K	80+	Omni	15K	75W A19	3	★
09453	LED15WA21/OMN/827GU24DIMG7 2PK	1,600	15W	2700K	80+	Omni	15K	100W A21	4	★
09454	LED15WA21/OMN/830GU24DIMG7 2PK	1,600	15W	3000K	80+	Omni	15K	100W A21	4	★
09455	LED15WA21/OMN/840GU24DIMG7 2PK	1,600	15W	4000K	80+	Omni	15K	100W A21	4	★

### A19/A21 : 240° : Dimmable : Advantage™ : Medium Base (Sold in 2-Packs)

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09461	LED6WA19/ADV/850-DIM-G7 2PK	440	6W	5000K	80+	240°	10K	40W A19	5	
09506	LED9WA19/ADV/827-DIM-G7A 2PK	750	9W	2700K	80+	240°	10K	75W A19	5	
09507	LED9WA19/ADV/830-DIM-G7A 2PK	750	9W	3000K	80+	240°	10K	75W A19	5	
09508	LED9WA19/ADV/840-DIM-G7A 2PK	750	9W	4000K	80+	240°	10K	75W A19	5	
09509	LED9WA19/ADV/850-DIM-G7A 2PK	750	9W	5000K	80+	240°	10K	75W A19	5	
60403	LED9WA19/ADV/840K-DIM-G7 2PK†	750	9W	4000K	80+	240°	10K	60W A19	5	
60405	LED12WA19/ADV/827K-DIM-G7 2PK	1,050	12W	2700K	80+	240°	10K	75W A19	5	
60406	LED12WA19/ADV/830K-DIM-G7 2PK	1,050	12W	3000K	80+	240°	10K	75W A19	5	
60407	LED12WA19/ADV/840K-DIM-G7 2PK	1,050	12W	4000K	80+	240°	10K	75W A19	5	
60408	LED12WA19/ADV/850K-DIM-G7 2PK	1,050	12W	5000K	80+	240°	10K	75W A19	5	
60409	LED16WA21/ADV/827K-DIM-G7 2PK	1,550	16W	2700K	80+	240°	10K	100W A21	5	
60410	LED16WA21/ADV/830K-DIM-G7 2PK	1,550	16W	3000K	80+	240°	10K	100W A21	5	
60411	LED16WA21/ADV/840K-DIM-G7 2PK	1,550	16W	4000K	80+	240°	10K	100W A21	5	
60412	LED16WA21/ADV/850K-DIM-G7 2PK	1,550	16W	5000K	80+	240°	10K	100W A21	5	

### A19/A21 : 240° : Non-Dimmable : Advantage™ : Medium Base (Sold in 2-Packs)

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09294	LED9WA19/240/830K-G6A 2PK†	760	9W	3000K	80+	240°	10K	60W A19	5	
09510	LED9WA19/ADV/827-G7A 2PK	750	9W	2700K	80+	240°	10K	60W A19	5	
09512	LED9WA19/ADV/840-G7A 2PK	750	9W	4000K	80+	240°	10K	60W A19	5	
60413	LED12WA19/ADV/827K-G7 2PK	1,050	12W	2700K	80+	240°	10K	75W A19	5	
60414	LED12WA19/ADV/830K-G7 2PK	1,050	12W	3000K	80+	240°	10K	75W A19	5	
60415	LED12WA19/ADV/840K-G7 2PK	1,050	12W	4000K	80+	240°	10K	75W A19	5	
60416	LED12WA19/ADV/850K-G7 2PK	1,050	12W	5000K	80+	240°	10K	75W A19	5	
60417	LED16WA21/ADV/827K-G7 2PK	1,550	16W	2700K	80+	240°	10K	100W A21	5	
60418	LED16WA21/ADV/830K-G7 2PK	1,550	16W	3000K	80+	240°	10K	100W A21	5	
60419	LED16WA21/ADV/840K-G7 2PK	1,550	16W	4000K	80+	240°	10K	100W A21	5	
60420	LED16WA21/ADV/850K-G7 2PK	1,550	16W	5000K	80+	240°	10K	100W A21	5	





A19/A21 : 300° Omnidirectional : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #
09132	LED6WA19/300/827K-DIM-G6†	470	6W	2700K	80+	300°	25K	40W A19	1
08914	LED11WA19/300/827K-DIM-G5†	1,100	11W	2700K	80+	300°	25K	75W A19	1
09107	LED15WA21/3WAY/827K-G5**†	1,600	15W	2700K	80+	300°	25K	100W A21	2

A19/A21 : 300° Omnidirectional : Dimmable : GU24 Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #
08925	LED9WA19/300/840K-GU24-DIM-G5†	800	9W	4000K	80+	300°	25K	60W A19	3
08926	LED11WA19/300/827K-GU24-DIM-G5†	1,100	11W	2700K	80+	300°	25K	75W A19	3
08927	LED11WA19/300/830K-GU24-DIM-G5†	1,100	11W	3000K	80+	300°	25K	75W A19	3
08928	LED11WA19/300/840K-GU24-DIM-G5†	1,100	11W	4000K	80+	300°	25K	75W A19	3
08929	LED15WA21/300/827K-GU24-DIM-G5†	1,600	15W	2700K	80+	300°	25K	100W A21	4
08930	LED15WA21/300/830K-GU24-DIM-G5†	1,600	15W	3000K	80+	300°	25K	100W A21	4
08931	LED15WA21/300/840K-GU24-DIM-G5†	1,600	15W	4000K	80+	300°	25K	100W A21	4

A19 : 240° : Dimmable : Advantage™ : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #
09144	LED6WA19/240/830K-DIM-G6A†	440	6W	3000K	80+	240°	25K	40W A19	5
09145	LED6WA19/240/840K-DIM-G6A†	440	6W	4000K	80+	240°	25K	40W A19	5
09146	LED6WA19/240/850K-DIM-G6A†	440	6W	5000K	80+	240°	25K	40W A19	5

A19/A21 : 240° : Dimmable : Advantage™ : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #
09140	LED6WA19/240/827K-G6A†	420	6W	2700K	80+	240°	25K	40W A19	5
09141	LED6WA19/240/830K-G6A†	420	6W	3000K	80+	240°	25K	40W A19	5
09142	LED6WA19/240/840K-G6A†	420	6W	4000K	80+	240°	25K	40W A19	5



Decorative Replacement Lamps

- Direct replacement for incandescent globe and bullet lamps
- Available in 2700K, 3000K and 4000K CCT
- 15,000 hour rated life
- Lasts 10x longer than incandescent
- 50,000 hour design life
- Instant-on with no warm up, unlike CFLs
- Ideal for wall sconces and ceiling fans
- Not for use in enclosed fixtures

G25 Decorative : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
90038	LED6WG25/827K-DIM-G4	450	6W	2700K	80+	15K	50W G25	1	★
90037	LED6WG25/830K-DIM-G4	450	6W	3000K	80+	15K	50W G25	1	★
90036	LED6WG25/840K-DIM-G4	450	6W	4000K	80+	15K	50W G25	1	

B11 Decorative : Dimmable : Candelabra Base

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08729	LED5WB11/E12/827-DIM-G5	325	5W	2700K	80+	15K	40W B11	2	★
08730	LED5WB11/E12/830-DIM-G5	325	5W	3000K	80+	15K	40W B11	2	★

B11 Decorative : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08731	LED5WB11/E26/827-DIM-G5	325	5W	2700K	80+	15K	40W B11	3	★
08732	LED5WB11/E26/830-DIM-G5	325	5W	3000K	80+	15K	40W B11	3	★





## BR Replacement Lamps

- Direct replacement for incandescent BR lamps
- 80% more efficient and 20x longer life than incandescent
- Smooth aluminum body with ANSI standard form factor
- Instant-on with no warm up, unlike CFLs
- +25,000 hour rated life for ENERGY STAR® Approved lamps
- 50,000 hour design life
- Choice of 2700K, 3000K, 4000K, or 5000K CCT
- Acceptable for ICAT rated downlights

### BR20 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08932	LED7WBR20/827K-DIM-G5	550	7W	2700K	80+	120°	25K	50W BR20	1	★
08933	LED7WBR20/830K-DIM-G5	550	7W	3000K	80+	120°	25K	50W BR20	1	★
08935	LED7WBR20/840K-DIM-G5	550	7W	4000K	80+	120°	25K	50W BR20	1	★

### BR30 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08998	LED8WBR30/827K-DIM-G5	650	8W	2700K	80+	120°	25K	65W BR30	2	★
08999	LED8WBR30/830K-DIM-G5	650	8W	3000K	80+	120°	25K	65W BR30	2	★
09000	LED8WBR30/840K-DIM-G5	650	8W	4000K	80+	120°	25K	65W BR30	2	★
08936	LED11WBR30/827K-DIM-G5	850	11W	2700K	80+	120°	25K	65W BR30	2	★
08937	LED11WBR30/830K-DIM-G5	850	11W	3000K	80+	120°	25K	65W BR30	2	★
08938	LED11WBR30/840K-DIM-G5	850	11W	4000K	80+	120°	25K	65W BR30	2	★
09111	LED11WBR30/850K-DIM-G5	850	11W	5000K	80+	120°	25K	65W BR30	2	★

### BR30 : Dimmable : Medium Base : 90 CRI

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09351	LED11WBR30/927K-DIM-G6	800	11W	2700K	90+	120°	25K	65W BR30	2	★
09352	LED11WBR30/930K-DIM-G6	800	11W	3000K	90+	120°	25K	65W BR30	2	★



5 YEAR WARRANTY



### BR30 : Dimmable : Medium Base : Pink

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #
09092	LED11WBR30/PINK-DIM-G5	N/A	11W	N/A	N/A	120°	25K	65W BR30 Pink	3

### BR40 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08942	LED17WBR40/827K-DIM-G5	1,400	17W	2700K	80+	120°	25K	100W BR40	5	★
08943	LED17WBR40/830K-DIM-G5	1,400	17W	3000K	80+	120°	25K	100W BR40	5	★
08944	LED17WBR40/840K-DIM-G5	1,400	17W	4000K	80+	120°	25K	100W BR40	5	★

### BR40 : Dimmable : Medium Base : 90 CRI

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09353	LED13WBR40/927K-DIM-G5	1,000	13W	2700K	90+	120°	25K	80W BR40	5	★
09354	LED13WBR40/930K-DIM-G5	1,000	13W	3000K	90+	120°	25K	80W BR40	5	★





## PAR Replacement Lamps

- Direct replacement for halogen PARs
- Compatible with a wide array of dimmers
- +25,000 hour rated life for ENERGY STAR® Approved lamps
- 50,000 hour design life
- Up to 80% electricity savings vs. halogen
- Choice of 2700K, 3000K and 4000K CCT
- Environmentally friendly: contains no glass, mercury, or lead

### PAR16 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09041	LED7WPAR16/FL/827K-DIM-G5	490	7W	2700K	80+	40°	25K	50W PAR16	1	★
09042	LED7WPAR16/FL/830K-DIM-G5	490	7W	3000K	80+	40°	25K	50W PAR16	1	★
09043	LED7WPAR16/FL/840K-DIM-G5	490	7W	4000K	80+	40°	25K	50W PAR16	1	★
09038	LED7WPAR16/NFL/827K-DIM-G5	490	7W	2700K	80+	20°	25K	50W PAR16	1	★
09039	LED7WPAR16/NFL/830K-DIM-G5	490	7W	3000K	80+	20°	25K	50W PAR16	1	★
09040	LED7WPAR16/NFL/840K-DIM-G5	490	7W	4000K	80+	20°	25K	50W PAR16	1	★

### PAR20 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09184	LED7WPAR20/FL/827K-DIM-G6	470	7W	2700K	80+	40°	25K	50W PAR20	2	★
09185	LED7WPAR20/FL/830K-DIM-G6	470	7W	3000K	80+	40°	25K	50W PAR20	2	★
09186	LED7WPAR20/FL/840K-DIM-G6	470	7W	4000K	80+	40°	25K	50W PAR20	2	★
09187	LED7WPAR20/NFL/827K-DIM-G6	470	7W	2700K	80+	20°	25K	50W PAR20	2	★
09188	LED7WPAR20/NFL/830K-DIM-G6	470	7W	3000K	80+	20°	25K	50W PAR20	2	★
09189	LED7WPAR20/NFL/840K-DIM-G6	470	7W	4000K	80+	20°	25K	50W PAR20	2	★



5 YEAR WARRANTY



### PAR30 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
09155	LED11WPAR30/FL/827K-DIM-G6	850	11W	2700K	80+	40°	25K	75W PAR30	3	★
09156	LED11WPAR30/FL/830K-DIM-G6	850	11W	3000K	80+	40°	25K	75W PAR30	3	★
09157	LED11WPAR30/FL/840K-DIM-G6	850	11W	4000K	80+	40°	25K	75W PAR30	3	★
09325	LED11WPAR30/FL/850K-DIM-G6	850	11W	5000K	80+	40°	25K	75W PAR30	3	★
09158	LED11WPAR30/NFL/827K-DIM-G6	850	11W	2700K	80+	20°	25K	75W PAR30	3	★
09159	LED11WPAR30/NFL/830K-DIM-G6	850	11W	3000K	80+	20°	25K	75W PAR30	3	★
09160	LED11WPAR30/NFL/840K-DIM-G6	850	11W	4000K	80+	20°	25K	75W PAR30	3	★

### PAR30SN : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	ENERGY STAR
08557	LED12WPAR30S/NFL/830-DIM-G4A†	800	12W	3000K	80+	20°	25K	75W PAR30SN	4	
08558	LED12WPAR30S/NFL/840-DIM-G4A†	800	12W	4000K	80+	20°	25K	75W PAR30SN	4	
09476	LED12WPAR30S/FL/827-DIM-G7	950	12W	2700K	80+	40°	25K	75W PAR30SN	4	★
09477	LED12WPAR30S/FL/830-DIM-G7	950	12W	3000K	80+	40°	25K	75W PAR30SN	4	★
09478	LED12WPAR30S/FL/840-DIM-G7	950	12W	4000K	80+	40°	25K	75W PAR30SN	4	★
09479	LED12WPAR30S/NFL/827-DIM-G7	950	12W	2700K	80+	40°	25K	75W PAR30SN	4	★
09480	LED12WPAR30S/NFL/830-DIM-G7	950	12W	3000K	80+	40°	25K	75W PAR30SN	4	★
09481	LED12WPAR30S/NFL/840-DIM-G7	950	12W	4000K	80+	40°	25K	75W PAR30SN	4	★

### PAR38 : Dimmable : Medium Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Incan.	Photo #	Wet Location Rated	ENERGY STAR
09165	LED13WPAR38/NFL/830K-DIM-G6	1,050	13W	3000K	80+	25°	25K	120W PAR38	5		
09161	LED13WPAR38/FL/827K-DIM-G6	1,050	13W	2700K	80+	40°	25K	120W PAR38	5		★
09162	LED13WPAR38/FL/830K-DIM-G6	1,050	13W	3000K	80+	40°	25K	120W PAR38	5		★
09163	LED13WPAR38/FL/840K-DIM-G6	1,050	13W	4000K	80+	40°	25K	120W PAR38	5		★
09513	LED15WPAR38/FL/827-DIM-G7	1,250	15W	2700K	80+	40°	25K	120W PAR38	5	💧	
09514	LED15WPAR38/FL/830-DIM-G7	1,250	15W	3000K	80+	40°	25K	120W PAR38	5	💧	
09515	LED15WPAR38/FL/840-DIM-G7	1,250	15W	4000K	80+	40°	25K	120W PAR38	5	💧	
09516	LED15WPAR38/FL/850-DIM-G7	1,250	15W	5000K	80+	40°	25K	120W PAR38	5	💧	
09326	LED17WPAR38/FL/850K-DIM-G4A†	1,300	17W	5000K	80+	40°	25K	120W PAR38	5		
90040	LED17WPAR38/NFL/830K-DIM-G4A†	1,300	17W	3000K	80+	25°	25K	120W PAR38	5	💧	
90039	LED17WPAR38/NFL/840K-DIM-G4A†	1,300	17W	4000K	80+	25°	25K	120W PAR38	5	💧	
09170	LED20WPAR38/FL/827K-DIM-G6	1,700	20W	2700K	80+	50°	25K	250W PAR38	6		★
09171	LED20WPAR38/FL/830K-DIM-G6	1,700	20W	3000K	80+	50°	25K	250W PAR38	6		★
09172	LED20WPAR38/FL/840K-DIM-G6	1,700	20W	4000K	80+	50°	25K	250W PAR38	6		★







## Miniature Reflector Replacement Lamps

- Direct replacement for halogen miniature reflector lamps
- 25,000 hour rated life lasting 20x longer than halogen incandescent
- Choice of 2700K, 3000K and 4000K CCT
- Available in 2 beam distributions: 25° Narrow Flood & 40° Flood
- Shatter-resistant for reduced risk of injury or breakage
- Contains no lead or mercury; RoHS compliant

### MR16 : Non-Dimmable : GU5.3 Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Halogen	Photo #
08834	LED7WMR16/20/830-G5†	400	7W	3000K	80+	20°	25K	50W MR16	1
08832	LED7WMR16/40/827-G5†	380	7W	2700K	80+	40°	25K	42W MR16	1
08837	LED7WMR16/40/840-G5†	400	7W	4000K	80+	40°	25K	42W MR16	1

### MR16 : Dimmable : GU5.3 Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Halogen	Photo #	ENERGY STAR
09431	LED7WMR16/20/840-DIM-G7†	490	7W	4000K	80+	20°	25K	50W MR16	2	★
09493	LED7WMR16/FL/827-DIM-G7	500	7W	2700K	80+	40°	25K	50W MR16	2	
09494	LED7WMR16/FL/830-DIM-G7	500	7W	3000K	80+	40°	25K	50W MR16	2	
09495	LED7WMR16/FL/840-DIM-G7	500	7W	4000K	80+	40°	25K	50W MR16	2	
09543	LED7WMR16/NFL/827-DIM-G7	500	7W	2700K	80+	25°	25K	50W MR16	2	
09544	LED7WMR16/NFL/830-DIM-G7	500	7W	3000K	80+	25°	25K	50W MR16	2	
09545	LED7WMR16/NFL/840-DIM-G7	500	7W	4000K	80+	25°	25K	50W MR16	2	
09203	LED7WMR16/FL/840K-DIM-G6	540	7W	4000K	80+	40°	25K	50W MR16	2	
09204	LED7WMR16/NFL/827K-DIM-G6	500	7W	2700K	80+	25°	25K	50W MR16	2	



5 YEAR WARRANTY

cUL US LISTED

### MR16 : Dimmable : GU10 Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Halogen	Photo #	ENERGY STAR
09497	LED7WGU10/FL/830-DIM-G7	500	7W	3000K	80+	40°	25K	50W GU10	3	★
09546	LED7WGU10/NFL/827-DIM-G7	500	7W	2700K	80+	20°	25K	50W GU10	3	
09435	LED7WGU10/20/827-DIM-G7†	500	7W	2700K	80+	20°	25K	75W GU10	3	★
09437	LED7WGU10/20/840-DIM-G7†	500	7W	4000K	80+	20°	25K	75W GU10	3	★
90028	LED7WGU10/20/830-DIM-G4†	450	7W	3000K	80+	20°	25K	75W GU10	3	
08839	LED7WGU10/40/827-DIM-G4†	420	7W	2700K	80+	40°	25K	50W GU10	3	
90027	LED7WGU10/40/830-DIM-G4†	450	7W	3000K	80+	40°	25K	50W GU10	3	

### MR11 : Non-Dimmable : GU4 Base

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Halogen	Photo #
08893	LED2WMR11/120/830-G5	140	2W	3000K	80+	120°	35K	20W MR11	4
08894	LED4WMR11/120/830-G5	160	4W	3000K	80+	120°	35K	20W MR11	4

### GBF/1383 : Non-Dimmable

Order Code	Item	Lm	W	CCT	CRI	Bm	Life/Hrs L70	Replaces Halogen	Photo #
08895	LED3WGBF/30/830-G5	125	3W	3000K	80+	30°	20K	20W GBF	5
08900	LED3WGBF/30/840-G5	125	3W	4000K	80+	30°	20K	20W GBF	5
08896	LED3W1383/30/830-G5	125	3W	3000K	80+	30°	20K	20W 1383	5
08899	LED3W1383/30/840-G5	125	3W	4000K	80+	30°	20K	20W 1383	5





## Notes

### G4 & G9 Replacement Lamps

- Direct replacement for halogen incandescent G4 & G9 lamps
- Consumes 75% less energy and lasts 25x longer than incandescent bulbs
- 25,000 hour rated life
- Choice of 3000K, 4000K, and 5000K CCT
- 200° multi-directional beam angle
- Integrated driver

#### G4 : 12VAC

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Replaces Incan.	Photo #
<b>08605</b>	LED2WG4/830K-G4	200	2.5W	3000K	80+	15K	10W G4	1
<b>08606</b>	LED2WG4/840K-G4	200	2.5W	4000K	80+	15K	10W G4	1
<b>08607</b>	LED2WG4/850K-G4	200	2.5W	5000K	80+	15K	10W G4	1

#### G9 : 120V

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Replaces Incan.	Photo #
<b>08609</b>	LED2WG9/840K-G4	200	2.5W	4000K	80+	15K	10W G9	2
<b>08610</b>	LED2WG9/850K-G4	200	2.5W	5000K	80+	15K	10W G9	2





## High Bay Fixtures

- Cost-effective, solid-state solutions for highbay and lowbay applications
- Replaces high-watt HID fixtures and/or multi-lamp fluorescent luminaires
- Available in round and linear configurations
- Range of available accessories to customize fixtures to individual needs
- 5 year system warranty

### BAY : Bay Light Round

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	V	Dimming	Replaces Fluor	Photo #	DLC v4.1 Premium
09582	BAY-3C-50K-U	12,500	100	5000K	80+	11.8"	50K	100-277V	1-10V	HBF 4 Lamp T8 and 4 Lamp T5	1	✓
09588	BAY-3C-50K-V	12,500	100	5000K	80+	11.8"	50K	200-480V	1-10V	HBF 4 Lamp T8 and 4 Lamp T5	1	✓
09583	BAY-4C-50K-U	18,750	150	5000K	80+	11.8"	50K	100-277V	1-10V	HBF 6 Lamp T8 and 4 Lamp T5	1	✓
09589	BAY-4C-50K-V	18,750	150	5000K	80+	11.8"	50K	200-480V	1-10V	HBF 6 Lamp T8 and 4 Lamp T5	1	✓
09584	BAY-5C-50K-U	25,000	200	5000K	80+	11.8"	50K	100-277V	1-10V	HBF 8 Lamp T8 and 6 Lamp T5 HO	1	✓
09590	BAY-5C-50K-V	25,000	200	5000K	80+	11.8"	50K	200-480V	1-10V	HBF 8 Lamp T8 and 6 Lamp T5 HO	1	✓

### BAY : Accessories (Sold Separately)

09585	BAY-REFLECTOR BT-AL-60D	60° Beam Aluminum Reflector
09586	BAY-REFLECTOR BT-AL-90D	90° Beam Aluminum Reflector
09587	BAY-REFLECTOR BT-PC-70D	70° Beam Polycarbonate Reflector

### LLH : Linear Highbay

Order Code	Item	Length	Lm	W	CCT	CRI	MOL	Life/Hrs L70	V	Dimming	Replaces Fluor/HID	Photo #	DLC v4.1 Premium
09193	LLH-2C-U	2'	13,750	110W	5000K	80+	23.8"	70K	120-277V	0-10V Dimming	4-lamp T8, 250W HID	2	✓
09195	LLH-4C-U	4'	26,730	220W	5000K	80+	45.9"	70K	120-277V	0-10V Dimming	6-lamp T5HO, 8-lamp T8	3	✓
09703	LLH-1C-40K-U*	2'	14,300	110W	5000K	80+	32.8"	70K	120-277	0-10V Dimming	HBF 6 Lamp T8 and 4 Lamp T5	2	✓
09538	LLH-1C-50K-U	2'	14,410	110W	5000K	80+	32.8"	70K	120-277	0-10V Dimming	HBF 6 Lamp T8 and 4 Lamp T5	2	✓
09539	LLH-2C-50K-U	2'	21,222	162W	5000K	80+	32.8"	70K	120-277	0-10V Dimming	HBF 8 Lamp T8 and 6 Lamp T5 HO	2	✓

Continued on next page >>>



### LLH : Linear Highbay (Continued)

Order Code	Item	Length	Lm	W	CCT	CRI	MOL	Life/Hrs L70	V	Dimming	Replaces Fluor/HID	Photo #	DLC v4.1 Premium
09540	LLH-3C-50K-U	4'	29,213	223W	5000K	80+	45.9"	70K	120-277	0-10V Dimming	8 Lamp T5 HO	3	✓
09591	LLH-3C-50K-V	4'	29,213	223W	5000K	80+	45.9"	70K	347-480	0-10V Dimming	8 Lamp T5 HO	3	✓
09541	LLH-4C-50K-U	4'	34,715	265W	5000K	80+	45.9"	70K	120-277	0-10V Dimming	8 Lamp T5 HO	3	✓
09542	LLH-5C-50K-U	4'	41,920	321W	5000K	80+	45.9"	70K	120-277	0-10V Dimming	8 Lamp T5 HO	3	✓
09592	LLH-5C-50K-V	4'	41,920	321W	5000K	80+	45.9"	70K	347-480	0-10V Dimming	8 Lamp T5 HO	3	✓

### LLH : Linear Highbay (with Occupancy Sensor)

Order Code	Item	Length	Lm	W	CCT	CRI	MOL	Life/Hrs L70	V	Dimming	Replaces Fluor/HID	Photo #	DLC v4.1 Premium
09571	LLH-1C-50K-U-1S	2'	14,410	110W	5000K	80+	32.8"	70K	120-277	0-10V Dimming	HBF 6 Lamp T8 and 4 Lamp T5	2	✓
09572	LLH-2C-50K-U-1S	2'	21,222	162W	5000K	80+	32.8"	70K	120-277	0-10V Dimming	HBF 8 Lamp T8 and 6 Lamp T5 HO	2	✓
09573	LLH-3C-50K-U-1S	4'	29,213	223W	5000K	80+	45.9"	70K	120-277	0-10V Dimming	8 Lamp T5 HO	3	✓
09552	LLH-4C-U-1S	4'	26,730	265W	5000K	80+	45.9"	70K	120-277	0-10V Dimming	8 Lamp T5 HO	3	✓

### LLH : Accessories (Sold Separately)

09226	LLH-CHAIN	Mounting Chain for LLH, 105 meters (1 pair)	09227	LLH-PENDANT BOX	Pendant Box for LLH, 3/4 inch NPT
09336	LLH-CL-2x1	Clear Lens for LLH-2C-U, LLH-1C-50K-U	09230	LLH-V HOOK-1	V-Hook for LLH-2C-U, LLH-4C-U, LLH-1C-50K-U, LLH-3C-50K-U
09337	LLH-CL-2x1.5	Clear Lens for LLH-3C-U, LLH-2C-50K-U	09229	LLH-V HOOK-1.5	V-Hook for LLH-3C-U, LLH-2C-50K-U, LLH-4C-50K-U, LLH-5C-50K-U
09338	LLH-CL-4x1	Clear Lens for LLH-4C-U, LLH-3C-50K-U	09222	LLH-WG-2x1	Wireguard for LLH-2C-U, LLH-1C-50K-U
09700	LLH-CL-4x1.5	Clear Lens for LLH-4C-50K-U, LLH-5C-50K-U	09223	LLH-WG-2x1.5	Wireguard for LLH-3C-U, LLH-2C-50K-U
09339	LLH-FL-2x1	Frosted Lens for LLH-2C-U, LLH-1C-50K-U	09224	LLH-WG-4x1	Wireguard for LLH-4C-U, LLH-3C-50K-U
09340	LLH-FL-2x1.5	Frosted Lens for LLH-3C-U, LLH-2C-50K-U	09702	LLH-WG-4x1.5	Wire Guard for LLH-4C-50K-U, LLH-5C-50K-U
09341	LLH-FL-4x1	Frosted Lens for LLH-4C-U, LLH-3C-50K-U	08845	LLH-YTK	Y-Toggle Cable - 10 ft (one only - 2 needed per order)
09701	LLH-FL-4x1.5	Frosted Lens for LLH-4C-50K-U, LLH-5C-50K-U			

### LLH : Replacement Driver Requirements

Fixture	Required Driver(s)
LLH-2C-U	One VPL100-240
LLH-3C-U	One VPL100-240 and one VPL50-115MVHDA-PD-1C
LLH-4C-U	Two VPL100-240





## Linear Fixtures

- Cost-effective, energy-efficient replacements for less efficient fluorescent fixtures
- Durable and stylish construction
- Available in 4000K color temperature
- Dimmable
- 5 year system warranty

### LLW : Linear Wrap


Order Code	Item	Size	Lm	W	V	Dimming	CCT	CRI	Life/Hrs L70	Photo #	DLC v4.1 Premium
09704	LLW-4CP-40K-U	4'	4,420	36W	120-277V	0-10V	4000K	80+	50K	1	✓
09705	LLW-5CP-40K-U	4'	5,200	42W	120-277V	0-10V	4000K	80+	50K	1	✓
09425	LLW-3C-40K-U	4'	4,160	32W	120-277V	0-10V	4000K	80+	50K	1	✓
09426	LLW-4C-40K-U	4'	4,608	36W	120-277V	0-10V	4000K	80+	50K	1	✓
09427	LLW-5C-40K-U	4'	5,334	42W	120-277V	0-10V	4000K	80+	50K	1	✓

### STR : Linear Strip

Order Code	Item	Size	Lm	W	V	Dimming	CCT	CRI	Life/Hrs L70	Photo #	DLC v4.1 Premium
09534	STR-2C-40K-U	4'	3,013	23W	120-277V	0-10V	4000K	80+	50K	2	✓
09535	STR-3C-40K-U	4'	4,224	32W	120-277V	0-10V	4000K	80+	50K	2	✓
09536	STR-4C-40K-U	4'	6,026	46W	120-277V	0-10V	4000K	80+	50K	2	✓

### VTS : Vapor Tight Surface

Order Code	Item	Lm	W	V	Dimming	CCT	CRI	MOL	Life/Hrs L70	Replaces Fluor	Photo #	DLC v4.1 Premium
09712	VTS-5CP-40K-U	5,200	40W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F32T8	3	✓
09713	VTS-7CP-40K-U	6,760	52W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F54T5HO	3	✓
09714	VTS-4CS-40K-U	4,400	40W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F32T8	3	✓
09715	VTS-7CS-40K-U	7,150	65W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F54T5HO	3	✓
09197	VTS-1C-U	4,980	42W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F32T8	3	✓
09198	VTS-2C-U	7,198	60W	120-277V	0-10V	4000K	80+	50.24"	50K	(2) F54T5HO	3	✓

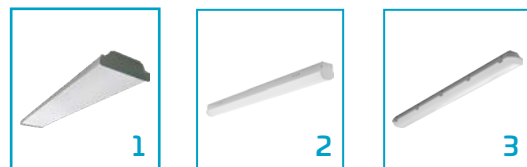

## Troffer & Panel Fixtures


- Alternative LED solution to traditional fluorescent troffers
- Ultra-high-efficiency LEDs provide superior performance
- Choice of 3500K, 4000K, or 5000K
- Available in 2'x2' and 2'x4'
- Standard 0-10V dimming driver
- Universal input voltage (120-277V)
- 5 year system warranty

### VOL : Volumetric Troffer

Order Code	Item	Size	Lm	W	CCT	CRI	Life/Hrs L70	V	Dimming	Replaces Fluor	Photo #	DLC v4.1 Premium
09706	VOL22-3CP-35K-U	2x2	3,250	26W	3500K	80+	50K	120-277V	0-10V Dimming		1	✓
09707	VOL22-3CP-40K-U	2x2	3,250	26W	4000K	80+	50K	120-277V	0-10V Dimming		1	✓
09708	VOL22-3CP-50K-U	2x2	3,250	26W	5000K	80+	50K	120-277V	0-10V Dimming		1	✓
09709	VOL24-5CP-35K-U	2x4	5,796	46W	3500K	80+	50K	120-277V	0-10V Dimming		2	✓
09710	VOL24-5CP-40K-U	2x4	5,796	46W	4000K	80+	50K	120-277V	0-10V Dimming		2	✓
09711	VOL24-5CP-50K-U	2x4	5,796	46W	5000K	80+	50K	120-277V	0-10V Dimming		2	✓
09469	VOL22-3C-35K-U	2x2	3,198	26W	3500K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	1	✓
09470	VOL22-3C-40K-U	2x2	3,275	26W	4000K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	1	✓
09491	VOL22-3C-50K-U	2x2	3,300	26W	5000K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	1	✓
09471	VOL24-5C-35K-U	2x4	5,880	48W	3500K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	2	✓
09472	VOL24-5C-40K-U	2x4	5,970	48W	4000K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	2	✓
09492	VOL24-5C-50K-U	2x4	6,115	48W	5000K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	2	✓

### SLM : Slim Panel

Order Code	Item	Size	Lm	W	CCT	CRI	Life/Hrs L70	V	Dimming	Replaces Fluor	Photo #	DLC v4.1 Premium
09485	SLM22-3C-35K-U	2'x2'	3,000	30W	3500K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	3	✓
09486	SLM22-3C-40K-U	2'x2'	3,000	30W	4000K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	3	✓
09487	SLM22-3C-50K-U	2'x2'	3,000	30W	5000K	80+	50K	120-277V	0-10V Dimming	3x 17WT8, 2U31T8	3	✓
09488	SLM24-5C-35K-U	2'x4'	4,000	40W	3500K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	4	✓
09489	SLM24-5C-40K-U	2'x4'	4,000	40W	4000K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	4	✓
09490	SLM24-5C-50K-U	2'x4'	4,000	40W	5000K	80+	50K	120-277V	0-10V Dimming	2x 32T8, 3x 32T8	4	✓

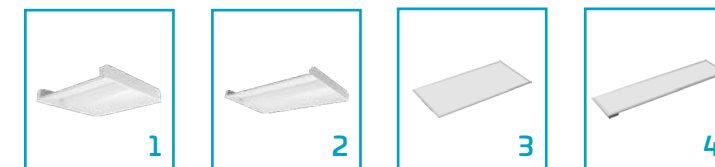



## Downlight Fixtures

- Ultra-efficient LED downlight kits designed to retrofit into existing incandescent recessed downlights
- Integrated LEDs reduce energy consumption up to 80%
- Fits many popular recessed downlight fixtures
- Lasts up to 30x longer than incandescent
- Choice of soft white, warm white and cool white CCT
- Instant-on, no warmup time
- 90 CRI versions available

### AK : Adjustable Neck Downlight (Sold in 2-Packs)

Order Code	Item	Size	Lm	W	V	Bm	CCT	CRI	Base	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09524	AK4-8.5W827-DIM-G7 2PK	4"	500	8.5W	120	115°	2700K	80+	E26	25K	50W BR20	1	☑	★
09525	AK6-12W827-DIM-G7 2PK	5 1/2"	800	12W	120	110°	2700K	80+	E26	25K	65W BR30	1	☑	★

### CDR : Commercial Downlight : Dimmable

Order Code	Item	Size	Lm	W	MOL	CCT	CRI	Notes	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09234	CDR-3C-830K-U	6"	2,200	25W	5.39"	3000K	80+	6.1"-6.9" Aperture	40K	(2) 18W CFL	2	☑	★
09235	CDR-3C-835K-U	6"	2,200	25W	5.39"	3500K	80+	6.1"-6.9" Aperture	40K	(2) 18W CFL	2	☑	★
09236	CDR-3C-840K-U	6"	2,200	25W	5.39"	4000K	80+	6.1"-6.9" Aperture	40K	(2) 18W CFL	2	☑	★
09237	CDR-4C-830K-U	8"	3,000	35W	5.9"	3000K	80+	7.8"-8.6" Aperture	40K	(2) 26W CFL	2	☑	★
09238	CDR-4C-835K-U	8"	3,000	35W	5.9"	3500K	80+	7.8"-8.6" Aperture	40K	(2) 26W CFL	2	☑	★
09239	CDR-4C-840K-U	8"	3,000	35W	5.9"	4000K	80+	7.8"-8.6" Aperture	40K	(2) 26W CFL	2	☑	★
09240	CDR-5C-830K-U	10"	4,200	50W	6.5"	3000K	80+	9.4"-10.2" Aperture	40K	(2) 42W CFL	2	☑	★
09241	CDR-5C-835K-U	10"	4,200	50W	6.5"	3500K	80+	9.4"-10.2" Aperture	40K	(2) 42W CFL	2	☑	★
09242	CDR-5C-840K-U	10"	4,200	50W	6.5"	4000K	80+	9.4"-10.2" Aperture	40K	(2) 42W CFL	2	☑	★

### DSK : Slim Disk Downlight : Dimmable

Order Code	Item	Size	Lm	W	CCT	CRI	V	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09518	DSK-11W927-DIM-G7	5"	650	10.5W	2700K	90	120V	50K	50W BR20	3	☑	★
09519	DSK-11W930-DIM-G7	5"	650	10.5W	3000K	90	120V	50K	50W BR20	3	☑	★
09520	DSK-11W940-DIM-G7	5"	650	10.5W	4000K	90	120V	50K	50W BR20	3	☑	★
09521	DSK-15W927-DIM-G7	7"	850	15W	2700K	90	120V	50K	65W BR30	3	☑	★

Continued on next page >>>



### DSK : Slim Disk Downlight : Dimmable (Continued)

Order Code	Item	Size	Lm	W	CCT	CRI	V	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09522	DSK-15W930-DIM-G7	7"	850	15W	3000K	90	120V	50K	65W BR30	3	☑	★
09523	DSK-15W940-DIM-G7	7"	850	15W	4000K	90	120V	50K	65W BR30	3	☑	★

### 4" Downlight Kit : Dimmable

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Replaces	Photo #	Wet Location Rated	ENERGY STAR
09677	LED-DK4-9W927-DIM-G7	600	9W	2700K	90	5.4"	35K	65W BR	4	☑	★
09678	LED-DK4-9W930-DIM-G7	600	9W	3000K	90	5.4"	35K	65W BR	4	☑	★
09679	LED-DK4-9W940-DIM-G7	600	9W	4000K	90	5.4"	35K	65W BR	4	☑	★
09680	LED-DK4-9W950-DIM-G7	600	9W	5000K	90	5.4"	35K	65W BR	4	☑	★
09365	LED-DK4-10W827-DIM-G5†	650	10W	2700K	80+	5.4"	35K	65W BR	4	☑	★
09077	LED-DK4-10W830-DIM-G5†	650	10W	3000K	80+	5.4"	35K	65W BR	4	☑	★
09078	LED-DK4-10W840-DIM-G5†	650	10W	4000K	80+	5.4"	35K	65W BR	4	☑	★

### 4" Rotatable Eye : Dimmable : Damp Location

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09083	LED-DK4RT-11W830-DIM-G5	650	11W	3000K	80+	5.14"	35K	65W BR	5	☑	★
09084	LED-DK4RT-11W840-DIM-G5	650	11W	4000K	80+	5.14"	35K	65W BR	5	☑	★

### 6" Downlight Kit : Dimmable

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Replaces	Photo #	Wet Location Rated	ENERGY STAR
09681	LED-DK6-11W927-DIM-G7	700	11W	2700K	90	7.5"	35K	65W BR	6	☑	★
09682	LED-DK6-11W930-DIM-G7	700	11W	3000K	90	7.5"	35K	65W BR	6	☑	★
09683	LED-DK6-11W940-DIM-G7	700	11W	4000K	90	7.5"	35K	65W BR	6	☑	★
09684	LED-DK6-11W950-DIM-G7	700	11W	5000K	90	7.5"	35K	65W BR	6	☑	★
09685	LED-DK6-15W927-DIM-G7	1100	15W	2700K	90	7.5"	35K	65W BR	6	☑	★
09686	LED-DK6-15W930-DIM-G7	1100	15W	3000K	90	7.5"	35K	65W BR	6	☑	★
09687	LED-DK6-15W940-DIM-G7	1100	15W	4000K	90	7.5"	35K	65W BR	6	☑	★
09688	LED-DK6-15W950-DIM-G7	1100	15W	5000K	90	7.5"	35K	65W BR	6	☑	★
09327	LED-DK6-15W930-DIM-G5	900	15W	3000K	90	7.5"	35K	65W BR	6	☑	★
09366	LED-DK6-10W827-DIM-G5†	750	10W	2700K	80+	7.5"	35K	65W BR	6	☑	★
09079	LED-DK6-10W830-DIM-G5†	750	10W	3000K	80+	7.5"	35K	65W BR	6	☑	★
09080	LED-DK6-10W840-DIM-G5†	750	10W	4000K	80+	7.5"	35K	65W BR	6	☑	★
09367	LED-DK6-17W827-DIM-G5†	1,200	17W	2700K	80+	7.5"	35K	90W BR	6	☑	★
09081	LED-DK6-17W830-DIM-G5†	1,200	17W	3000K	80+	7.5"	35K	90W BR	6	☑	★
09082	LED-DK6-17W840-DIM-G5†	1,200	17W	4000K	80+	7.5"	35K	90W BR	6	☑	★

### 6" Rotatable Eye : Dimmable : Damp Location

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Replaces	Photo #	Damp Location Rated	ENERGY STAR
09085	LED-DK6RT-11W830-DIM-G5	750	11W	3000K	80+	7.28"	35K	65W BR	7	☑	★
09086	LED-DK6RT-11W840-DIM-G5	750	11W	4000K	80+	7.28"	35K	65W BR	7	☑	★







## Outdoor Fixtures

- Cost-effective, solid-state LED solutions for flood and area lighting
- Replaces traditional HID or quartz halogen flood lights
- Instant-on with no warmup
- 5 year system warranty
- Long 50K+ hour life reduces maintenance costs

### AFL : Area Flood Light

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #	DLC v4.1
08985	AFL-3C-W-U	14,850	148W	5000K	120-277V	70+	207"	60K	NEMA 7x7	150-250W	1	✓
08986	AFL-5C-W-U	20,080	236W	5000K	120-277V	70+	207"	60K	NEMA 7x7	250-400W	2	✓

### FLM : Flood Light Mini

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Notes	Replaces Halogen	Photo #	DLC v4.1
08987	FLM-1C-N-U	1,153	15W	5000K	70+	5.1"	50K	Narrow 75°	150W	3	
08988	FLM-1C-U	1,221	15W	5000K	70+	5.1"	50K	Wide 115°	150W	4	
09093	FLM-2C-N-LV1	1,860	25W	5000K	70+	6.5"	50K	Narrow 75°	250W	5	
08990	FLM-2C-N-U	1,860	25W	5000K	70+	6.5"	50K	Narrow 75°	250W	5	
08991	FLM-2C-U	2,207	25W	5000K	70+	6.5"	50K	Wide 115°	250W	6	✓
09094	FLM-3C-N-LV1	3,634	45W	5000K	70+	6.3"	50K	Narrow 75°	300W	7	



5 YEAR WARRANTY

cUL US LISTED



### ASL : Area Site Lighter

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #	DLC v4.1
09273	ASL-3C-40K-U	12,442	95W	4000K	70+	16.2"	60K	Type III, V	250W	9	✓
09275	ASL-5C-40K-U	17,737	144W	4000K	70+	16.2"	60K	Type III, V	400W	9	✓
09274	ASL-3C-50K-U	12,442	95W	5000K	70+	16.2"	60K	Type III, V	250W	9	✓
09276	ASL-5C-50K-U	17,737	144W	5000K	70+	16.2"	60K	Type III, V	400W	9	✓

### FLJ : Flood Light Mini

Order Code	Item	Lm	W	CCT	CRI	V	Life/Hrs L70	Mount	Replaces Halogen	Photo #	DLC v4.1
09611	FLJ-1C-50K-Y-U	1,350	12W	5000K	80+	120-277V	50K	Yoke	150W	13	✓
09612	FLJ-1C-50K-K-U	1,350	12W	5000K	80+	120-277V	50K	Knuckle	150W	14	✓
09615	FLJ-3C-50K-Y-U	3,200	30W	5000K	80+	120-277V	50K	Yoke	300W	15	✓
09623	FLJ-3C-50K-K-U	3,200	30W	5000K	80+	120-277V	50K	Knuckle	300W	16	✓
09616	FLJ-5C-50K-Y-U	5,400	50W	5000K	80+	120-277V	50K	Yoke	300W	17	✓
09617	FLJ-5C-50K-K-U	5,400	50W	5000K	80+	120-277V	50K	Knuckle	300W	18	✓
09618	FLJ-1C-30K-Y-U	1,350	12W	3000K	80+	120-277V	50K	Yoke	150W	13	✓
09619	FLJ-1C-30K-K-U	1,350	12W	3000K	80+	120-277V	50K	Knuckle	150W	14	✓
09613	FLJ-3C-30K-Y-U	3,200	30W	3000K	80+	120-277V	50K	Yoke	300W	15	✓
09614	FLJ-3C-30K-K-U	3,200	30W	3000K	80+	120-277V	50K	Knuckle	300W	16	✓
09620	FLJ-5C-30K-Y-U	5,400	50W	3000K	80+	120-277V	50K	Yoke	300W	17	✓
09621	FLJ-5C-30K-K-U	5,400	50W	3000K	80+	120-277V	50K	Knuckle	300W	18	✓







## Wallpack Fixtures

- Economical and energy-efficient solutions for general purpose wall mount lighting
- Durable, impact-resistant construction
- Easy to install
- 5 year system warranty

### DTD : Dusk-To-Dawn

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #	DLC v4.1
08588	DTD-1C-U	3,194	42W	5000K	120-277V	70+	13.9"	50K	w/ 120-277V photocell	50-175W	1	
08980	DTD-2C-U	5,441	58W	5000K	120-277V	70+	13.9"	50K	w/ 120-277V photocell	175-250W	1	✓
09579	DTD-2C-50K-U	5,000	50W	5000K	100-277V	80+	13.9"	50K	w/ 100-277V photocell	175-250W	1	✓

### DTD : Accessories (Sold Separately)

08702	DTD-ARM	21" conduit arm
08906	PCTLU	Photocontrol 122-277V

### WFA : Wallpack Flood Arch

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #	DLC v4.1
08597	WFAM-1C-U	1,910	22W	5000K	70+	8"	50K	Medium	70-150W	2	✓
08598	WFAM-2C-U	3,158	40W	5000K	70+	8"	50K	Medium	175-250W	2	
08599	WFAL-3C-U	7,970	83W	5000K	70+	12.8"	50K	Large	400W	3	

### WFA : Accessories (Sold Separately)

08704	WFAM-KN	1/2" Knuckle	08738	PCB1	Photocontrol 120V
08703	WFAM-SF	2-3/8" Slipfitter	08739	PCB2	Photocontrol 277V
08705	WFAM-UT	U-Bracket	08867	LP1020-36-C0480	Driver for WFAM-1C-U
08706	WFAL-SF	2-3/8" Slipfitter	08863	LP1040-36-C0950	Driver for WFAM-2C-U
08707	WFAL-UT	U-Bracket			

### WMC : Wallpack Cube

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Finish	Photo #	DLC v4.1
09580	WMC-2C-50K-U	1,900	20W	5000K	120-277V	80+	11.01"	50K	Bronze	4	✓
09581	WMC-3C-50K-U	2,800	30W	5000K	120-277V	80+	11.01"	50K	Bronze	4	✓



5 YEAR WARRANTY

UL US LISTED



### WMG : Wallpack Glass

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Finish	Photo #	DLC v4.1
09574	WMG-1C-50K-U	2,750	30W	5000K	120-277V	70+	8.54"	50K	Bronze	5	✓
09575	WMG-2C-50K-U	4,800	50W	5000K	120-277V	70+	9.29"	50K	Bronze	6	✓
09576	WMG-3C-50K-U	5,300	60W	5000K	120-277V	70+	9.29"	50K	Bronze	6	✓
09577	WMG-4C-50K-U	7,500	80W	5000K	120-277V	70+	9.29"	50K	Bronze	6	✓
09578	WMG-5C-50K-U	13,000	120W	5000K	100-277V	70+	9.29"	50K	Bronze	6	✓

### WPC : Wallpack Cube

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #
08873	WPC-1C-120	770	14W	5000K	120V only	70+	11.02"	50K	w/ 120V photocell	50W	4
09424	WPC-2C-120	1,800	20W	5000K	120V only	70+	11.02"	50K	w/ 120V photocell	50W-70W	7

### WPC : Accessories (Sold Separately)

08864	LP1013-36-C0300	Driver for WPC-1C-120
-------	-----------------	-----------------------

### WPG : Wallpack Glass

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #
08981	WPGS-1C-U	2,598	31W	5000K	70+	9.45"	50K	Small	50-175W	8
09663	WPGS-1C-U-B	3,465	30W	5000K	70+	9.45"	50K	Small	50-175W	8
08590	WPG-1C-U	3,400	37W	5000K	70+	7.13"	50K	Medium	175-250W	9
09664	WPG-1C-U-B	4,553	40W	5000K	70+	7.13"	50K	Medium	175-250W	9
08591	WPG-2C-U	5,600	55W	5000K	70+	7.13"	50K	Medium	250-400W	9
09665	WPG-2C-U-B	8,212	75W	5000K	70+	7.13"	50K	Medium	250-400W	9
08982	WPLG-1C-U	9,795	87W	5000K	70+	9.37"	50K	Large	400W	10
09410	WPLG-1C-U-4K	9,795	87W	4000K	70+	9.37"	50K	Large	400W	10

### WPG : Accessories (Sold Separately)

08738	PCB1	Photocontrol 120V	08866	LP1040-36-C0700	Driver for WPG-2C-U
08739	PCB2	Photocontrol 277V	08865	LP1040-36-C0900	Driver for WPG-1C-U
08746	WP-347T	347V Wallpack Step Down Transformer			

### WPT : Wallpack Trapezoid

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Replaces HID	Photo #
08595	WPT-1C-U	2,998	37W	5000K	120-277V	70+	9.25"	50K	175-250W	11
08596	WPT-2C-U	6,449	75W	5000K	120-277V	70+	9.25"	50K	250-400W	11

### WPT : Accessories (Sold Separately)


08738	PCB1	Photocontrol 120V	08746	WP-347T	347V Wallpack Step Down Transformer
08739	PCB2	Photocontrol 277V	08865	LP1040-36-C0900	Driver for WPT-1C-U and WPT-2C-U

### WPW : Wallpack Wedge

Order Code	Item	Lm	W	CCT	V	CRI	MOL	Life/Hrs L70	Notes	Replaces HID	Photo #
08589	WPW-1C-120	828	11W	5000K	120V only	70+	7.08"	50K	w/ 120V photocell	60W	12

### WPW : Accessories (Sold Separately)

08864	LP1013-36-C0300	Driver for WPW-1C-120
-------	-----------------	-----------------------

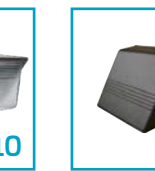



## Canopy Fixtures

- Cost-effective, solid-state solutions for highbay applications
- Replaces high-watt HID fixtures and/or multi-lamp fluorescent luminaires
- Available in round and linear configurations
- 5 year limited warranty

### SCSS : Surface Canopy Square, Small/Shallow

Order Code	Item	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Size	Replaces HID	Photo #	DLC v4.1
08787	SCSS-1C-U	4,803	40W	5000K	70+	3.75"	50K	10.3"	50-175W	1	✓
09004	SCSS-2C-U	6,375	58W	5100K	70+	3.75"	50K	10.3"	175-250W	1	✓
09448	SCSS-3C-50K-U	9,778	86W	5000K	70+	3.75"	50K	14.0"	150W	2	✓
09449	SCSS-4C-50K-U	12,695	117W	5000K	70+	3.75"	50K	14.0"	250W	2	✓

#### SCSS : Accessories (Sold Separately)

08738	PCB1	Photocontrol 120V
08739	PCB2	Photocontrol 277V

### SCSM/L : Surface Canopy Square, Medium/Large

Order Code	Item	Size	Lm	W	CCT	CRI	MOL	Life/Hrs L70	Replaces HID	Photo #	DLC v4.1
09001	SCSM-1C-U	Medium	2,322	22W	5000K	70+	7.1"	50K	50-100W	3	
09008	SCSM-1C-347V	Medium	2,322	22W	5000K	70+	7.1"	50K	50-100W	3	✓
09002	SCSL-1C-U	Large	3,906	40W	5000K	70+	8.9"	50K	50-175W	4	✓
09006	SCSL-1C-347V	Large	3,906	40W	5000K	70+	8.9"	50K	50-175W	4	✓
09003	SCSL-2C-U	Large	4,285	55W	5000K	70+	8.9"	50K	250-400W	4	
09007	SCSL-2C-347V	Large	4,285	55W	5000K	70+	8.9"	50K	250-400W	4	

#### SCSM/L : Accessories (Sold Separately)

08738	PCB1	Photocontrol 120V	08863	LP1040-36-C0950	Driver for SCSL-1C-U
08739	PCB2	Photocontrol 277V	09335	SCSL-LENS	Replacement Lens



5 YEAR WARRANTY

cUL US LISTED



### SCRS : Surface Canopy Round, Shallow

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	Size	Replaces HID	Photo #	DLC v4.1
09422	SCRS-2C-U	3,843	41W	5000K	70+	50K	11"	50-175W	5	✓
09423	SCRS-3C-U	5,770	57W	5000K	70+	50K	11"	175-250W	5	✓

#### SCRS : Accessories (Sold Separately)

08738	PCB1	Photocontrol 120V
08739	PCB2	Photocontrol 277V

### SCST : Slim Canopy

Order Code	Item	Lm	W	CCT	CRI	Life/Hrs L70	V	Replaces HID	Photo #	DLC v4.1
09675	SCST-4C-50K-U	12,955	120W	5000K	70+	60K	100-277V	400W MH	6	✓



## Miniature LED

- 30,000 hour rated life
- Low power consumption and high brightness
- Direct replacement for standard incandescent lamps
- Available in blister pack, two per card
- Energy efficient: costs less than other alternatives to operate over the life of the lamp
- Extreme long life: less frequent re-lamping reduces maintenance costs

Order Code	Item	W	Life/ Hrs	Base		Replaces Incandescent	Photo #
02678	LED-120-MB-G	110-130VAC	T-3/4	BA9s	Green	120MB, 120MB-6, 130MB, 8-3995, 949, 967	1
02679	LED-120-MB-R	110-130VAC	T-3/4	BA9s	Red	120MB, 120MB-6, 130MB, 8-3995, 949, 967	1
02681	LED-120-MB-W	110-130VAC	T-3/4	BA9s	White	120MB, 120MB-6, 130MB, 8-3995, 949, 967	1
02682	LED-120-MB-Y	110-130VAC	T-3/4	BA9s	Yellow	120MB, 120MB-6, 130MB, 8-3995, 949, 967	1
02683	LED-120-PSB-G	110-130VAC	T-2	T55	Green	120PSB5, 120PSB-Neon	2
02684	LED-120-PSB-R	110-130VAC	T-2	T55	Red	120PSB5, 120PSB-Neon	2
02685	LED-120-PSB-W	110-130VAC	T-2	T55	White	120PSB5, 120PSB-Neon	2
02686	LED-120-PSB-Y	110-130VAC	T-2	T55	Yellow	120PSB5, 120PSB-Neon	2
05379	LED-12-DCBAY-W	12VAC/DC	S-8	BAY15d	White	DC Index Bayonet Base 12V S8 Lamps	3
05385	LED-12-Festoon-W	12VAC/DC	Festoon 10mm	SV8.5mm	White	10 x 44 Xenon Festoons	4
05394	LED-12-SCBAY-W	12VAC/DC	S-8	BA15s	White	SC Bayonet Base 12V S8 Lamps	5
02687	LED-14-BA9S-G	14VAC/DC	T-3/4	BA9s	Green	756, 1813, 1815, 1816, 1889, 1891, 1892, 1893	1
02688	LED-14-BA9S-R	14VAC/DC	T-3/4	BA9s	Red	756, 1813, 1815, 1816, 1889, 1891, 1892, 1893	1
02689	LED-14-BA9S-W	14VAC/DC	T-3/4	BA9s	White	756, 1813, 1815, 1816, 1889, 1891, 1892, 1893	1
02691	LED-14-T1.75 Wedge-W	14VAC/DC	T-3/4	W2.1x4.6d	White	18, 37, 70, 73, 74	6
00345	LED-194-W	14VAC/DC	T-3/4	W2.1x9.5d	White	T3-1/4 Min Wedge Based Lamps 12/14V	7
02693	LED-24-BA9S-G	24-28VAC/DC	T-3/4	BA9s	Green	24MB, 28MB, 313, 757, 1818, 1819, 1820, 1829, 1843, 1864, 1873	1
02694	LED-24-BA9S-R	24-28VAC/DC	T-3/4	BA9s	Red	24MB, 28MB, 313, 757, 1818, 1819, 1820, 1829, 1843, 1864, 1873	1
02695	LED-24-BA9S-W	24-28VAC/DC	T-3/4	BA9s	White	24MB, 28MB, 313, 757, 1818, 1819, 1820, 1843, 1829, 1864, 1873	1
02696	LED-24-BA9S-Y	24-28VAC/DC	T-3/4	BA9s	Yellow	24MB, 28MB, 313, 757, 1818, 1819, 1820, 1843, 1829, 1864, 1873	1
05377	LED-24-Festoon-W	24VDC	Festoon 10mm	SV8.5mm	White	10 x 44 Xenon Festoons	4
02698	LED-24-MF-W	24-28VAC/DC	T-1/4	SX6s	White	327, 376, 385, 387, 7341	8
02702	LED-24-MG-W	24-28VAC/DC	T-1/4	S5.7s	White	276, 334, 388	9
02704	LED-24-PSB-G	24-28VAC/DC	T-2	T55	Green	24PSB5, 28PSB5	2
02705	LED-24-PSB-R	24-28VAC/DC	T-2	T55	Red	24PSB5, 28PSB5	2
02706	LED-24-PSB-W	24-28VAC/DC	T-2	T55	White	24PSB5, 28PSB5	2
02707	LED-24-PSB-Y	24-28VAC/DC	T-2	T55	Yellow	24PSB5, 28PSB5	2
02711	LED-24-T1.75 Wedge-W	24-28VAC/DC	T-1/4	W2.1x4.6d	White	17, 85	6
05742	LED-6-BA9S-W	6VAC/DC	T-3/4	BA9s	White	6MB, 44, 47, 238, 755, 1810, 1847, 1866	1



## Guaranteed sale!

Move products out the door with Eiko's wire rack displays! Available in three recommended layouts and interchangeable header cards, you will have the option to pick and choose from our broad selection of LitespanLED® replacement lamps and fixtures – all guaranteed to facilitate sales!

### LED Lamp and Fixture Merchandisers

Order Code	Item	Lamp Option	Fixture Option	Lamp & Fixture Option	Photo(s)
60424	LED9WA19/OMN/827K-DIM-G7 2PK	2		2	
60425	LED9WA19/OMN/830K-DIM-G7 2PK	2		2	
60426	LED9WA19/OMN/840K-DIM-G7 2PK	2		2	
60433	LED15WA21/OMN/827K-DIM-G7 2PK	2			
60434	LED15WA21/OMN/830K-DIM-G7 2PK	2			
60435	LED15WA21/OMN/840K-DIM-G7 2PK	2			
60403	LED9WA19/ADV/840K-DIM-G7 2PK	2			
08936	LED11WBR30/827K-DIM-G5	4		6	
08937	LED11WBR30/830K-DIM-G5	4		6	
09156	LED11WPAR30/FL/830K-DIM-G6	4			
09185	LED7WPAR20/FL/830K-DIM-G6	8			
09374	LED27WPT4OKMED-G7	4		4	
09387	LED54WPT4OKMOG-G7	4		4	
09383	LED45WPT4OKMOG-G7	4			
08729	LED5WB11/E12/827-DIM-G5	12			
08730	LED5WB11/E12/830-DIM-G5	12			
09077	LED-DK4-10W830-DIM-G5	8			
09078	LED-DK4-10W840-DIM-G5	8			
09081	LED-DK6-17W830-DIM-G5	8			
09082	LED-DK6-17W840-DIM-G5	8			
08590	WMG-1C-50K-U		6	4	
08591	WMG-2C-50K-U		6		
08588	DTD-2C-U		6	4	
08787	SCSS-1C-U		4		
08873	WMC-2C-50K-U		2		
08991	FLM-2C-U		4		



# EiKO USA: Terms, Conditions, & Shipping Procedures

**Effective:** March 1, 2017.

Supersedes all past terms and conditions of Price books and Sales Supplements.

**Prices:** As Shown and subject to change without notice.

**Distributor Status:** Distributors must purchase a minimum of \$3,500 annually in order to maintain distributor status.

**Small Order Charge:** Orders under \$250 will be assessed a \$15 small order charge (SOC).

**Payment Terms:** Net 30 days, from date of shipment as it appears on invoice. Postmark date on envelope will determine if payment has been made within terms. All orders received are subject to review and approval by our credit department. Orders received from customers with delinquent accounts may be subject to shipping delays, so please keep your account current.

**Freight:** NOTE: SoLux and EiKO products may be combined to meet prepaid freight requirements. EiKO Global, LLC will select the carrier of its choice.

1. All orders of \$1,000 or more will be shipped FREE FREIGHT F.O.B. destination via regular ground UPS, FedEx or USPS within the continental United States. Orders less than \$1,000 will be shipped F.O.B. origin.
2. UPS Second Day Air Blue - At the request of the distributor, orders will be billed at the UPS Second Day Air Rate.
3. UPS Next Day Air Red Label - At the request of the distributors, orders will be billed at the UPS Red Label Air rate.
4. Shipments made at the choice of the distributors, other than above, will be shipped F.O.B. shipping point.
5. Additional charges will apply for residential delivery.
6. Alaska, Hawaii and Puerto Rico - Orders of \$1,000 or more will be shipped free freight F.O.B. to a freight forwarder.
7. EiKO will no longer ship freight collect using the customer's account number.

We will cover the above items under normal Continental United States Policy. Therefore, you can achieve free freight to a border destination and then pick up the expense of forwarding the freight to your destination in Alaska, Hawaii or Puerto Rico. As an example, if you are a customer in Hawaii, you can have the goods for orders over \$1,000 shipped free freight to a freight forwarder. It would then be your responsibility to cover the freight to Hawaii.

## Return Authorization:

1. You must contact EiKO Global, LLC for authorization to return defective products and shipment errors.
  2. Return authorization will not be issued unless the distributor provides a valid invoice number showing when goods were purchased. A copy of this invoice must be included with the return.
  3. Goods must be an active item and be less than one year old to be eligible for return. Clearance and closeout items are not eligible for return.
  4. Where the request for return is neither defective merchandise nor error made by EiKO Global, LLC, the following policy will apply: A restocking charge of 20% will be charged on all authorized and acceptable goods. If goods are not returned in resalable condition they will be returned to the sender at the expense of the sender and no credit will be issued.
- NOTE: All returns must have a return number on the outside of the box or they will be refused.

**Shipment Discrepancies:** All shipment discrepancies, damage, etc, must be reported within 10 days of the shipment date shown on the invoice.

**General:** We reserve the right to, at any time and without notice, discontinue or substitute brands.

**Minimum Order Requirements for Linear Fluorescent Lamps:** In order to avoid breakage, the minimum order quantity for T8 & T12 linear fluorescent lamps four feet or longer is 360. The minimum order quantity for programmed start T5 linear fluorescent lamps is 100. Mixing SKUs to meet the minimum order is allowed. Orders under \$1,000 will be charged \$70 LTL freight. \$1500 minimum total order required for paid freight when purchasing any 8' T8 products. Product ships on 8' pallet in case quantities only.

**\*Important Note About Minimum Advertised Pricing (MAPP):** In order to avoid predatory pricing and to maintain the integrity of the products, SoLux products purchased through EiKO Global, LLC may not be advertised for sale (Internet, electronic, print media, mailings or otherwise) by you, a sub-distributor or any other agent, below the minimum advertised price established in the current Distributor Net Price Schedule. This minimum advertised price will be known as and referred to as the MAPP price. Failure to comply with MAPP pricing requirements will result in the loss of your access to SoLux products.

**EiKO Global, LLC:** 23220 W. 84<sup>th</sup> St, Shawnee, KS 66227 • Ph: 1.800.852.2217 • F: 1.913.441.6679 • Email: orders@eiko.com

eiko.com

# EiKO Canada: Terms, Conditions, & Shipping Procedures

**Effective:** March 1, 2017.

Supersedes all previously issued copies.

**Ordering:** All orders should be emailed to orderdesk@eiko.com or faxed to EiKO at 1-888-705-1335.

All orders received are subject to review and approval by our credit department.

**Distributor Status:** Distributors must purchase a minimum of \$1500.00 annually to maintain distributor status.

**Prices:** All prices are payable in Canadian funds. Prices are subject to change without notice and do not include applicable taxes. Any applicable taxes will be added to the invoice.

**Minimum Order:** \$75.00 minimum order requirement.

**Payment Terms:** Net 30 Days, from date of shipment as it appears on the invoice. Postmark date on envelope will determine if payment has been made within terms. All payments must be made in Canadian funds and mailed to below. EFT is available upon request.

EiKO Global, LLC (Canada)

81 King Street

Barrie, Ontario, L4N 6B5

**Freight Terms:** All pre-paid orders will be shipped F.O.B. destination via ground service and the carrier will be determined by Eiko Canada Ltd. Orders that do not meet the pre-paid amount will be shipped at customer's expense. At the request and expense of customer, orders can be shipped via air service. At the request of customer, orders can be drop shipped and pre-paid amounts will apply to shipping destination.

F.O.B Barrie, pre-paid as follows (before taxes):

British Columbia	\$1,000.00	New Brunswick	\$1,000.00
Alberta	\$1,000.00	Nova Scotia	\$1,000.00
Saskatchewan	\$1,000.00	Prince Edward Island	\$1,000.00
Manitoba	\$750.00	Newfoundland and Labrador	\$1,500.00
Ontario	\$500.00	Yukon	\$1,500.00
Montreal (Metropolitan Area)	\$500.00	Northwest Territories	\$1,500.00
All other points in Quebec	\$750.00	Nunavut	\$1,500.00

**NOTE:** - Pre-paid freight is \$1,000.00 in Ontario, Quebec and Manitoba when ordering Fluorescent or LED tubes 4 feet or longer.  
- Expedited ground freight is available upon request for Western Canada. Pre-paid freight is \$1500.00.

**Shipment Discrepancies/Damages:** EiKO will credit or replace product found to arrive in damaged or broken condition on all pre-paid freight orders. All shipment discrepancies, damage, etc., must be reported within 10 days of the shipment date shown on the invoice.

**Return Authorizations:** You must contact EiKO within 90 days of delivery for a Return Authorization number. An RA number will only be provided if the customer has a valid invoice showing when the goods were purchased from EiKO. Goods must be an active item and less than one year old to be eligible for return. Clearance and closeout items are not eligible for return. All returns must be shipped pre-paid with a copy of the invoice and RA included. A restocking charge of 25% will be charged on all authorized and acceptable goods. An order of 2 times the return value will be accepted as an offset to the restocking charge. Goods returned not in original packaging and not in resalable condition will be returned to sender, at the expense of the sender, and no credit will be issued.

**General:** EiKO reserves the right to discontinue and substitute brands at any time without notice.

**EiKO Global Canada, LLC:** 81 King St, Barrie, ON L4N 6B5 • Ph: 1.888.410.8151 • F: 1.888.705.1335 • Email: orderdesk@eiko.com

eiko.com

# General Lighting Limited Warranty

EiKO brand lamps are warranted to be free of defective materials and workmanship for the period listed below. EiKO will replace or credit the distributor only for the cost of any lamp that fails under normal operating conditions and the use and operation conditions below due to defective materials or workmanship.

**This warranty is limited to the replacement or credit of the lamp itself. This is buyer's exclusive remedy. Any other warranty, express or implied, including any warranty of merchantability or fitness for a particular purpose, is excluded and disclaimed. EiKO shall not be liable for any special, incidental or consequential damage including labor, loss of use, lost profits or injury to persons or property.**

EiKO reserves the right to examine all lamps prior to the determination of warranty status. All lamps must be retained for warranty claims. The warranty period starts on the date of installation. If the date of installation is unknown or undetermined the warranty period will start at the wholesale purchase date.

Lamp Category	Warranty Period
LitespanLED® Line	60 months
Advantage™ Line	36 months
Metal Halide, High-Pressure Sodium, Mercury Vapor	15 months
Compact Fluorescent	12 months
Self Ballasted Compact Fluorescent	12 months
Linear Fluorescent (below 14 watt)	12 months
Linear Fluorescent (14 watt and above)	24 months
LCD	120 days

Credit is calculated as follows:

Credit (\$) = Invoiced Purchase Price (\$) x Unexpired Original Warranty Period (months)/Warranty Period

**Use and Operating Conditions:** Lamps must be used in UL approved fixtures with UL approved ballasts and installed according to local and national codes and standards. Use of occupancy sensors, dimmers or programmable systems with the lamp may void the warranty.

**HID Lamps:** Warranty is based on 5,000 hours per year maximum operation with a minimum of 8 hours operation per cycle. More frequent cycles will shorten lamp life and may not be covered under this warranty.

**Fluorescent Lamps:** Warranty is based on 4,000 hours per year maximum operation with a minimum of 3 hours operation per cycle. More frequent cycles will shorten lamp life and may not be covered under this warranty.

**Large Lamps:** Warranty is in effect for sales and installations on and after January 1, 2006.

**LED:** Warranty is in effect for sales and installations on and after July 1, 2010.

**LCD:** Warranty is in effect for sales and installations on and after July 1, 2009.



[watch](#) > [like](#) > [follow](#) >



---

23220 W. 84<sup>th</sup> St, Shawnee, KS 66227 · (P) 1.800.852.2217 · (F) 1.800.492.8975

Canada: 81 King St, Barrie, ON L4N 6B5 · (P) 1.888.410.8151 · (F) 1.888.705.1335