

Project		Catalog #		Type	
Prepared by		Notes		Date	



Metalux

FM WR CCT SELECT

LED Low Profile Round Flushmount
Wall or Ceiling Mount

Typical Applications

Bedroom • Closet • Corridor • Stairway • Utility Rooms • Laundry Rooms • Dormitories

Interactive Menu

- Order Information page 2
- Energy and Performance Data page 2
- Product Warranty

Product Certification



Product Features




Top Product Features

- 3 Color Field selectable CCT: 3000K, 4000K and 5000K
- Perfect for utility or laundry rooms, closets, dormitories & more
- ENERGY STAR® rated
- Easy to install. Surface or direct mount to junction box
- 5-year warranty and long life LEDs

Dimensions

Catalog Number	A	B	C	D
FM9WRCCR	10-1/4" [260mm]	3-3/8" [86mm]	8-11/16" [221mm]	11/16" [18mm]
FM11WRCCR	11" [280mm]	3-3/16" [80mm]	9-7/8" [251mm]	5/8" [17mm]
FM15WRCCR	15-1/16" [383mm]	4-1/8" [105mm]	13-1/4" [336mm]	11/16" [18mm]
FM19WRCCR	19" [483mm]	4-5/8" [118mm]	17-9/16" [446mm]	11/16" [18mm]

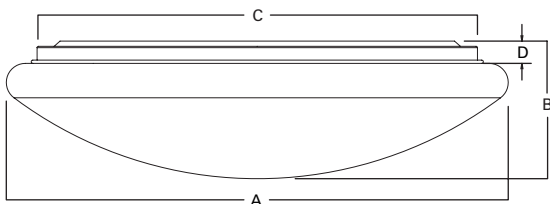

Order Information

Catalog Number	Unit Carton UPC	I2of5	Pallet Qty.
FM9WRCCR	080083845392	10080083845399	96
FM11WRCCR	080083840151	10080083840158	72
FM15WRCCR	080083845378	10080083845375	32
FM19WRCCR	080083845415	10080083845412	24

Product Specifications

Construction

- Die formed post painted white steel housing
- Available sizes: 9", 11", 15" and 19" nominal
- Injection molded acrylic round lens
- Tool-less twist and lock channel groove lens retention design for easy maintenance
- Cam-latch lens retention design (19" FM round only)

Controls

- Standard 120V Dimming drivers
- Compatible with most standard dimmer switches

Electrical

- Selectable switch configuration includes 3000K, 4000K, and 5000K CCT
- 120V, FCC Class B rated, Dimming Driver
- L70 at 50,000 rated life-hours (TM-21), or greater than 43 years at 3 hrs/day
- LEDs are 80 CRI minimum

Shielding

- Round low-profile die formed lens design
- Standard smooth opal whit blend provides even illumination with no pixelization
- Lens provides 360-degrees of light distribution

Installation

- Surface (wall or ceiling) mount capable via junction box
- Includes hardware, cross-bar and wire connectors
- Ambient temperature range: 0°F-122°F

Compliance

- UL/cUL listed for dry location
- Energy Star qualified
- RoHS compliant
- LED complies with IESNA LM-79 and LM-80

Warranty

- Five year warranty

Energy and Performance Data

	Feature	Benefit
Performance	Field Selectable CCT (3000-4000-5000K)	Customize light color to match any space
	Energy Star certification	Eligible for Energy Rebates
	5-year warranty	Certified and guaranteed performance
Construction	Long life LED source, 50K life-hrs.	No costly lamp replacements
	J-Box mountable, Hardware included	Easy to install
	Opal white lens for 360-degree of light	Even illumination and light for safety

Performance Data*

Catalog Number	Lumens	Watts
FM9WRCCR	900	10.6
FM11WRCCR	1100	12.8
FM15WRCCR	1600	22.8
FM19WRCCR	2500	30.5

* Performance is measured at 3000K CCT

Shipping Data

Catalog No.	Individual Wt.	Master Pack	Pallet
FM9	1.2 lbs.	8	96
FM11	2.9 lbs.	4	72
FM15	3.8 lbs.	4	32
FM19	4.9 lbs.	2	24