

 
Condulet® Multi-Gang Device Boxes - Cast Iron or Aluminum

Accessories
see pages 37-45

2F

With and Without Mounting Lugs for
Threaded Rigid and IMC Conduit

FS†



Two Gang Tandem

| Size | Cat. # |
|------|--------|
| 1/2 | FS17 |
| 3/4 | FS27 |


FSC†



Two Gang Tandem

| Size | Cat. # |
|------|--------|
| 1/2 | FSC17 |
| 3/4 | FSC27 |


FSE

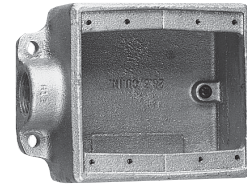

Two Gang

| Size | Cat. # |
|------|--------|
| 3/4 | FSE22 |


FS & FD

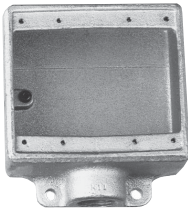

Two Gang

| Size | Cat. # | Cat. # |
|------|--------|--------|
| 1/2 | FS12* | FD12 |
| 3/4 | FS22* | FD22* |
| 1 | FS32 | FD32 |

FSC & FDC

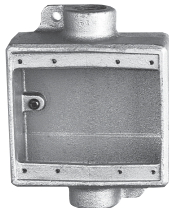

Two Gang


| Size | Cat. # | Cat. # |
|------|--------|---------|
| 1/2 | FSC12 | FDC12 |
| 3/4 | FSC222 | FDC222* |
| 1 | FSC32 | FDC32 |

†Use single gang covers only.

*Available in copper-free aluminum;
add suffix "SA".

Dimensions

In Inches:

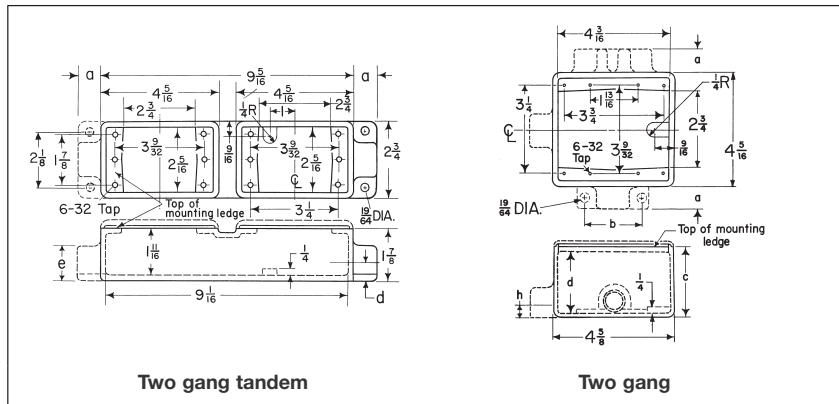

Two gang tandem

| Series | Hub Size | a | b | e |
|--------|----------|-----|-----|-------|
| FS | 1/2 | 7/8 | 5/8 | 1 1/4 |
| | 3/4 | 7/8 | 3/4 | 1 1/2 |

Two gang

| Series | Hub Size | a | b | c | d | h |
|--------|----------|-----|-------|---------|---------|-----|
| FS | 1/2 | 7/8 | 2 1/4 | 1 7/8 | 1 11/16 | 5/8 |
| | 3/4 | 7/8 | 2 1/4 | 1 7/8 | 1 11/16 | 3/4 |
| | 1 | 1 | 2 1/2 | 1 7/8 | 1 11/16 | 7/8 |
| FD | 1/2 | 7/8 | 2 1/4 | 2 11/16 | 2 1/2 | 5/8 |
| | 3/4 | 7/8 | 2 1/4 | 2 11/16 | 2 1/2 | 3/4 |
| | 1 | 1 | 2 1/2 | 2 11/16 | 2 1/2 | 7/8 |

2F

Condulet® Multi-Gang Device Boxes - Cast Iron or Aluminum

Accessories
see pages 37-45

With and Without Mounting Lugs for
Threaded Rigid and IMC Conduit

2F


FSS & FDS



Two Gang

| Size | Cat. # | Cat. # |
|------|--------|--------|
| 3/4 | FSS222 | FDS222 |

FSD

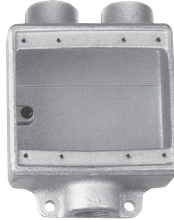


Two Gang

| Size | Cat. # |
|------|---------|
| 3/4 | FSD212* |

*Hubs on 2 hub side are 1/2"


FS & FD

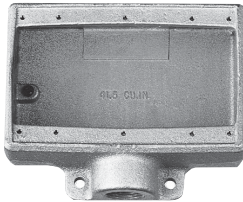

Three Gang

| Size | Cat. # | Cat. # |
|------|--------|--------|
| 3/4 | FS23 | FD23 |
| 1 | FS33 | |

FSS

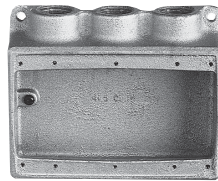


Three Gang

| Size | Cat. # |
|------|--------|
| 3/4 | FSS23 |

Dimensions

In Inches:

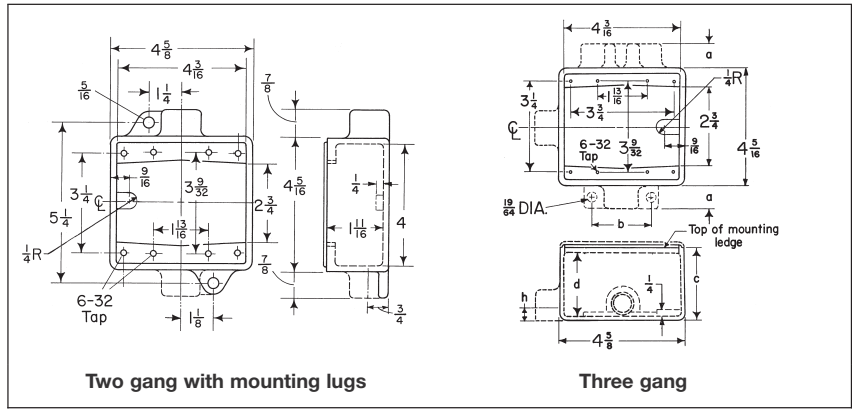

Three gang

| Series | Hub Size | a | c | d |
|--------|----------|-----|---------|---------|
| FS | 3/4 | 7/8 | 1 1/8 | 1 11/16 |
| | 1 | 1 | 1 7/8 | 1 11/16 |
| FD | 3/4 | 7/8 | 2 11/16 | 2 1/2 |

 
Condulet® Multi-Gang Device Boxes - Cast Iron or Aluminum

Accessories
see pages 37-45

2F

With and Without Mounting Lugs for
Threaded Rigid and IMC Conduit

FS†




| Two Gang Tandem | |
|-----------------|--------|
| Size | Cat. # |
| 1/2 | FS17 |
| 3/4 | FS27 |

FSC†




| Two Gang Tandem | |
|-----------------|--------|
| Size | Cat. # |
| 1/2 | FSC17 |
| 3/4 | FSC27 |

FSE

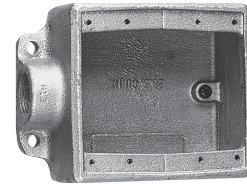


| Two Gang | |
|----------|--------|
| Size | Cat. # |
| 3/4 | FSE22 |

FS & FD

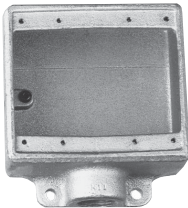

| Two Gang | | |
|----------|--------|--------|
| Size | Cat. # | Cat. # |
| 1/2 | FS12* | FD12 |
| 3/4 | FS22* | FD22* |
| 1 | FS32 | FD32 |

FSC & FDC

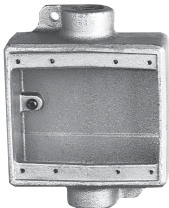


| Two Gang | | |
|----------|--------|--------|
| Size | Cat. # | Cat. # |
| 1/2 | FSC12 | FDC12 |
| 3/4 | FSC22 | FDC22* |
| 1 | FSC32 | FDC32 |

†Use single gang covers only.

*Available in copper-free aluminum;
add suffix "SA".

Dimensions

In Inches:

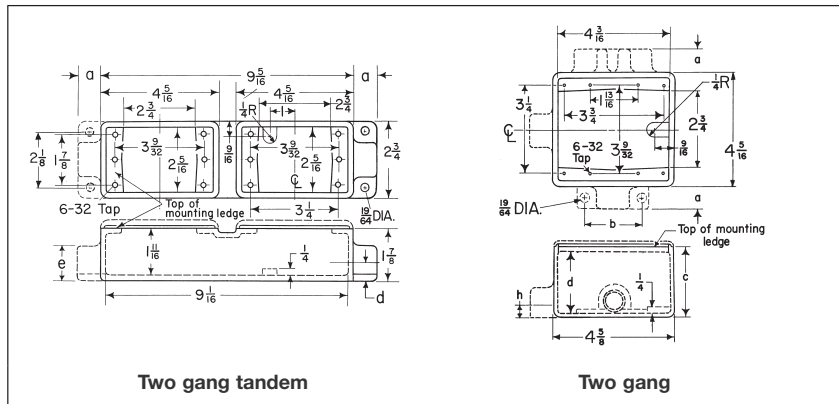

Two gang tandem

| Series | Hub Size | a | b | e |
|--------|----------|-----|-----|-------|
| FS | 1/2 | 7/8 | 5/8 | 1 1/4 |
| | 3/4 | 7/8 | 3/4 | 1 1/2 |

Two gang

| Series | Hub Size | a | b | c | d | h |
|--------|----------|-----|-------|---------|---------|-----|
| FS | 1/2 | 7/8 | 2 1/4 | 1 7/8 | 1 11/16 | 5/8 |
| | 3/4 | 7/8 | 2 1/4 | 1 7/8 | 1 11/16 | 3/4 |
| | 1 | 1 | 2 1/2 | 1 7/8 | 1 11/16 | 7/8 |
| FD | 1/2 | 7/8 | 2 1/4 | 2 11/16 | 2 1/2 | 5/8 |
| | 3/4 | 7/8 | 2 1/4 | 2 11/16 | 2 1/2 | 3/4 |
| | 1 | 1 | 2 1/2 | 2 11/16 | 2 1/2 | 7/8 |

2F


Condulet® Multi-Gang Device Boxes - Cast Iron or Aluminum

Accessories
see pages 37-45

With and Without Mounting Lugs for
Threaded Rigid and IMC Conduit


2F

FSS & FDS

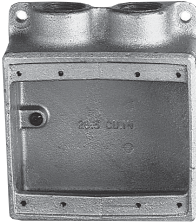

| Two Gang | | |
|----------|--------|--------|
| Size | Cat. # | Cat. # |
| 3/4 | FSS222 | FDS222 |


FSD

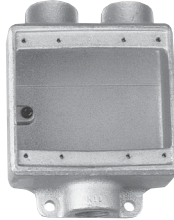

| Two Gang | |
|----------|---------|
| Size | Cat. # |
| 3/4 | FSD212* |


*Hubs on 2 hub side are 1/2"

FS & FD

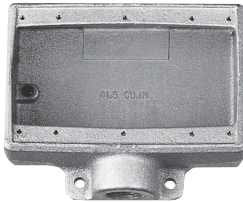


| Three Gang | | |
|------------|--------|--------|
| Size | Cat. # | Cat. # |
| 3/4 | FS23 | FD23 |
| 1 | FS33 | |

FSS

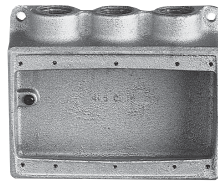

| Three Gang | |
|------------|--------|
| Size | Cat. # |
| 3/4 | FSS23 |

Dimensions In Inches:

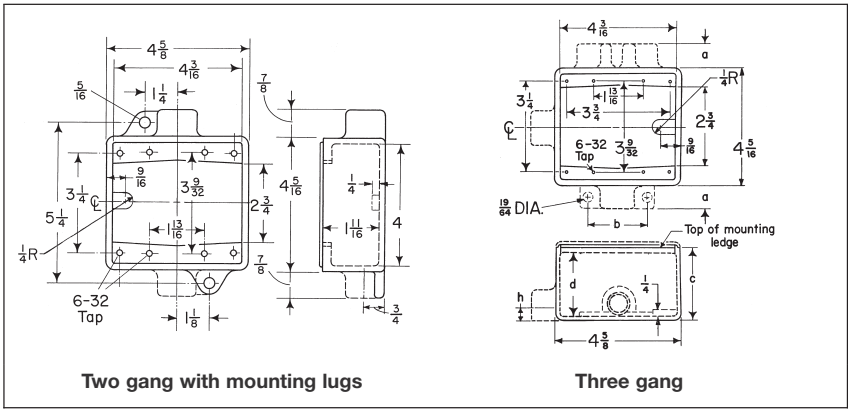

| Three gang | | | | |
|------------|----------|-----|---------|---------|
| Series | Hub Size | a | c | d |
| FS | 3/4 | 7/8 | 1 1/8 | 1 11/16 |
| | 1 | 1 | 1 7/8 | 1 11/16 |
| FD | 3/4 | 7/8 | 2 11/16 | 2 1/2 |