

DESCRIPTION

The ALL-PRO™ LED Outdoor Security series is designed to provide superior security with the sustainability of LED Technology. Designed to be a direct replacement for traditional halogen and incandescent fixtures, these round low profile LED floodlights pack high performance into a small package. These fixtures are available in Flood, Motion and Dusk to Dawn configurations, and are made with durable die-cast aluminum.

| Catalog # | | Type |
|-------------|--|------|
| Project | | |
| Comments | | Date |
| Prepared by | | |

SPECIFICATION FEATURES

Construction

- Durable die-cast aluminum housing suitable for wet locations
- Powder coated bronze or white finish
- High reflectance polycarbonate reflector for maximum LED light output
- Tool-less head and motion sensor adjustment
- Tempered glass lens
- Suitable for wall or eave mounting using recessed junction box

Electrical

- 120VAC, 60Hz
- Maintenance-free LEDs with 50,000 hours of life
- Fixture operating temperature range from -30°C to 40°C
- UL and CUL listed for wet locations
- External supply wiring 75°C minimum

Motion Configuration

- Motion sensor detects motion 180° up to 70 feet
- Adjustable motion timer from 1 to 12 minutes

- Integral photocell prevents lights from turning on with motion during daylight hours
- Manual override allows fixture to operate as a standard floodlight at night for 6 hours

Optics

- Precision optics for maximum efficiency
- 5000K color temperature
- 1600 Lumens

Warranty



- 5 year limited warranty





LED TWIN ROUND SERIES

DIMENSIONS



MOTION

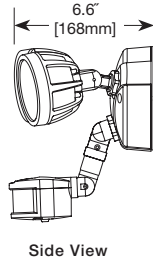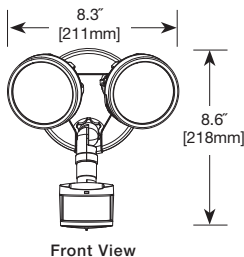


DUSK TO DAWN

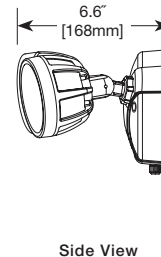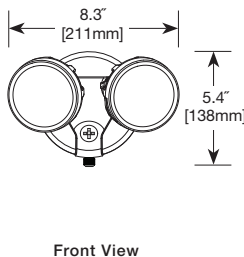

FLOOD

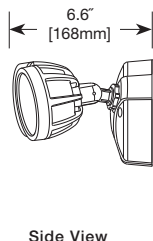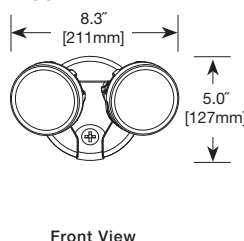

MOUNTING

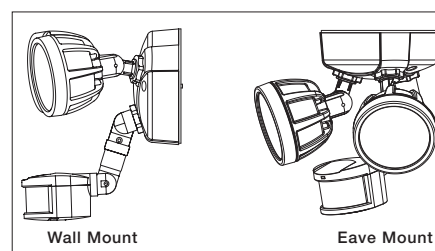

ORDERING INFORMATION

| Catalog Number | Product Description |
|----------------|--|
| MST18R17L | Bronze Twin LED with 180° Motion Sensor |
| MST18R17LW | White Twin LED with 180° Motion Sensor |
| FTR1740L | Bronze Twin LED Floodlight |
| FTR1740LW | White Twin LED Floodlight |
| FTR1740LPC | Bronze Twin LED Floodlight with integrated photo control |
| FTR1740LPCW | White Twin LED Floodlight with integrated photo control |

Innovation you can rely on™

Sustainable Design

CERTIFICATION DATA

UL/CUL Wet Location Listed
Lighting Facts® Approved

TECHNICAL DATA

120V only
-30°C to 40°C Temperature Rating
External Supply Wiring 75° Minimum
Wall and Eave Mount

DESCRIPTION

The ALL-PRO™ LED Outdoor Security series is designed to provide superior security with the sustainability of LED Technology. Designed to be a direct replacement for traditional halogen and incandescent fixtures, these round low profile LED floodlights pack high performance into a small package. These fixtures are available in Flood, Motion and Dusk to Dawn configurations, and are made with durable die-cast aluminum.

| Catalog # | | Type |
|-------------|--|------|
| Project | | |
| Comments | | Date |
| Prepared by | | |

SPECIFICATION FEATURES

Construction

- Durable die-cast aluminum housing suitable for wet locations
- Powder coated bronze or white finish
- High reflectance polycarbonate reflector for maximum LED light output
- Tool-less head and motion sensor adjustment
- Tempered glass lens
- Suitable for wall or eave mounting using recessed junction box

Electrical

- 120VAC, 60Hz
- Maintenance-free LEDs with 50,000 hours of life
- Fixture operating temperature range from -30°C to 40°C
- UL and CUL listed for wet locations
- External supply wiring 75°C minimum

Motion Configuration

- Motion sensor detects motion 180° up to 70 feet
- Adjustable motion timer from 1 to 12 minutes

- Integral photocell prevents lights from turning on with motion during daylight hours
- Manual override allows fixture to operate as a standard floodlight at night for 6 hours

Optics

- Precision optics for maximum efficiency
- 5000K color temperature
- 1600 Lumens

Warranty



- 5 year limited warranty





LED TWIN ROUND SERIES

DIMENSIONS



MOTION

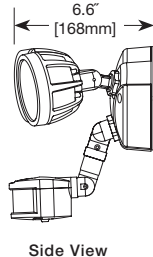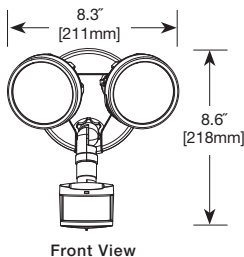


DUSK TO DAWN

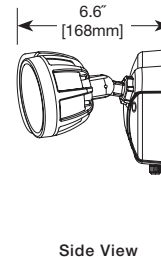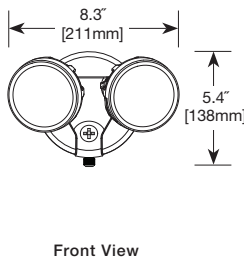

FLOOD

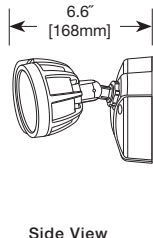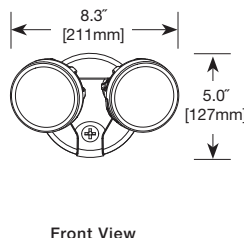

MOUNTING

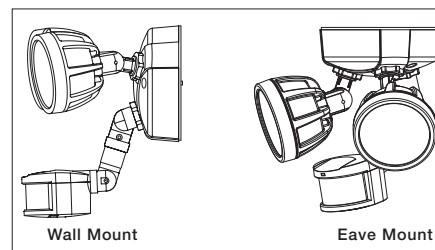

ORDERING INFORMATION

| Catalog Number | Product Description |
|----------------|--|
| MST18R17L | Bronze Twin LED with 180° Motion Sensor |
| MST18R17LW | White Twin LED with 180° Motion Sensor |
| FTR1740L | Bronze Twin LED Floodlight |
| FTR1740LW | White Twin LED Floodlight |
| FTR1740LPC | Bronze Twin LED Floodlight with integrated photo control |
| FTR1740LPCW | White Twin LED Floodlight with integrated photo control |

Innovation you can rely on™

Sustainable Design

CERTIFICATION DATA

UL/CUL Wet Location Listed
Lighting Facts® Approved

TECHNICAL DATA

120V only
-30°C to 40°C Temperature Rating
External Supply Wiring 75° Minimum
Wall and Eave Mount