


# FXH150QT

Medium base HPS, MH or CFL specification grade flood with Integra Hood glare shield and 1/2" heavy duty swivel arm. Lamp supplied.

Color: Bronze

Weight: 15.6 lbs

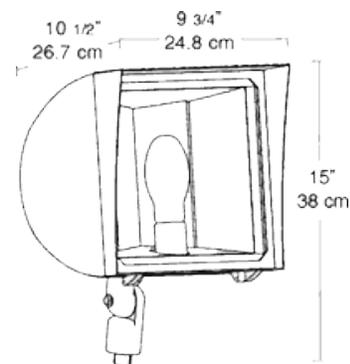

## Lamp Info

Type: ED17  
Watts: 150W  
Shape/Size: N/A  
Base: N/A  
ANSI: N/A  
Hours: 10,000  
Lamp Lumens: 12,500  
Efficacy: 68 LPW

## Ballast Info

Type: CWA-HPF QT  
120V: 1.3/1.8A  
208V: .8/1.1A  
240V: .7/.9A  
277V: .6/.8A  
Input Watts: 185W  
Efficiency: 81%

## Technical Specifications

### UL Listing:

Suitable for wet locations. Suitable for mounting within 1.2m (4ft) of the ground.

### Housing:

Precision die cast aluminum. 1/2" NPS locking Swivel Arm, Wall Bracket Trunion or Slip Fitter.

### Reflector:

Anodized aluminum. Field adjustable beam spread. Rotates 90° for horizontal or vertical lamp position.

### Lens Frame & Glare Shield:

Precision die cast aluminum. Hinged for easy access. Phillips head screws for added security.

### Socket:

HID Porcelain 4kv Pulse Rated socket with nickel plated screw shell CFL Plug in type, GX24q-4 base.

### Finish:

Our environmentally friendly polyester powder coatings are formulated for high-durability and long-lasting color, and contains no VOC or toxic heavy metals.

### Lens:

Thermal tempered shock resistant glass, 3/16" thick.

### Lens Gasket:

High temperature one piece molded silicone set in die cast retaining groove. Remains in place during relamping.

### Ground Mounting:

Use the new MPM19 Mighty Post with aluminum cap for sturdy installation.

### Quad Tap:

Fixture works with 120, 208, 240 and 277 Volts .

### EPA:

Maximum EPA 1.1

### Patents:

Pat. D545,472

**RAB**  
LIGHTING

Tech Help Line: 888 RAB-1000

Email: [sales@rabweb.com](mailto:sales@rabweb.com)

On the web at: [www.rabweb.com](http://www.rabweb.com)

Copyright ©2013 RAB Lighting, Inc. All Rights Reserved

Note: Specifications are subject to change without notice

Page 1 of 1