



BURNDY Catalog Number
UPC Number
Description
Status

GAR1726
 7818102342044
 4-2/0CU 1 1/2IPS
 Active

Web Use
 BURNDY Product Line

Width (in)
 Length (in)
 Height (in)
 Size (Hex) or Size (Bolt)
 Size (Hex) or Size (Bolt) - in
 B Length (in)
 Width (Fraction)
 Height (Fraction) (in)

Dimensional
 3.25
 1.56
 4.00
 3/8
 0.38
 2.31
 3-1/4
 4

Product Description

General

Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 1-1/2" Pipe,
 1-5/8" -1-7/8" Rod, Bright Dipped

Other

268

Approvals / Certifications

Type of U Bolt

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards
 Rated for Direct Burial

Y
 Y
 Exempt
 N
 N
 UL467
 Y

Conductor(s)

Copper Tube Size (SCH40) - Range
 Rod Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)
 Rebar Size (Range)

1 1/2 IPS IPS
 1 5/8 in-1 7/8 in
 4 AWG-3/0 AWG
 5 AWG-2/0 AWG
 N/A

Physical

Type of Hardware
 Installation Torque
 Type of Plating
 Plated (Yes or No)
 Product Material

DURIUMâ€ Silicon Bronze
 240
 Bright Dipped
 N
 Copper Alloy

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

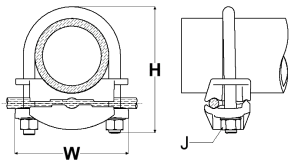

BURNDY Catalog Number
UPC Number
Description
Status

GAR1726
 7818102342044
 4-2/0CU 1 1/2IPS
 Active

Web Use
 BURNDY Product Line

Width (in)
 Length (in)
 Height (in)
 Size (Hex) or Size (Bolt)
 Size (Hex) or Size (Bolt) - in
 B Length (in)
 Width (Fraction)
 Height (Fraction) (in)

Dimensional
 3.25
 1.56
 4.00
 3/8
 0.38
 2.31
 3-1/4
 4

Product Description

General

Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 1-1/2" Pipe,
 1-5/8" -1-7/8" Rod, Bright Dipped

Other

268

Approvals / Certifications

Type of U Bolt

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS
 Industry Standards
 Rated for Direct Burial

Y
 Y
 Exempt
 N
 N
 UL467
 Y

Conductor(s)

Copper Tube Size (SCH40) - Range
 Rod Size (Range)
 Copper Solid Size (Range)
 Copper Stranded (Range)
 Rebar Size (Range)

1 1/2 IPS IPS
 1 5/8 in-1 7/8 in
 4 AWG-3/0 AWG
 5 AWG-2/0 AWG
 N/A

Physical

Type of Hardware
 Installation Torque
 Type of Plating
 Plated (Yes or No)
 Product Material

DURIUM® Silicon Bronze
 240
 Bright Dipped
 N
 Copper Alloy

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175