



BURNDY Catalog Number
UPC Number
Description
Status

GAR1826
 7818102350033
 4-2/0CU 2IPS
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in)	3.69
Length (in)	1.56
Height (in)	4.25
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
B Length (in)	2.75
Width (Fraction)	3-3/4
Height (Fraction) (in)	4-1/4

General

Product Description
 Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 2" Pipe,
 2" -2-3/8" Rod, Bright Dipped

Other

Type of U Bolt 257

Approvals / Certifications

UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y

Conductor(s)

Copper Tube Size (SCH40) - Range	2 IPS IPS
Rod Size (Range)	2 in-2 3/8 in
Copper Solid Size (Range)	4 AWG-3/0 AWG
Copper Stranded (Range)	5 AWG-2/0 AWG
Rebar Size (Range)	N/A

Physical

Type of Hardware	DURIUM® Silicon Bronze
Installation Torque	240
Type of Plating	Bright Dipped
Plated (Yes or No)	N
Product Material	Copper Alloy

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

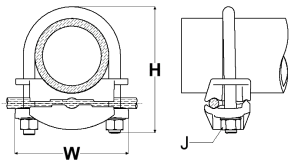

BURNDY Catalog Number
UPC Number
Description
Status

GAR1826
 7818102350033
 4-2/0CU 2IPS
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 3.69
 Length (in) 1.56
 Height (in) 4.25
 Size (Hex) or Size (Bolt) 3/8
 Size (Hex) or Size (Bolt) - in 0.38
 B Length (in) 2.75
 Width (Fraction) 3-3/4
 Height (Fraction) (in) 4-1/4

General

Product Description
 Mechanical Grounding Connector,
 Cable to Rod or Pipe, 4 AWG
 (Sol)-2/0 AWG (Str), 2" Pipe,
 2" -2-3/8" Rod, Bright Dipped

Other

Type of U Bolt 257

Approvals / Certifications

UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 UL Recognized N
 CULUS N
 Industry Standards UL467
 Rated for Direct Burial Y

Conductor(s)

Copper Tube Size (SCH40) - Range 2 IPS IPS
 Rod Size (Range) 2 in-2 3/8 in
 Copper Solid Size (Range) 4 AWG-3/0 AWG
 Copper Stranded (Range) 5 AWG-2/0 AWG
 Rebar Size (Range) N/A

Physical

Type of Hardware DURIUM® Silicon Bronze
 Installation Torque 240
 Type of Plating Bright Dipped
 Plated (Yes or No) N
 Product Material Copper Alloy

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175