


Clip-on™ Stamped Steel and Aluminum Covers and Separate Gaskets

For Form 7 Conduit Bodies

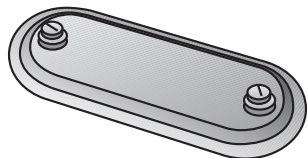

Type 170

Type 170 Stamped Steel and Aluminum Clip-on™ Cover

Use:

To cover conduit body opening.

Features:

- Centering tabs
- Easy installation
- Easy removal
- Nylon sealing washers

Material/Finish:

Stamped Steel/Zinc Pre-Galvanized
Stainless Steel Screws
Zinc Electroplated Clips

Optional Material:

Aluminum add suffix -SA as shown below

Third Party Certification:



UL Listed: E-18095

Suitable for wet locations when used with gaskets, Type GASK on Form 7 conduit bodies.



CSA Certified: 009795

Suitable for wet locations when used with gaskets, Type GASK on Form 7 conduit bodies.


Applicable Third Party Standards:

UL Standard: 514A

CSA Standard: C22.2 No. 18

Fed. Spec: A-A-50563

NEMA: FB-1, FB-2.10

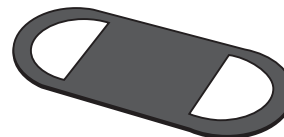

Type GASK

Type GASK Solid Cover Gasket

Use:

To provide a worry-free, rain tight seal when used with Type 170 or 170F covers that have heavy-duty cover screw washers.

Material:

Closed-Cell Neoprene.
Temperature Rating: 212°F/100°C.


Note: UL/CSA not applicable.

Trade Size (inches)	Catalog Number Steel	Catalog Number Aluminum
1/2	170	170-SA
3/4	270	270-SA
1	370	370-SA
1 1/4	470	470-SA
1 1/2	570	570-SA
2	670	670-SA
2 1/2-3	870	870-SA
3 1/2-4	970	970-SA

Trade Size (inches)	Catalog Number
1/2	GASK571
3/4	GASK572
1	GASK573
1 1/4	GASK574
1 1/2	GASK575
2	GASK576
2 1/2-3	GASK578
3 1/2-4	GASK579

Clip-on™ Stamped Steel and Aluminum Covers and Separate Gaskets

For Form 7 Conduit Bodies

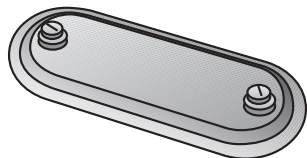

Type 170

Type 170 Stamped Steel and Aluminum Clip-on™ Cover

Use:

To cover conduit body opening.

Features:

- Centering tabs
- Easy installation
- Easy removal
- Nylon sealing washers

Material/Finish:

Stamped Steel/Zinc Pre-Galvanized
Stainless Steel Screws
Zinc Electroplated Clips

Optional Material:

Aluminum add suffix -SA as shown below

Third Party Certification:



UL Listed: E-18095

Suitable for wet locations when used with gaskets, Type GASK on Form 7 conduit bodies.



CSA Certified: 009795

Suitable for wet locations when used with gaskets, Type GASK on Form 7 conduit bodies.


Applicable Third Party Standards:

UL Standard: 514A

CSA Standard: C22.2 No. 18

Fed. Spec: A-A-50563

NEMA: FB-1, FB-2.10

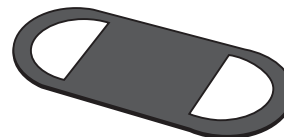

Type GASK

Type GASK Solid Cover Gasket

Use:

To provide a worry-free, rain tight seal when used with Type 170 or 170F covers that have heavy-duty cover screw washers.

Material:

Closed-Cell Neoprene.
Temperature Rating: 212°F/100°C.

Note: UL/CSA not applicable.

Trade Size (inches)	Catalog Number Steel	Catalog Number Aluminum
1/2	170	170-SA
3/4	270	270-SA
1	370	370-SA
1 1/4	470	470-SA
1 1/2	570	570-SA
2	670	670-SA
2 1/2-3	870	870-SA
3 1/2-4	970	970-SA

Trade Size (inches)	Catalog Number
1/2	GASK571
3/4	GASK572
1	GASK573
1 1/4	GASK574
1 1/2	GASK575
2	GASK576
2 1/2-3	GASK578
3 1/2-4	GASK579