

Stud Wall and Drywall Accessories

Grounding Devices




GEE

Grounding Clip

- For grounding switch and outlet boxes using non-metallic sheathed cables with ground wire
- Grounds #12 and #14 copper and #12 aluminum conductors


Grounding Pigtail

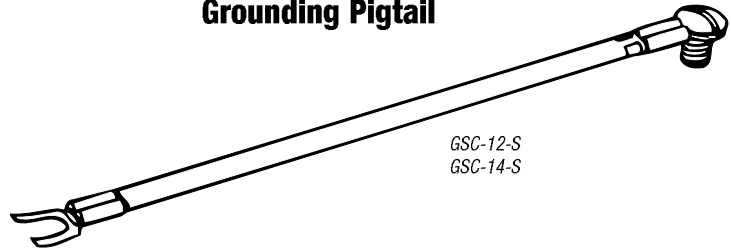


GSC-12-S
GSC-14-S

Grounding Screw and Wire

- A prelooped 6"-long bare or insulated copper ground wire attached to a 10-32 x 3/8" hexagon-head washer-face screw, colored green

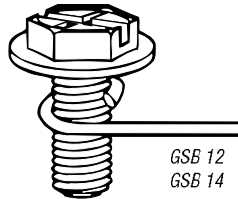


GSB 12
GSB 14

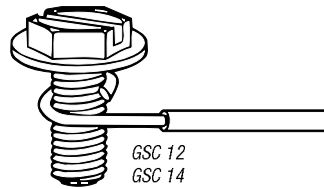

GSC 12
GSC 14

Grounding Screw

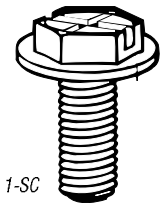


GS 1-SC

CAT. NO.	DESCRIPTION	STD. CTN.	UNIT PKG.
Grounding Clip			
GEE	Zinc-plated, spring-steel, colored green accommodates #12 and #14 copper and #12 aluminum solid conductors in non-metallic sheathed cable. Also approved for connecting bonding jumper from receptacle to grounded metal device box. 50 per unit package	1,000	—
Grounding Screws and Pigtails			
GSC 12	10-32 x 3/8" slotted hexagon-head washer-face ground screw with green dye finish and a six-inch solid copper #12 AWG insulated wire	1,000	100
GSC-12-S*	#12 AWG insulated eight-inch stranded pigtail with a captive 10-32 x 3/8" round head screw on one end and a fork-tongue terminal on the other end	1,000	100
GSC-12-10 1/2	10-32 x 3/8" slotted hexagon-head washer-face ground screw with green dye finish and a 10 1/2 inch solid-copper #12 AWG insulated wire	1,000	100
GSC 14	10-32 x 3/8" slotted hexagon-head washer-face ground screw with green dye finish and a six-inch solid-copper #14 AWG insulated wire	1,000	100
GSC 14 S*	#14 AWG insulated eight-inch stranded pigtail with a captive 10-32 x 3/8" round head screw on one end and a fork-tongue terminal on the other end	1,000	100
GSB 12	10-32 x 3/8" slotted hexagon-head washer-face ground screw with green dye finish and a six-inch solid-copper #12 AWG bare wire	1,000	100
GSB 14	10-32 x 3/8" slotted hexagon-head washer-face ground screw with green dye finish and a six-inch solid-copper #14 AWG bare wire	1,000	100
GS 1-SC	10-32 x 3/8" slotted hexagon-head washer-face screw with green dye finish. Provides positive ground continuity in boxes with a #10-32 tapped hole	1,000	100

* Eight-inch stranded pigtail is also available with a captive 10-32 x 3/8" round-head screw on one end and a fork-tongue terminal on the other end.

Stud Wall and Drywall Accessories


Channel Bar

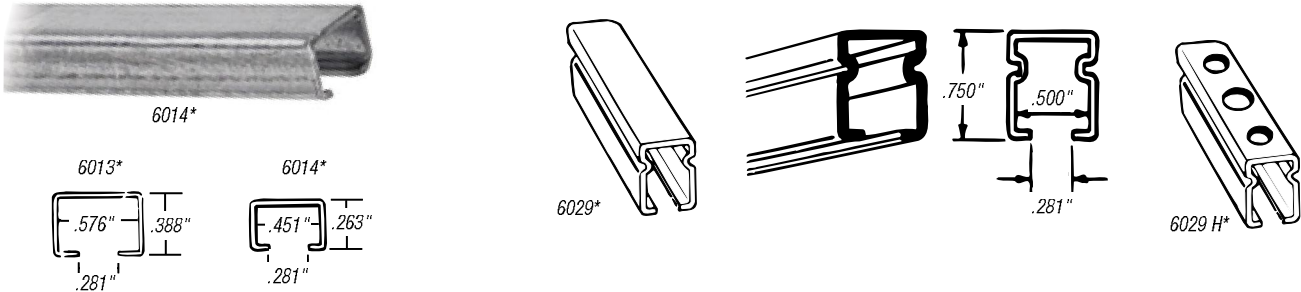

CAT. NO.	DESCRIPTION	MIN. ORDER (FT.)	STD. CTN.
<i>Mounts Fixtures, Boxes and Conduits in Suspended Ceilings</i>			
6013*	20 ga. single channel bar	100	100
6014*	18 ga. single channel bar	100	100
6029*	16 ga. (.060") ribbed	100	100
6029 H*	16 ga. (.060") ribbed — with holes for #12 sheet-metal screw and 1/4" threaded rod	100	100

*10-ft. lengths.

Box and Channel Fasteners

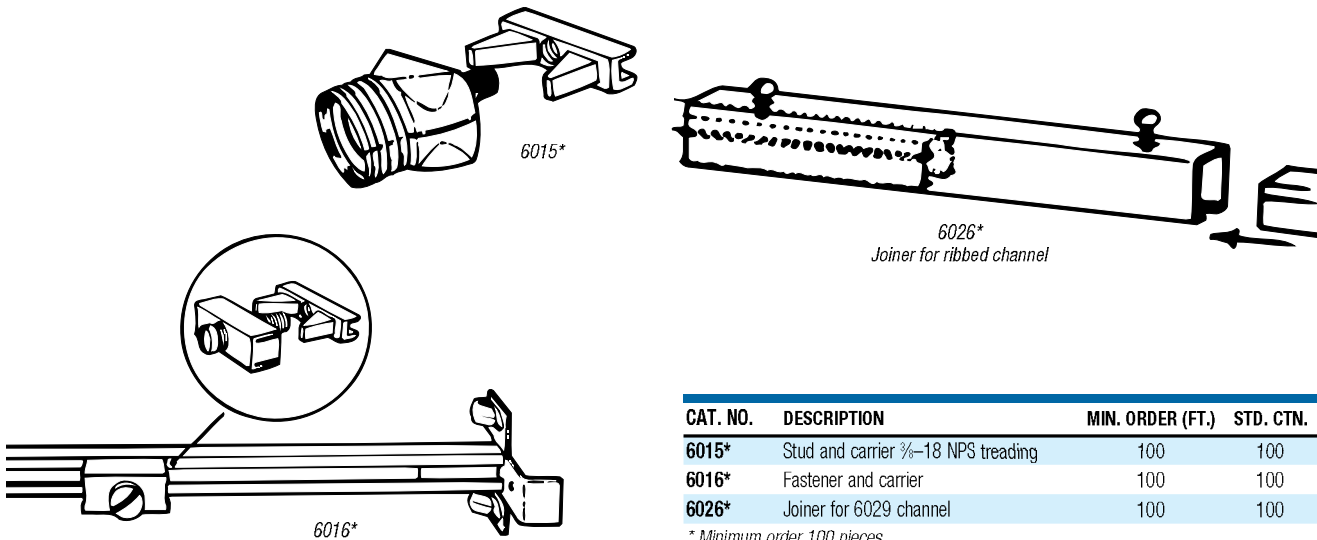

CAT. NO.	DESCRIPTION	MIN. ORDER (FT.)	STD. CTN.
6015*	Stud and carrier 1/8-18 NPS threading	100	100
6016*	Fastener and carrier	100	100
6026*	Joiner for 6029 channel	100	100

* Minimum order 100 pieces.

Stud Wall and Drywall Accessories

Conduit-to-Metal Stud

- Attaches securely to most metal stud sizes
- Riveted to accommodate your drywall requirements

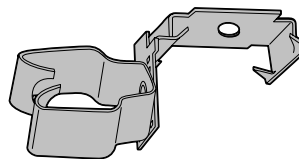


Fig. 1

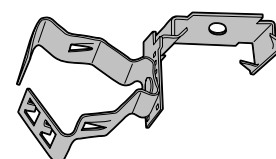


Fig. 2

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SF-S1/2	1	Snap on stud, push-in conduit clip, 1/2" conduit	25
SSF-SF-S3/4	1	Snap on stud, push-in conduit clip, 3/4" conduit	25
SSF-SF-S1	1	Snap on stud, push-in conduit clip, 1" conduit	25
SSF-SF-C3/8	2	Snap on stud, conduit support clip, 3/8" conduit or MC/AC cable	25
SSF-SF-C1/2 3/4	2	Snap on stud, conduit support clip, 1/2"-3/4" conduit	25
SSF-SF-C1	2	Snap on stud, conduit support clip, 1" conduit	25
SSF-SK-C1/2 3/4	3	1/2"-3/4" finger close conduit clip	25
SSF-SK-C1	3	1" finger close conduit clip	25
SSF-SK-S1/2	4	1/2" snap-in conduit clip	25
SSF-SK-S3/4	4	3/4" snap-in conduit clip	25
SSF-SK-S1	4	1" snap-in conduit clip	25

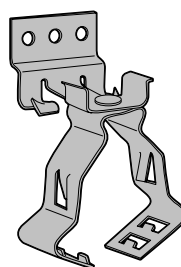


Fig. 3

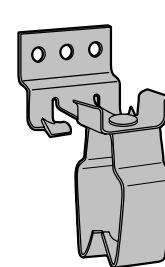


Fig. 4

Easy-Snap Grommet

- Fits any size or shape metal stud hole
- Provides complete 360° protection for cable

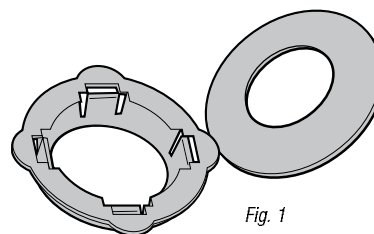
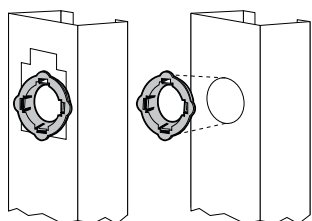


Fig. 1

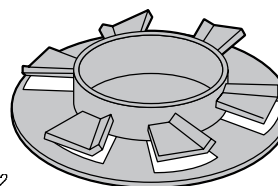


Fig. 2

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
1300	1	Plastic bushing for metal stud 1" trade size opening (1 1/2")	100
1216-EN	2	Twisted universal bushing for metal stud	50

Stud Wall and Drywall Accessories

Through-Stud Cable Conduit Support

- A quick means of support for horizontal runs of conduits or MC/AC through metal stud
- Installs easily with a screw gun
- SSF-SPI enables ENT conduit and MC/AC cable to be easily pulled through metal stud

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SAB-C1/2 3/4	1	1/2" or 3/4" finger close conduit clip	25
SSF-SAB-C3/8	1	Finger-close conduit clip 14-2 thru 12-3 MC/AC cable and 3/8" conduit	25
SSF-SAB-S1/2	2	Snap-in conduit clip — 1/2" conduit	25
SSF-SAB-S3/4	2	Snap-in conduit clip — 3/4" conduit	25
SSF-SP1	3	Supports up to 1" conduit	100

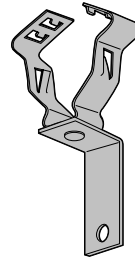


Fig. 1

 
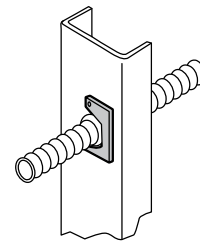


Fig. 2

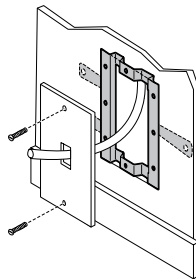


Fig. 3



Low-Voltage Mounting Brackets — Screw-On Support

- Eliminates the need for an electrical box when installing low-voltage Class 2 wiring
- For old work or new work



CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SLV	1	Old-work or new work low-voltage bracket	100
VN1	2	Non-metallic single-gang new-work low-voltage bracket	50
VN2	—	Non-metallic two-gang new-work low-voltage bracket	50
VW1	3	Non-metallic single-gang old-work low-voltage bracket	50
VW2	—	Non-metallic two-gang old-work low-voltage bracket	50
WBF-1	4	Low-voltage mounting bracket with screws	100



Fig. 1



Fig. 2



Fig. 3


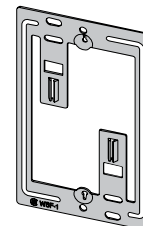


Fig. 4


Stud Wall and Drywall Accessories

Cable Support

 - Supports up to four runs of MC and AC cable and up to six runs of non-metallic sheathed cable
- Installs with nails or staples or sheet-metal screws
- Complies with NEC® 300-4d for all wood and metal studs
- Made with high-strength plastic




CABLE TYPE	CABLE SIZE	MAX. QTY./FASTENER
Non-Metallic Sheathed Cable	#14-2, #12-2, #10-2,	6
	#14-3, #12-3 and #10-3 with Ground	
Non-Metallic	#8-2 and #6-2 with Ground	4
Metallic Clad (MC) Cable and #10-4 with Ground	#14-2, #12-2, #10-2,	4
	#14-3, #12-3, #10-3,	
	#14-4, #12-4	
Armored Cable (AC)	#14-4, #12-2, #10-2,	4
	#8-2, #14-3, #12-3,	
	#10-3, #14-4, #12-4 and #10-4 with Ground	
Flexible Conduit (BX)	¼", ½"	4

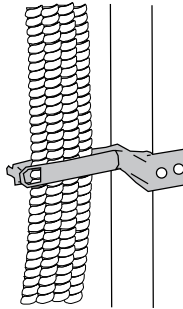

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SC6	1	Non-Metallic Sheathed MC/AC Cable to Stud Clip	100

Device Leveler and Retainer

- Use for oversized drywall openings
- Prevents broken cover plates
- Stops device from being pushed back in wall
- Makes floating device rigid

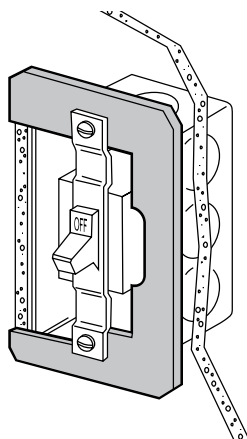


CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SR	1	Single-Gang Device Leveler and Retainer	100

NEC and National Electrical Code are registered trademarks of the National Fire Protection Association, Inc.

Screw-On Conduit Support


- Supports ½" and ¾" EMT conduit and MC/AC cable
- Works with wood or metal stud
- Preset bend provides alignment with knockouts for 1½"-deep boxes or 2¼"-deep boxes

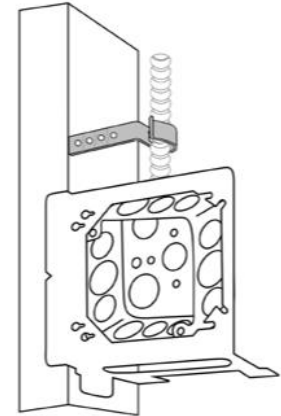

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-SS1/2 3/4	1	½" and ¾" EMT Conduit and MC/AC to Metal or Wood Stud. For 1½"-Deep Box	100
SSF-SS1/2 3/4D	1	½" and ¾" EMT Conduit Metal or Wood Stud. For 2¼"-Deep Box	100

Protector Plates

- Protects cable(s) from damage when installing drywall or paneling
- No nails or screws required
- Fits all stud sizes
- Both products meet requirements for NEC® 300-4
- ST66 legs are crimped with pliers to stud to provide secure fit

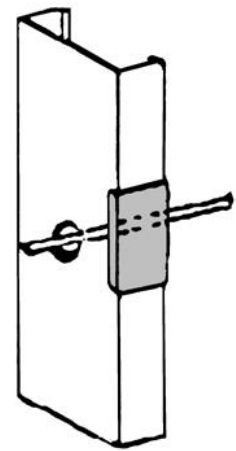

CAT. NO.	FIG. NO.	DESCRIPTION	STD. CTN.
SSF-ST66	1	Protector Plate for Metal Stud	100
66EP	2	Protector Plate for Wood Stud	100