


GK6426, Copper Alloy Grounding Clamp, 3 Cables to Rod or Pipe

By Burndy
Catalog # [GK6426](#)

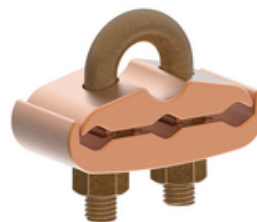

Mechanical Grounding Connector, 3 Cables to Rod or Pipe, 4 AWG (Sol.) - 2/0 AWG (Str.), 3/8" Pipe, 5/8" - 3/4" Rod, 3/8" Stud.

General

Application	For Joining Three Equal Copper Cables To Rod Or Tube, Direct Burial In Earth Or Concrete
Catalog Number	GK6426
EU RoHS Indicator	Yes
Installation Torque	240 LBS/in
Recommended in-lb	
Material	Copper Alloy, Cast
Material Type - Screw Plated	DURIUM™ Silicon Bronze N
Plating Type	Unplated
Sub Brand	MECHANICAL CONNECTOR
Type	Three Cables to Rod or Tube
U Bolt Type	269
UPC	781810233528
UPC 12 Digit	7818102335288

Dimensions

Bolt Size	3/8 in
Dimension - B Length inch	1.50 in
Dimension - Height inch	2.81 in
Dimension - Width inch	2.94 in
Dimension - Width mm	75 mm

Conductor Related

Conductor - Rod Size	5/8 in ; 3/4 in
Conductor Size	#4 AWG Sol - 2/0 AWG Str

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

- [3D Models - GK6426_MODEL-STEP](#)
- [3D Models - GK6426_MODEL-PDF](#)
- [3D Models - GK6426_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section E2 - Mechanical Grounding](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_gk2la](#)
- [Sales Drawings - sc069674-01](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
BRDY-GK6426-SPEC-EN | REV 6/2024