

HALO®




## H1499RT

**4" Aperture  
Shallow Ceiling  
Remodel Housing  
12V Low Voltage MR16  
Halogen**

### RECESSED DOWNLIGHTING

- Thermally Protected Non-IC Shallow Ceiling Low Voltage Remodel Housing
- Integral magnetic Transformer
- Insulation must be kept 3" away from all sides of housing
- \* For use with 12V MR16 halogen lamps

### DIMENSIONS

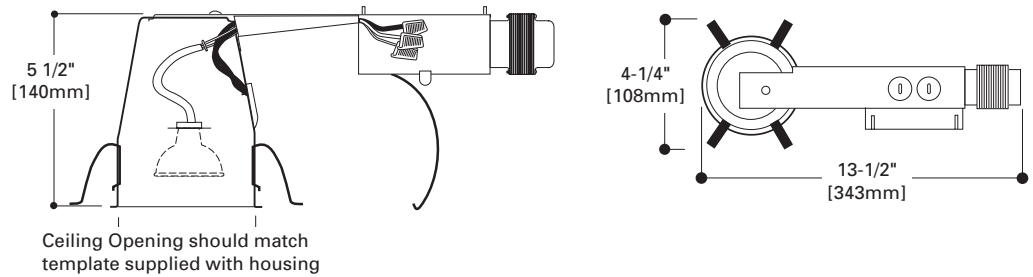

### DESCRIPTION

The H1499RT is a small aperture remodel housing for providing accent and task lighting. The H1499RT is designed for use in non-insulated existing ceiling or for existing insulated ceilings where insulation can be kept 3" from all sides of the housing. It can be installed from below the ceiling.

#### Housing

Die-stamped 20 gauge CRS with white powder coat finish.

#### Junction Box

J-Box features include:

- Listed for through branch circuit wiring
- Seven 1/2" trade size knockouts with true pry-out slots
- Four pryouts with integral strain relief for non-metallic sheathed cable

#### "Quick Connect" Connectors

Three "Quick Connect" connectors eliminate need for separate wire nuts - simply strip supply wires and push in

#### Socket

Ceramic socket with reflector for bi pin MR16 lamps .

#### Remodel Clips

Four remodel clips secure housing and accommodates 1/2" and 5/8" ceiling materials.

#### Transformer

120V magnetic transformer steps line voltage down to lamp operating voltage.

#### Support Spring

Support spring helps support weight of junction box and transformer. Automatically adjusts for different ceiling

materials..

#### Thermal Protector

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.

#### Labels

- UL/cUL Listed for Damp Location
- UL/cUL Listed for Feed Through

**H1499IC**

**H1499T**


**H1499RT**

**H1499T75**

**1421 Reflector Trim**

- Die cast trim ring with reflector cone
- Provides General Illumination
- Lamps:

<b>H1499T</b>	50W 12V MR16
<b>H1499RT</b>	
<b>H1499IC</b>	75W 12V MR16
<b>H1499T75</b>	

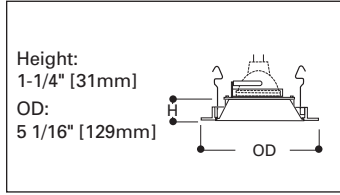

**1421RG**  
White Trim, Residential Gold Reflector

**1421CG**  
White Trim, Champagne Gold Reflector

**1421C**  
White Trim, Clear Specular Reflector



**1421SL**  
Silver Trim, Clear Specular Reflector

**1421MB**  
White Trim, Black Specular Reflector

**1421H**  
White Trim, Haze Reflector



**1421BZ**  
Tuscan Bronze, Tuscan Bronze Reflector

**1421AC**  
Antique Copper Trim, Antique Copper Reflector


**1421SN**  
Satin Nickel Trim, Satin Nickel Reflector

**1493**

**Coilex® Baffle**

- Die cast trim ring
- Coilex® Baffle
- For general lighting
- Lamps:

<b>H1499T</b>	50W 12V MR16
<b>H1499RT</b>	
<b>H1499IC</b>	75W 12V MR16
<b>H1499T75</b>	

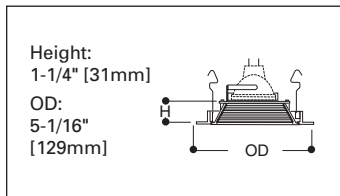

**1493PB**  
Polished Brass Trim with Black Baffle

**1493W**  
White with White Baffle

**1493P**  
White with Black Baffle



**1493SN**  
Satin Nickel Trim with Black Baffle

**1493BC**  
Black Chrome Trim with Black Baffle

**1493SL**  
Silver Trim with Black Baffle



**1493TBZ**  
Tuscan Bronze Trim with Black Baffle

**1493AC**  
Antique Copper Trim with Black Baffle

HALO®




## H1499RT

4" Aperture  
Shallow Ceiling  
Remodel Housing  
12V Low Voltage MR16  
Halogen

### RECESSED DOWNLIGHTING

- Thermally Protected Non-IC Shallow Ceiling Low Voltage Remodel Housing
- Integral magnetic Transformer
- Insulation must be kept 3" away from all sides of housing
- \* For use with 12V MR16 halogen lamps

### DIMENSIONS

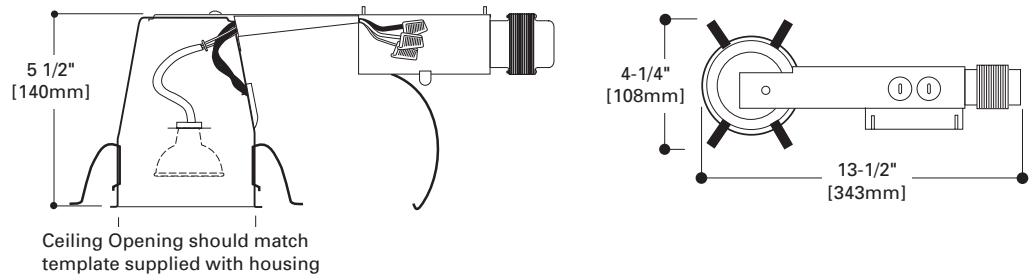

### DESCRIPTION

The H1499RT is a small aperture remodel housing for providing accent and task lighting. The H1499RT is designed for use in non-insulated existing ceiling or for existing insulated ceilings where insulation can be kept 3" from all sides of the housing. It can be installed from below the ceiling.

#### Housing

Die-stamped 20 gauge CRS with white powder coat finish.

#### Junction Box

J-Box features include:

- Listed for through branch circuit wiring
- Seven 1/2" trade size knockouts with true pry-out slots
- Four pryouts with integral strain relief for non-metallic sheathed cable

#### "Quick Connect" Connectors

Three "Quick Connect" connectors eliminate need for separate wire nuts - simply strip supply wires and push in

#### Socket

Ceramic socket with reflector for bi pin MR16 lamps .

#### Remodel Clips

Four remodel clips secure housing and accommodates 1/2" and 5/8" ceiling materials.

#### Transformer

120V magnetic transformer steps line voltage down to lamp operating voltage.

#### Support Spring

Support spring helps support weight of junction box and transformer. Automatically adjusts for different ceiling

materials..

#### Thermal Protector

Self resetting thermal protector deactivates fixture if overheating occurs due to improper lamping or misapplied insulation.

#### Labels

- UL/cUL Listed for Damp Location
- UL/cUL Listed for Feed Through

**H1499IC**

**H1499T**


**H1499RT**

**H1499T75**

**1421 Reflector Trim**

- Die cast trim ring with reflector cone
- Provides General Illumination
- Lamps:

<b>H1499T</b>	50W 12V MR16
<b>H1499RT</b>	50W 12V MR16
<b>H1499IC</b>	50W 12V MR16
<b>H1499T75</b>	75W 12V MR16

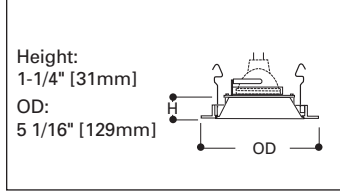

**1421RG**  
White Trim, Residential Gold Reflector

**1421CG**  
White Trim, Champagne Gold Reflector

**1421C**  
White Trim, Clear Specular Reflector



**1421SL**  
Silver Trim, Clear Specular Reflector

**1421MB**  
White Trim, Black Specular Reflector

**1421H**  
White Trim, Haze Reflector



**1421BZ**  
Tuscan Bronze, Tuscan Bronze Reflector

**1421AC**  
Antique Copper Trim, Antique Copper Reflector


**1421SN**  
Satin Nickel Trim, Satin Nickel Reflector

**1493**

**Coilex® Baffle**

- Die cast trim ring
- Coilex® Baffle
- For general lighting
- Lamps:

<b>H1499T</b>	50W 12V MR16
<b>H1499RT</b>	50W 12V MR16
<b>H1499IC</b>	50W 12V MR16
<b>H1499T75</b>	75W 12V MR16

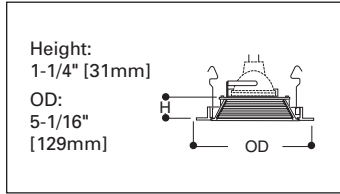

**1493PB**  
Polished Brass Trim with Black Baffle

**1493W**  
White with White Baffle

**1493P**  
White with Black Baffle



**1493SN**  
Satin Nickel Trim with Black Baffle

**1493BC**  
Black Chrome Trim with Black Baffle

**1493SL**  
Silver Trim with Black Baffle



**1493TBZ**  
Tuscan Bronze Trim with Black Baffle

**1493AC**  
Antique Copper Trim with Black Baffle