

Project		Catalog #		Type	
Prepared by		Notes		Date	



HALO

H27RT

6" Non-Insulated Shallow Ceiling Recessed Housing

Typical Applications

Residential, Light Commercial

Interactive Menu

- Order Information page 2
- Product Specification page 3
- Product Warranty

Product Certification




Product Features

Top Product Features

- Quick Connect wiring connectors included in junction box
- NM cable pry-outs and conduit knockouts in junction box
- Remodel springs accommodate 1/2" and 5/8" ceiling material
- Thermally protected
- Die-formed housing
- Options to meet Trade Agreements Act requirements

Dimensional and Mounting Details

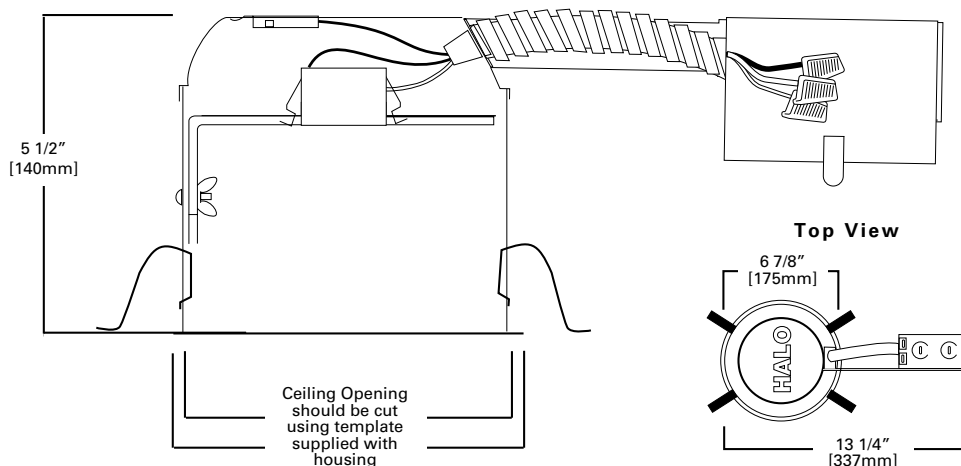
















 

Order Information

SAMPLE ORDER NUMBER: **H27RT-426RG**




Order housing, trim and accessories separately.

Domestic Preferences	Housing
Domestic Preferences ⁽¹⁾	Housing
[Blank] =Standard TAA =Trade Agreements Act	H27RT = 6" Non-Insulated Shallow Ceiling Remodel Housing
<small>(1) Only product configurations with this designated prefix are built to be compliant with the Trade Agreements Act of 1979 (TAA). Please refer to DOMESTIC PREFERENCES website for more information. Components shipped separately may be separately analyzed under domestic preference requirements.</small>	

Trims

Reflectors	Baffles	Eyeballs and Adjustables	Lens Trims
 <p>426 Specular Reflector Cone 75W R30, 65W BR30, 75W PAR30 OD: 7 1/4" [184mm]</p> <p>426 = Specular Clear 426H = Haze 426RG = Residential Gold 426CG = Champagne Gold 426MB = Specular Black</p>	 <p>310 Baffle 75W R30, 65W BR30, 75W PAR30 OD: 7 1/4" [184mm]</p> <p>310P = Black Baffle 310W = White Baffle</p>	 <p>74 Eyeball - 30° Tilt 75W PAR30 OD: 8" [203mm]</p> <p>74P = White Eyeball</p>	 <p>70 Albalite Lens 60W A19 OD: 8" [203mm]</p> <p>70P = Albalite Lens with White Trim Ring 70PS = Albalite Lens Showerlight with White Trim Ring</p>
 <p>429 Dayform White Cone 75W R30, 65W BR30, 75W PAR30 OD: 7 1/4" [184mm]</p> <p>429P = White</p>		 <p>77 Eyeball 50W R20, 50W PAR20 OD: 8" [203mm]</p> <p>77P = White Eyeball</p>	 <p>170 Albalite Lens w Reflector 60W A19 OD: 8" [203mm]</p> <p>170P = Albalite Lens with White Trim Ring - Socket Supporting 170PS = Albalite Lens Showerlight with White Trim Ring - Socket Supporting</p>
 <p>4261 Self Flanged Reflector Cone 75W R30, 75W PAR30 OD: 7 1/4" [184mm]</p> <p>4261 = White Self Flanged Reflector Cone</p>		 <p>78 Eyeball - 30° Tilt 75W R30, 75W PAR30 OD: 8" [203mm]</p> <p>78P = White Eyeball 78SL = Silver Eyeball 78B = Brass Eyeball 78PB = Polished Brass Eyeball 78PAT = White AIR-TITE Eyeball</p>	 <p>71 Drop Opal Lens 60W A19 OD: 8" [203mm]</p> <p>71P = Drop Opal Lens with White Trim Ring 71PS = Drop Opal Lens Showerlight with White Trim Ring</p>
		 <p>376 Adjustable 75W PAR30 OD: 7 1/4" [184mm]</p> <p>376P = Black Baffle, Black Lampholder, White Trim Ring</p>	 <p>171 Drop Opal Lens w Reflector 60W A19 OD: 8" [203mm]</p> <p>171P = Drop Opal Lens with White Trim Ring - Socket Supporting 171PS = Drop Opal Lens Showerlight with White Trim Ring - Socket Supporting</p>
		 <p>378 Adjustable with Splay Reflector 75W PAR30 OD: 7 3/4" [197mm]</p> <p>378 = White Lampholder with Clear Splay 378P = White Lampholder with White Splay</p>	 <p>73 Fresnel Lens 60W A19 OD: 8" [203mm]</p> <p>73P = Fresnel Lens with White Trim Ring 73PS = Fresnel Lens Showerlight with White Trim Ring</p>
		 <p>419 Regressed Eyeball with Splay 75W PAR30 OD: 7 1/4" [184mm]</p> <p>419 = White Eyeball with Clear Splay 419P = White Eyeball with White Splay</p>	 <p>173 Fresnel Lens w Reflector 60W A19 OD: 8" [203mm]</p> <p>173P = Fresnel Lens with White Trim Ring - Socket Supporting 173PS = Fresnel Lens Showerlight with White Trim Ring - Socket Supporting</p>
		 <p>420 Coilex Baffle Eyeball 75W BR30, 75W PAR30L OD: 7 1/4" [184mm]</p> <p>420P = White Eyeball with Black Baffle 420PB = Polished Brass Eyeball with Black Baffle 420W = White Eyeball with White Baffle</p>	

Trims

Open Trims	
	79 Pinhole Trim 50W PAR30, 65W BR30 OD: 8" [203mm]
79P = White Pinhole Trim	
	301 Open 75W R30, 65W BR30, 75W PAR30 OD: 8" [203mm]
301P = White Open Trim 301PB = Polished Brass Open Trim	
	328 Splay Trim 100W R30, 75W PAR30, 65W BR30 OD: 7-1/4" [184mm]
328P = White Splay Trim	

Accessories	
Metal Trim Rings Compatible with 310, 312, 376, 378, 419, 420, 426	
TRM6P = White Metal TRM6PB = Polished Brass TRM6C = Chrome TRM6MB = Black Metal TRM6SL = Silver Metal TRP7MB = Black Plastic	

Product Specifications

A Housing

Die-stamped 20 gauge CRS with white powder coat finish.

B Socket Plate

Rigid socket plate adjusts and locks without tools for various lamp sizes.

C Junction Box

U.L. listed for through branch circuit wiring. Seven conduit knockouts are uniform 1/2" size with true pryout slots. Four Romex pryouts included.

D Socket

Porcelain socket with nickel plated brass screw shell.

E Thermal Protector

Integral Thermal Protector deactivates fixture if an incorrect lamp is used or if ceiling insulation material is not applied correctly.

F Remodel Clips

Four remodel clips secure housing and accommodate 1/2" and 5/8" ceiling material.

G "Quick Connect" Connectors

Three "Quick Connect" connectors eliminate need for separate wire nuts - simply strip supply wires and push in

Labels

- U.L. listed for Damp Location
- U.L. listed for Feed Through
- CSA Certified