

|             |  |           |  |      |  |
|-------------|--|-----------|--|------|--|
| Project     |  | Catalog # |  | Type |  |
| Prepared by |  | Notes     |  | Date |  |



# HALO

## H27T

6" Non-Insulated Shallow Ceiling Recessed Housing

### Typical Applications

Residential, Light Commercial

### Interactive Menu

- Order Information page 2
- Product Specification page 3
- Product Warranty



### Product Certification



### Top Product Features

- Got Nail!™ bar hangers
- Pass-N-Thru™ tool-less shortening of bar hangers
- Slide-N-Side™ wire traps
- Quick Connect wiring connectors included in junction box
- Thermally protected
- Options to meet Trade Agreements Act requirements

### Dimensional and Mounting Details

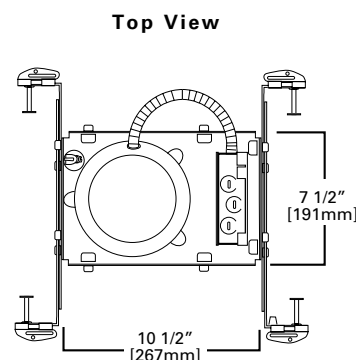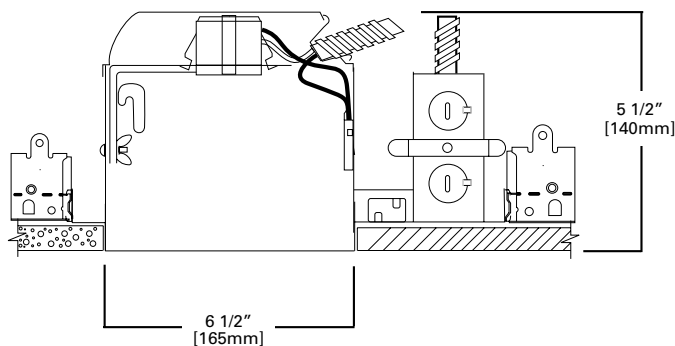




















## Order Information Continued

SAMPLE ORDER NUMBER: **H27T-426RG**

Order housing, trim and accessories separately.




| Domestic Preferences   | Housing  |
|--|--|
| Domestic Preferences <sup>(1)</sup>  | Housing  |
| <b>[Blank]</b> =Standard<br><b>TAA</b> =Trade Agreements Act   | <b>H27T</b> = 6" Non-Insulated Shallow Ceiling Housing |
| (1) Only product configurations with this designated prefix are built to be compliant with the Trade Agreements Act of 1979 (TAA). Please refer to <a href="#">DOMESTIC PREFERENCES</a> website for more information. Components shipped separately may be separately analyzed under domestic preference requirements. |  |

## Trims

| Reflectors  | Baffles   | Eyeballs and Adjustables   | Lens Trims   |
|---|---|--|--|
|  <p><b>426 Specular Reflector Cone</b><br/><b>100W R30</b><br/>OD: 7 1/4" [184mm]</p> <p>426 = Specular Clear<br/>426H = Haze<br/>426RG = Residential Gold<br/>426CG = Champagne Gold<br/>426MB = Specular Black</p> |  <p><b>310 Baffle</b><br/><b>75W R30</b><br/>OD: 7 1/4" [184mm]</p> <p>310P = Black Baffle<br/>310W = White Baffle</p> |  <p><b>74 Eyeball - 30° Tilt</b><br/><b>75W PAR30</b><br/>OD: 8" [203mm]</p> <p>74P = White Eyeball</p>   |  <p><b>70 Albalite Lens</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>70P = Albalite Lens with White Trim Ring<br/>70PS = Albalite Lens Showerlight with White Trim Ring</p> |
|  <p><b>429 Dayform White Cone</b><br/><b>75W R30</b><br/>OD: 7 1/4" [184mm]</p> <p>429P = White Cone</p>   |   |  <p><b>77 Eyeball</b><br/><b>50W R20, 50W PAR20</b><br/>OD: 8" [203mm]</p> <p>77P = White Eyeball</p>   |  <p><b>170 Albalite Lens w Reflector</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>170P = Albalite Lens with White Trim Ring - Socket Supporting</p>                         |
|  <p><b>4261 Self Flanged Reflector Cone</b><br/><b>100W R30</b><br/>OD: 7 1/4" [184mm]</p> <p>4261P = White Self Flanged Reflector Cone</p>  |   |  <p><b>78 Eyeball - 30° Tilt</b><br/><b>75W R30, 75W PAR30</b><br/>OD: 8" [203mm]</p> <p>78P = White Eyeball<br/>78SL = Silver Eyeball<br/>78B = Brass Eyeball<br/>78PB = Polished Brass Eyeball<br/>78PAT = White AIR-TITE Eyeball</p>       |  <p><b>71 Drop Opal Lens</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>71P = Drop Opal Lens with White Trim Ring</p>   |
|   |   |  <p><b>90 Double Bubble - 60° Tilt</b><br/><b>250W PAR38</b><br/>OD: 8" [203mm]</p> <p>90P = White Double Bubble Adjustable</p>   |  <p><b>171 Drop Opal Lens</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>171P = Drop Opal Lens with White Trim Ring - Socket Supporting</p>                                 |
|   |   |  <p><b>376 Adjustable</b><br/><b>75W PAR30</b><br/>OD: 7 1/4" [184mm]</p> <p>376P = Black Baffle, Black Lampholder, White Trim Ring</p>   |  <p><b>73 Fresnel Lens</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>73P = Fresnel Lens with White Trim Ring</p>   |
|   |   |  <p><b>378 Adjustable with Splay Reflector</b><br/><b>75W PAR30</b><br/>OD: 7 3/4" [197mm]</p> <p>378 = White Lampholder with Clear Splay<br/>378P = White Lampholder with White Splay</p>  |  <p><b>173 Fresnel Lens</b><br/><b>60W A19</b><br/>OD: 8" [203mm]</p> <p>173P = Fresnel Lens with White Trim Ring - Socket Supporting</p>                                     |
|   |   |  <p><b>419 Regressed Eyeball with Splay</b><br/><b>75W PAR30</b><br/>OD: 7 1/4" [184mm]</p> <p>419 = White Eyeball with Clear Splay<br/>419P = White Eyeball with White Splay</p>   |  <p><b>75 All-Glas</b><br/><b>60W A19</b><br/>OD: 7 3/4" [197mm]</p> <p>75 = All-Glas Diffuser</p>  |
|   |   |  <p><b>420 Coilex Baffle Eyeball</b><br/><b>75W BR30, 75W PAR30L</b><br/>OD: 7 1/4" [184mm]</p> <p>420P = White Eyeball with Black Baffle<br/>420PB = Polished Brass Eyeball with Black Baffle<br/>420W = White Eyeball with White Baffle</p> |  |

**Trims**

**Open Trims**

| Open Trims  |  |
|---|--|
|  | <p><b>79 Pinhole Trim</b><br/> <b>75W PAR30, 65W BR30</b><br/>                     OD: 8" [203mm]</p> <p><b>79P</b> = White Pinhole Trim</p>                         |
|  | <p><b>301 Open</b><br/> <b>75W R30</b><br/>                     OD: 8" [203mm]</p> <p><b>301P</b> = White Open Trim<br/> <b>301PB</b> = Polished Brass Open Trim</p> |
|  | <p><b>328 Splay Trim</b><br/> <b>100W R30, 75W PAR30, 65W BR30</b><br/>                     OD: 7-1/4" [184mm]</p> <p><b>328P</b> = White Splay Trim</p>             |

**Accessories**

| Accessories  |
|--|
| <p><b>Metal Trim Rings</b><br/>                     Compatible with 310, 312, 376, 378, 426, 419, 420<br/> <b>TRM6P</b> = White Metal<br/> <b>TRM6PB</b> = Polished Brass<br/> <b>TRM6C</b> = Chrome<br/> <b>TRM6MB</b> = Black Metal<br/> <b>TRM6SL</b> = Silver Metal<br/> <b>TRP7MB</b> = Black Plastic</p> |
| <p><b>Oversize Trim Rings</b><br/>                     For use when ceiling opening is cut too large. Compatible with 310, 312, 376, 378, 419, 420, 426, 429<br/> <b>OT400P</b> = 9 1/4" White Metal<br/> <b>OT403P</b> = 8" White Plastic</p>   |
| <p><b>Step Down Transformer</b><br/>                     Steps 277V line voltage down to 120V fixture operating voltage. 150VA max.<br/> <b>H277</b> = 150VA Max.</p>  |
| <p><b>Power-Trac Adapter Trim</b><br/>                     Allows 120V Trac lampholders (150W Max.) to be used with recessed installations<br/> <b>477P</b> = Black Baffle, white trim ring<br/> <b>477W</b> = White Baffle, white trim ring</p>   |

**Product Specifications**

**A Housing**

Die-stamped 20 gauge CRS with white powder coat finish.

**B Socket Plate**

Rigid socket plate adjusts and locks without tools for various lamp sizes.

**C Plaster Frame**

Housing adjusts in plaster frame 1 3/8" to accommodate different ceiling thicknesses. Includes locking screws for hanger bars and cutouts for crimping hanger bars in position

**D Junction Box**

U.L. listed for through branch circuit wiring. Positioned to accommodate straight conduit runs. Seven conduit knockouts are uniform 1/2" size with true pryout slots. Four Romex pryouts with integral strain relief also included.

**E GOT NAIL! Pass-N-Thru™ Bar Hangers**

Bar Hanger Features include:

- Pre-installed nail easily installs in regular lumber, engineered lumber and laminated beams
- Safety and guidance system prevents snagging, ensures smooth straight nail penetration and allows bar hangers to be easily removed if necessary.
- Automatic leveling flange aligns the housing and lets you hold the housing in place with one hand while driving nails
- Housing can be positioned at any point within 24" joist span
- Score lines allow "toolless" shortening for 12" joists
- Bar hangers may be repositioned 90°
- Bar hangers do not need to be removed from frame for shortening
- Integral T-bar clips snaps onto T-bars - no additional clips required

**F Socket**

Porcelain socket with nickel plated brass screw shell.

**G Thermal Protector**

Integral Thermal Protector deactivates fixture if an incorrect lamp is used or if ceiling insulation material is not applied correctly.

**Labels**

- U.L. listed for Damp Location
- U.L. listed for Feed Through
- CSA Certified