

Straight Blade Devices  
 20A, 250V, 2 Pole, 3 Wire Grounding  
 Insulgrip® Plug

# HUBBELL

## Features

- Ribbed nylon housing is impact and chemical resistant
- VARI-SIZE adjustable cord clamp
- Fast lead assembly screws
- Beveled housing prevents snagging

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black and white nylon	.230"-.720"(5.8-18.3)	783585174709	HBL5466C

## Listings

UL Listed to UL498 File E1706  
 CSA Certified to C22.2 No. 42 File 280  
 NEMA® WD-6 Compliant  
 NEMA® WD-6 Compliant

## Specifications

Housing/Cord Clamp	Nylon
Blade Holder	Nylon
Terminal Retainer	Clear Polycarbonate
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

## Performance

### Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

### Mechanical


Terminal Accommodation	#18-10 AWG. Standed copper wire only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

### Environmental



Flammability	UL 94 HB or better
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)



AGENCY LISTING  
 PER TABLE

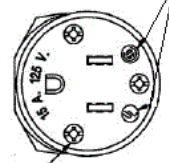

ALL SCREWS ARE  
 COMBINATION  
 ROBERTSON/PHILLIPS/  
 SLOTTED HEAD

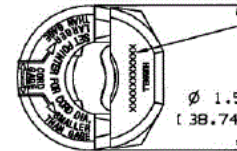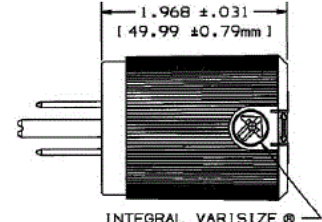

CATALOG NUMBER  
 (HBL5266CM2 &  
 HBL5266EBK NOT  
 MARKED)

## Accessories

Weatherproof Boot	HBL6017
-------------------	---------

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.



Straight Blade Devices  
 20A, 250V, 2 Pole, 3 Wire Grounding  
 Insulgrip® Plug

# HUBBELL

## Features

- Ribbed nylon housing is impact and chemical resistant
- VARI-SIZE adjustable cord clamp
- Fast lead assembly screws
- Beveled housing prevents snagging

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black and white nylon	.230"-.720"(5.8-18.3)	783585174709	HBL5466C

## Listings

UL Listed to UL498 File E1706  
 CSA Certified to C22.2 No. 42 File 280  
 NEMA® WD-6 Compliant  
 NEMA® WD-6 Compliant

## Specifications

Housing/Cord Clamp	Nylon
Blade Holder	Nylon
Terminal Retainer	Clear Polycarbonate
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

## Performance

### Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

### Mechanical


Terminal Accommodation	#18-10 AWG. Standed copper wire only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

### Environmental



Flammability	UL 94 HB or better
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)



AGENCY LISTING  
 PER TABLE

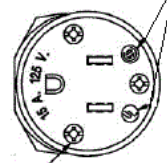

ALL SCREWS ARE  
 COMBINATION  
 ROBERTSON/PHILLIPS/  
 SLOTTED HEAD

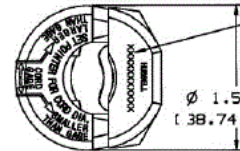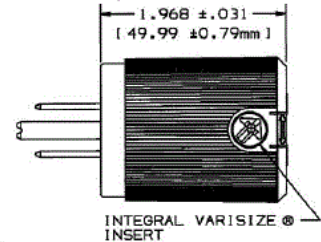

CATALOG NUMBER  
 (HBL5266CM2 &  
 HBL5266EBK NOT  
 MARKED)

∅ 1.527 ± 0.015  
 [ 38.74 ± 0.38mm ]

## Accessories

Weatherproof Boot	HBL6017
-------------------	---------

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

