



NO HOUSING REQUIRED
Repositionable driver j-box included



We've added three levels of lumen select to our popular HLB Series. Now you can select from three different levels of brightness based on your ceiling height and lighting needs.

This HLB update also expanded your color options with selectable color temperature from soft white, bright white, true white, cool white and daylight.

HLB's precision acrylic lens also helps reduce glare, making your living space more comfortable.

Product Features

- Round 4" & 6" slim canless downlight suitable for installation in IC (insulation contact) or non-IC applications
- Ultra-thin 1/2" fixture installs virtually anywhere with canless springs - NO HOUSING REQUIRED
- **Lens & Trim:** Slim die-cast aluminum trim with prismatic lens
- **Color Temperature (CCT):** 5-color Field-SeleCCTable (2700K, 3000K, 3500K, 4000K, 5000K); 90+ CRI
- **Brightness (Lumens):** Lumen Select switch – 4" - 700/850/1000 lumens / 6" - 800/1000/1200 lumens
- **Dimming:** Dims to 5% (phase cut LE/TE); 120V input
- AIR-TITE, wet location-listed, and ENERGY STAR®
- 50,000 hrs of maintenance-free operation in damp or wet locations
- 5-year warranty



LEARN MORE




Personalize Your Lighting



Select the perfect color temperature for your space with 5 options: soft white, bright white, true white, cool white, daylight.



Choose between 3 brightness settings (low, medium, high) based on your ceiling or preferred light level.

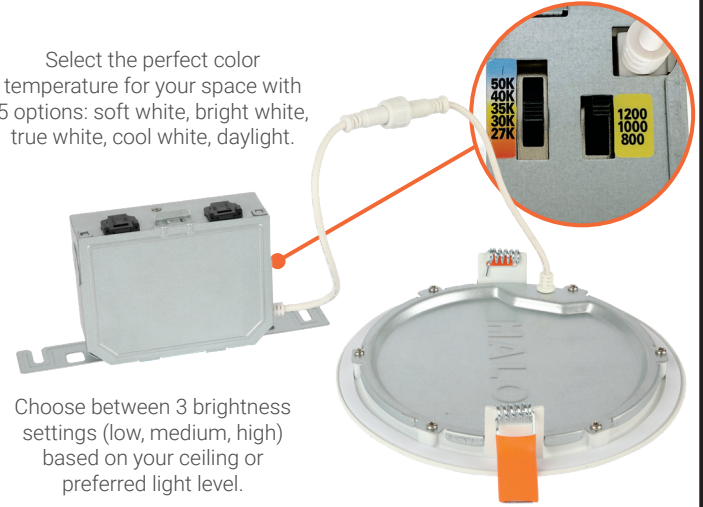

EASY CANLESS INSTALLATION

Mounts directly to ceiling



Order Information

4" Slim Canless

Catalog Number	Description	Lumens (nominal)	CRI	CCT	Driver	Finish	UPC
HLB4LSFS5	4-inch Round Slim Canless LED Downlight	700/850/1000 selectable lumens	90+ CRI	5-Color Field-SeleCCTable: 2700K, 3000K, 3500K, 4000K, 5000K	5% Phase Cut LE/TE Dimming, 120V 60Hz	Matte White	080083297306
HLB4LSFS5-C	4-inch Round Slim Canless LED Downlight (Canadian Version)	700/850/1000 selectable lumens	90+ CRI	5-Color Field-SeleCCTable: 2700K, 3000K, 3500K, 4000K, 5000K	5% Phase Cut LE/TE Dimming, 120V 60Hz	Matte White	080083297344

6" Slim Canless

Catalog Number	Description	Lumens (nominal)	CRI	CCT	Driver	Finish	UPC
HLB6LSFS5	6-inch Round Slim Canless LED Downlight	800/1000/1200 selectable lumens	90+ CRI	5-Color Field-SeleCCTable: 2700K, 3000K, 3500K, 4000K, 5000K	5% Phase Cut LE/TE Dimming, 120V 60Hz	Matte White	080083297320
HLB6LSFS5-C	6-inch Round Slim Canless LED Downlight (Canadian Version)	800/1000/1200 selectable lumens	90+ CRI	5-Color Field-SeleCCTable: 2700K, 3000K, 3500K, 4000K, 5000K	5% Phase Cut LE/TE Dimming, 120V 60Hz	Matte White	080083297368



Refer to ENERGY STAR® Certified Products List. Can be used to comply with California Title 24 High Efficacy requirements. Certified to California Appliance Efficiency Database under JAB.



Cooper Lighting Solutions
1121 Highway 74 South
Peachtree City, GA 30269
P: 770-486-4800
cooperlighting.com

Canada Sales
5925 McLaughlin Road
Mississauga, Ontario L5R 1B8
P: 905-501-3000
F: 905-501-3172

© 2025 Cooper Lighting Solutions
All Rights Reserved
Publication No. BR51878425
March 19, 2025 4:04 PM

Product availability, specifications, and compliances are subject to change without notice.