

BURNDY Catalog Number
UPC Number
Description
Status

KA25U
 7818103701933
 14STR-1/0STR DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.63
 Length (in) 1.50
 Bolt Hole Size (in) 0.25
 Thickness 0.19
 D - in 0.81
 Pad Width (in) 0.63
 N (in) 0.44

General

Number of Conductors 1
 Number of Holes 1
 Product Description Aluminum Universal Terminal, 1 Hole, 14-1/0 AWG (Str), 1/4" Stud, 1 Screw, Al/Cu Rated, Tin Plated

Conductor(s)

Aluminum Size (Range) 14 STR- 1/0 STR
 Copper Solid Size (Range) 12 AWG-1/0 AWG
 Copper Stranded (Range) 14 AWG-1/0

Physical

Installation Torque 50
 Type of Plating Tin
 Connector Type Terminal
 Bolt Hole Size 1/4
 Plated (Yes or No) Y
 Product Material Aluminum

Approvals / Certifications

Rated for Direct Burial N
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Exempt
 Industry Standards UL468A-468B

Documentation

For further technical assistance, please contact us



BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

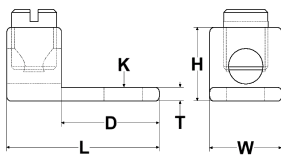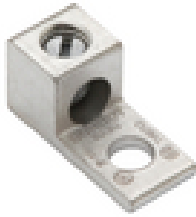

BURNDY Catalog Number
UPC Number
Description
Status

KA25U
 7818103701933
 14STR-1/0STR DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in)	0.63
Length (in)	1.50
Bolt Hole Size (in)	0.25
Thickness	0.19
D - in	0.81
Pad Width (in)	0.63
N (in)	0.44

General

Number of Conductors	1
Number of Holes	1
Product Description	Aluminum Universal Terminal, 1 Hole, 14-1/0 AWG (Str), 1/4" Stud, 1 Screw, Al/Cu Rated, Tin Plated

Conductor(s)

Aluminum Size (Range)	14 STR- 1/0 STR
Copper Solid Size (Range)	12 AWG-1/0 AWG
Copper Stranded (Range)	14 AWG-1/0

Physical

Installation Torque	50
Type of Plating	Tin
Connector Type	Terminal
Bolt Hole Size	1/4
Plated (Yes or No)	Y
Product Material	Aluminum

Approvals / Certifications

Rated for Direct Burial	N
UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
Industry Standards	UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175