

BURNDY Catalog Number
UPC Number
Description
Status

KS25
 7818100131066
 SERVIT 4 STR - 1/0 STR
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.73
 Size (Hex) or Size (Bolt) 3/4
 Cross Flats 0.94
 Size (Hex) or Size (Bolt) - in 0.750
 B Length (in) .83
 B Length (Fraction) 83/100

General

Product Description

Copper Split Bolt, Cu: 4 AWG-1/0 AWG (Str) (Run & Tap)

Conductor(s)

Copper Tap Range 14 AWG-1/0
 CopperWeld Solid Run Size (Range) 2/0
 Copper Stranded Run (Range) 4 AWG-1/0
 CopperWeld Stranded Tap Size (Range) 5 D AWG-2 A AWG
 Copper Solid Tap (Range) 14 AWG-1/0
 CopperWeld Solid Tap Size (Range) 2/0
 Copper Solid Run Size (Range) 4 AWG-1/0
 CopperWeld Stranded Run Size (Range) 4 D AWG-2 A AWG

Physical

Installation Torque 385
 Type of Plating Unplated
 Connector Type Split Bolt
 Plated (Yes or No) N
 Product Material Copper

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards RUS

Documentation

For further technical assistance, please contact us



BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

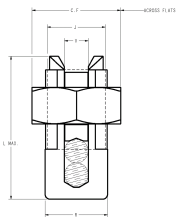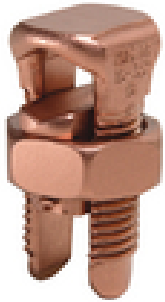

BURNDY Catalog Number
UPC Number
Description
Status

KS25
 7818100131066
 SERVIT 4 STR - 1/0 STR
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.73
 Size (Hex) or Size (Bolt) 3/4
 Cross Flats 0.94
 Size (Hex) or Size (Bolt) - in 0.750
 B Length (in) .83
 B Length (Fraction) 83/100

General

Product Description

Copper Split Bolt, Cu: 4 AWG-1/0 AWG (Str) (Run & Tap)

Conductor(s)

Copper Tap Range 14 AWG-1/0
 CopperWeld Solid Run Size (Range) 2/0
 Copper Stranded Run (Range) 4 AWG-1/0
 CopperWeld Stranded Tap Size (Range) 5 D AWG-2 A AWG
 Copper Solid Tap (Range) 14 AWG-1/0
 CopperWeld Solid Tap Size (Range) 2/0
 Copper Solid Run Size (Range) 4 AWG-1/0
 CopperWeld Stranded Run Size (Range) 4 D AWG-2 A AWG

Physical

Installation Torque 385
 Type of Plating Unplated
 Connector Type Split Bolt
 Plated (Yes or No) N
 Product Material Copper

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards RUS

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175