



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED5PAR20-F-8XX

REPLACEMENT LAMP

DESCRIPTION

5.5W PAR20 Lamp | 2700–5000K | >80 CRI | Standard Flood



Enclosed
Fixture Rated



RoHS
Compliant

3YEAR
WARRANTY

LAMP TYPE: PAR20
BASE TYPE: E26 (Medium)
WATTAGE: 5.5W
COLOR TEMPERATURE: 2700–5000K
COLOR RENDERING INDEX (CRI): >80
WARRANTY: 3 Years
RATED LIFE: L70 (25,000 Hours)



TYPICAL APPLICATIONS

- Track-lighting
- Display
- Flood- and spot-lighting
- Outdoor fixtures

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- PF: >0.70
- Complies with Part 15 of FCC
- Smooth, uniform dimming
- Precision-crafted, full-face optics for precise beam angle control
- Durable plastic housing lowers the risk for breakage
- Operating temperature range: –4°F/–20°C to 113°F/45°C
- Long life minimizes replacement and maintenance costs
- ANSI compliant construction ensures fitment for intended applications
- Meets Energy Star requirements
- UL Listed
- Rated for use in damp and wet locations
- Suitable for use in open, enclosed, and recessed fixtures

ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	Energy Star CBCP	CRI	Beam Angle	Dimmable	Efficacy
KT-LED5PAR20-F-827	PAR20 bulb; Standard flood; Dimmable	2700K	120V	5.5W	50W halogen	E26	500 lm	935	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-830	PAR20 bulb; Standard flood; Dimmable	3000K	120V	5.5W	50W halogen	E26	500 lm	910	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-840	PAR20 bulb; Standard flood; Dimmable	4000K	120V	5.5W	50W halogen	E26	500 lm	1011	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-850	PAR20 bulb; Standard flood; Dimmable	5000K	120V	5.5W	50W halogen	E26	500 lm	1051	>80	40°	Yes	91 lm/W




ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED5PAR20-F-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

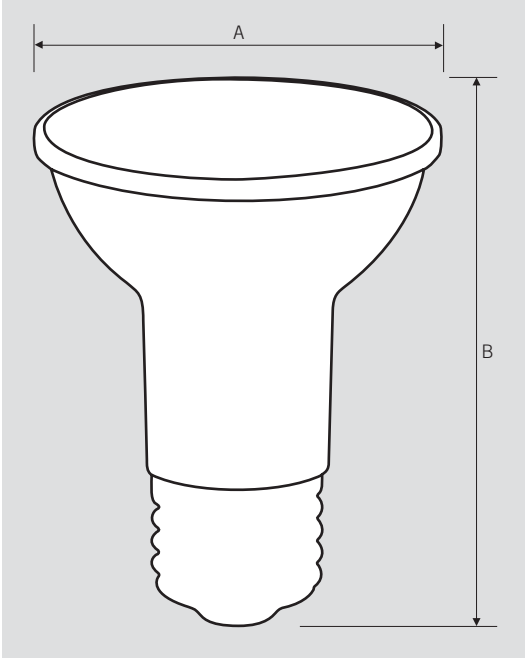

LAMP DIMENSIONS

A (Diameter)	2.52"
B (Length)	3.23"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	12.01" x 9.06" x 9.45"
Carton Weight	5.56 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ENERGY STAR UNIQUE ID	EASY CODE	UPC
KT-LED5PAR20-F-827	24 pcs	2353377	RKN-80	843654127392
KT-LED5PAR20-F-830	24 pcs	2353369	GLM-33	843654127408
KT-LED5PAR20-F-840	24 pcs	2353370	YRY-69	843654127415
KT-LED5PAR20-F-850	24 pcs	2353378	PLZ-87	843654127422

CATALOG NUMBER BREAKDOWN

KT-LED5PAR20-F-8XX

1 2 3 4 5 6 7

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Standard Flood
- 6 800 Series
- 7 Color Temperature



ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED5PAR20-F-8XX

REPLACEMENT LAMP

DESCRIPTION

5.5W PAR20 Lamp | 2700–5000K | >80 CRI | Standard Flood



Enclosed
Fixture Rated



RoHS
Compliant

3YEAR
WARRANTY

LAMP TYPE: PAR20
BASE TYPE: E26 (Medium)
WATTAGE: 5.5W
COLOR TEMPERATURE: 2700–5000K
COLOR RENDERING INDEX (CRI): >80
WARRANTY: 3 Years
RATED LIFE: L70 (25,000 Hours)

TYPICAL APPLICATIONS

- Track-lighting
- Display
- Flood- and spot-lighting
- Outdoor fixtures

PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- PF: >0.70
- Complies with Part 15 of FCC
- Smooth, uniform dimming
- Precision-crafted, full-face optics for precise beam angle control
- Durable plastic housing lowers the risk for breakage
- Operating temperature range: –4°F/–20°C to 113°F/45°C
- Long life minimizes replacement and maintenance costs
- ANSI compliant construction ensures fitment for intended applications
- Meets Energy Star requirements
- UL Listed
- Rated for use in damp and wet locations
- Suitable for use in open, enclosed, and recessed fixtures

ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	Energy Star CBCP	CRI	Beam Angle	Dimmable	Efficacy
KT-LED5PAR20-F-827	PAR20 bulb; Standard flood; Dimmable	2700K	120V	5.5W	50W halogen	E26	500 lm	935	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-830	PAR20 bulb; Standard flood; Dimmable	3000K	120V	5.5W	50W halogen	E26	500 lm	910	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-840	PAR20 bulb; Standard flood; Dimmable	4000K	120V	5.5W	50W halogen	E26	500 lm	1011	>80	40°	Yes	91 lm/W
KT-LED5PAR20-F-850	PAR20 bulb; Standard flood; Dimmable	5000K	120V	5.5W	50W halogen	E26	500 lm	1051	>80	40°	Yes	91 lm/W




ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED5PAR20-F-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

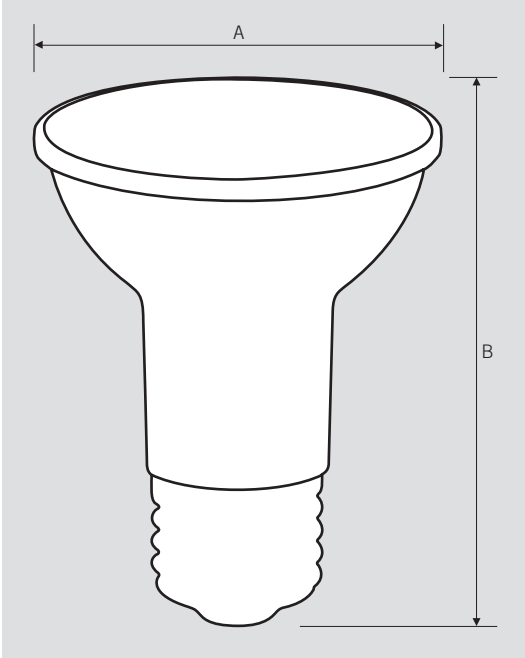

LAMP DIMENSIONS

A (Diameter)	2.52"
B (Length)	3.23"

BASE TYPE: E26 (Medium)

PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	12.01" x 9.06" x 9.45"
Carton Weight	5.56 lbs

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ENERGY STAR UNIQUE ID	EASY CODE	UPC
KT-LED5PAR20-F-827	24 pcs	2353377	RKN-80	843654127392
KT-LED5PAR20-F-830	24 pcs	2353369	GLM-33	843654127408
KT-LED5PAR20-F-840	24 pcs	2353370	YRY-69	843654127415
KT-LED5PAR20-F-850	24 pcs	2353378	PLZ-87	843654127422

CATALOG NUMBER BREAKDOWN

KT-LED5PAR20-F-8XX

1 2 3 4 5 6 7

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Standard Flood
- 6 800 Series
- 7 Color Temperature