

KT-LED9.5A19-0-8XX

REPLACEMENT LAMP

DESCRIPTION

9.5W A19 Lamp | 2700–5000K | >80 CRI | Omni-Directional



RoHS
Compliant

2YEAR
WARRANTY

LAMP TYPE: A19
BASE TYPE: E26 (Medium)
WATTAGE: 9.5W
COLOR TEMPERATURE: 2700–5000K
COLOR RENDERING INDEX (CRI): >80
WARRANTY: 2 Years
RATED LIFE: L70 (15,000 Hours)



TYPICAL APPLICATIONS

- Table, Desk, and Floor Lamps
- Wall Sconces
- Surface Mount Ceiling Fixtures
- General Lighting
- Pendant Lights

PRODUCT FEATURES

- Energy Efficient, 80%+ Energy Savings over Legacy Equivalents
- Lower Heat Generation than Legacy Equivalents
- PF >0.70
- Complies with Part 15 of FCC
- Durable Plastic housing lowers the risk for breakage
- ANSI complaint construction ensures fitment for intended applications
- Operating temperature range –4°F/–20°C to 95°F/35°C
- Long Life minimizes replacement and maintenance costs
- Meets Energy Star requirements
- UL Listed
- Smooth diffused lens for comfortable glare free performance
- UL enclosed rated, suitable for use in totally enclosed luminaires
- Smooth, uniform dimming

ELECTRICAL AND PERFORMANCE SPECIFICATIONS

Keystone Catalog Number	Description	Color Temp	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Base Type	Lumens	CRI	Light Distribution	Dimmable	Efficacy
KT-LED9.5A19-0-827	A19 bulb. Omni-Directional, dimmable	2700K	120V	9.5W	60W halogen	E26	800	>80	230°	Yes	84 lm/W
KT-LED9.5A19-0-830	A19 bulb. Omni-Directional, dimmable	3000K	120V	9.5W	60W halogen	E26	800	>80	230°	Yes	84 lm/W
KT-LED9.5A19-0-835	A19 bulb. Omni-Directional, dimmable	3500K	120V	9.5W	60W halogen	E26	800	>80	230°	Yes	84 lm/W
KT-LED9.5A19-0-840	A19 bulb. Omni-Directional, dimmable	4000K	120V	9.5W	60W halogen	E26	800	>80	230°	Yes	84 lm/W
KT-LED9.5A19-0-850	A19 bulb. Omni-Directional, dimmable	5000K	120V	9.5W	60W halogen	E26	800	>80	230°	Yes	84 lm/W




ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

KT-LED9.5A19-0-8XX

REPLACEMENT LAMP

PHYSICAL CHARACTERISTICS

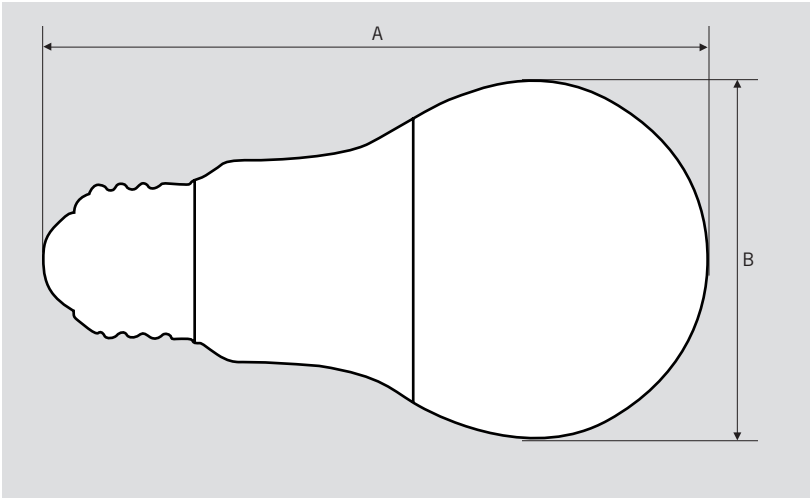

PACKAGING

Carton Quantity	60 pcs
Carton Dimensions	15.55" x 13.07" x 10"
Carton Weight	9.9 lbs

LAMP DIMENSIONS

A (Length)	4.33"
B (Diameter)	2.36"

BASE TYPE: E26 (Medium)

ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS
KT-LED9.5A19-0-8XX	60 pcs	Active

CATALOG NUMBER BREAKDOWN

KT-LED9.5A19-0-8XX

- 1
- 2
- 3
- 4
- 5
- 6
- 7

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Lamp Shape
- 5 Omni-Directional
- 6 800 Series
- 7 Color Temperature