



Light your path and enhance your outdoor space with durable die cast metal LED pathway lights that are built to withstand the elements. Available in full cutoff, 1 tier and 2 tier models, FERN is equivalent to 20W halogen and has a 100,000 hour LED lifespan.

Color: Bronze

Weight: 4.7 lbs

<b>Project:</b>	<b>Type:</b>
<b>Prepared By:</b>	<b>Date:</b>

Driver Info		LED Info	
Type	Constant Current	Watts	6W
120V	N/A	Color Temp	2700K (Residential Warm)
208V	N/A	Color Accuracy	81 CRI
240V	N/A	L70 Lifespan	100,000 Hours
277V	N/A	Lumens	292
Input Watts	5.8W	Efficacy	50.3 lm/W

**Technical Specifications**

**Compliance**

**UL Listed:**

Suitable for wet locations. Suitable for mounting within 4 feet of the ground.

**IESNA LM-79 & LM-80 Testing:**

RAB LED luminaires and LED components have been tested by an independent laboratory in accordance with IESNA LM-79 and LM-80.

**Construction**

**IP Rating:**

Ingress protection rating of IP66 for dust and water

**Cold Weather Starting:**

The minimum starting temperature is -30°C/-34°F

**Housing:**

Precision die-cast aluminum housing

**Lens:**

Clear polycarbonate

**Mounting:**

18" stem with 1/2" NPS thread on both ends. Mounts to sturdy plastic pike to ground mount (included).

**Green Technology:**

Mercury and UV free. RoHS-compliant components.

**Gaskets:**

High-temperature silicone gaskets

**Finish:**

Formulated for high durability and long-lasting color

**Electrical**

**System Transformer:**

No driver needed. Multi-tap magnetic transformer with 60 Hz only (sold separately). 054A.

**Performance**

**Lifespan:**

100,000-Hour LED lifespan based on IES LM-80 results and TM-21 calculations

**LED Characteristics**

**LEDs:**

Long-life, high-efficacy, surface-mount LEDs

**Color Stability:**

LED color temperature is warrantied to shift no more than 200K in color temperature over a 5-year period

**Technical Specifications (continued)**

**LED Characteristics**

**Color Uniformity:**

RAB's range of Correlated Color Temperature follows the guidelines of the American National Standard for Specifications for the Chromaticity of Solid State Lighting (SSL) Products, ANSI C78.377-2017.

**Other**


**Warranty:**

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of five (5) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at [rablighting.com/warranty](http://rablighting.com/warranty).

**Buy American Act Compliance:**

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

**Dimensions**

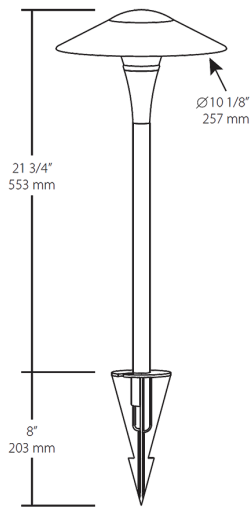

**Features**

- Compatible with 12VAC systems
- Includes 8" ground spike
- 100,000-Hour lifespan

**Ordering Matrix**

Family	Tiers	LED	Wattage	Color Temp	Finish
LL	1	LED	6LV	YY	A

FC = Full Cutoff  
 1 = 1 Tier  
 2 = 2 Tiers

LED = LED    6LV = 6W 12VAC    YY = 2700K (Residential Warm)

A = Bronze  
 B = Black  
 D = Sand  
 W = White  
 VG = Verde Green