


NEW!
Now in
STEEL

Steel and Stainless Steel Low Profile Cord Grips

Oil- and Liquid-tight Seal, Widest Cable Range in Industry

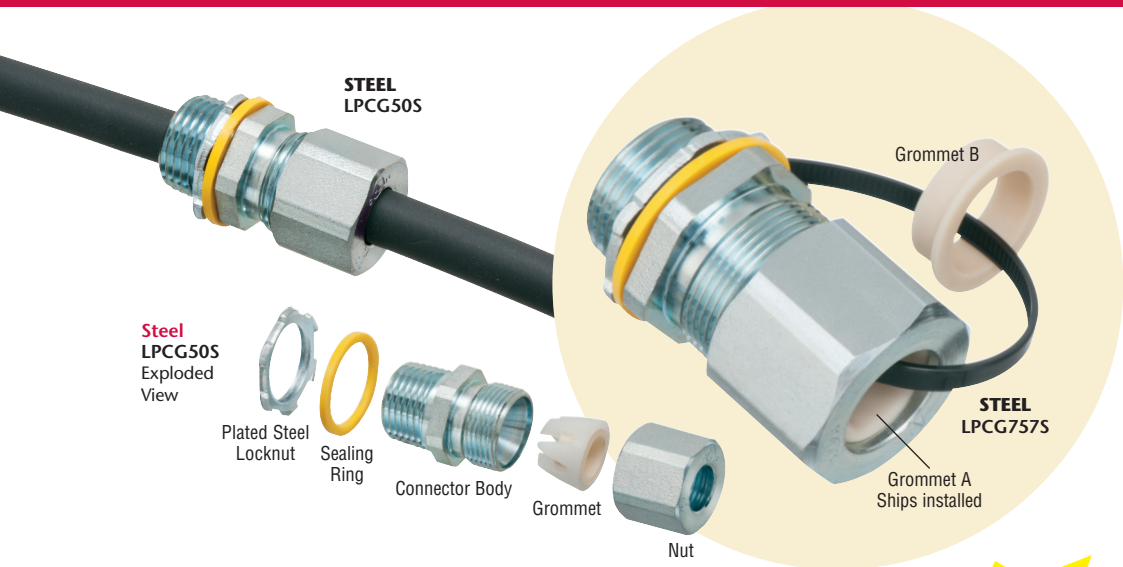


Arlington now offers **zinc-plated STEEL** and **STAINLESS STEEL** low profile, strain-relief cord grips in addition to its zinc and non-metallic cord grips.

These steel connectors offer the *widest cord ranges in the industry*, so you'll have fewer items to stock.

And, they deliver superior pullout resistance. The unique nylon gripper squeezes onto the cable or cord when the nut is tightened, locking the cord firmly in place. A sealing ring assures a liquid- and oil-tight seal.

Steel
LPCG505
Exploded
View

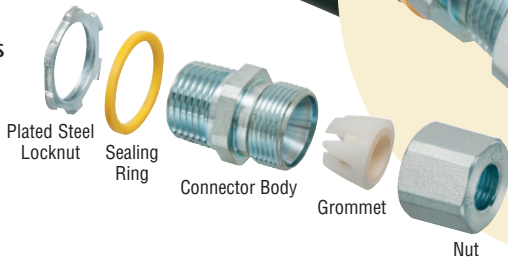

STEEL
LPCG7575

Grommet A
Ships installed

Nut



LPCG503S



LPCG507S

ZINC-PLATED STEEL STRAIN-RELIEF CORD CONNECTORS

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	CORD RANGE (DIA.)	UNIT PKG	STD PKG
LPCG503S*	12788	1/2"	.100 to .360	25	100
LPCG505	12787	1/2"	.200 to .485	25	100
LPCG507S	12789	1/2"	.385 to .600	25	100
LPCG753S*	12790	3/4"	.100 to .360	10	50
LPCG754S	12791	3/4"	.200 to .485	10	50
LPCG757S	12792	3/4"	Grommet A .385 to .600 Grommet B .600 to .750	10	50

NEW!
STEEL



LPCG753S



Grommet before
tightening



Grommet tightened
*stainless steel shown

**Unique cord gripping action...
Widest cable range means
fewer items to stock.**

* UL listing not applicable for cords under .200" diameter.
Wire strength will not meet UL 35 lb test requirements for the fitting.

These connectors are suitable for Class I, Division I and II locations when installed in accordance with NEC Articles 501.10 (b) and 501.10 (2) and where allowed under Article 510.140



Stainless Steel Connector and Locknut
LPCG757SS Exploded View



LPCG505S



LPCG507SS

304 STAINLESS STEEL STRAIN-RELIEF CORD CONNECTORS with STAINLESS STEEL LOCKNUTS

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	CORD RANGE (DIA.)	UNIT PKG	STD PKG
LPCG503SS*	12794	1/2"	.100 to .360	25	100
LPCG505SS	12793	1/2"	.200 to .485	25	100
LPCG507SS	12795	1/2"	.385 to .600	25	100
LPCG753SS*	12796	3/4"	.100 to .360	10	50
LPCG754SS	12797	3/4"	.200 to .485	10	50
LPCG757SS	12798	3/4"	Grommet A .385 to .600 Grommet B .600 to .750	10	50

NEW!
STAINLESS
STEEL



LPCG753SS



LPCG757SS

Grommet B

Grommet A
Ships installed

**304 Stainless Steel delivers
extra corrosion protection!**

See reverse for zinc and non-metallic
cord grips.

Patents pending



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717 • Fax 570/562.0646
www.aifittings.com

PLASTIC and ZINC Strain-Relief, Low Profile Cord Grips


Widest Cord Range • Low Profile, Oil- and Liquid-tight Seal



In addition to STEEL and STAINLESS STEEL Arlington offers low profile, strain-relief cord grips in zinc and non-metallic styles.

They also offer the largest cord range in the industry at the lowest cost, so you'll save on inventory.

- Superior pullout resistance
Nylon gripper squeezes onto cord as nut is tightened

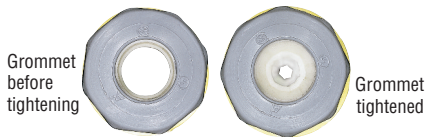

- Sealing ring assures liquid- and oil-tight seal when installing in non-threaded openings
- UL/CSA Listed



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717 • Fax 570/562.0646
www.aifittings.com


NON-METALLIC LOW PROFILE, STRAIN-RELIEF CORD CONNECTORS

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	CORD RANGE (DIA.)	UNIT PKG	STD PKG
LPCG503*	50350	1/2"	.100 to .360	25	100
LPCG50	80086	1/2"	.200 to .485	25	100
LPCG507	50354	1/2"	.385 to .600	25	100
LPCG753*	50760	3/4"	.100 to .360	10	50
LPCG754	50762	3/4"	.200 to .485	10	50
LPCG757	36100	3/4"	Grommet A .385 to .600 Grommet B .600 to .750	10	50

* UL listing not applicable for cords under .200" diameter.
Wire strength will not meet UL 35 lb test requirements for the fitting.

To order in **BLACK**, add suffix 'BL' to catalog number, i.e. LPCG50BL.

To order in **WHITE**, add suffix 'W' to catalog number, i.e. LPCG50W.

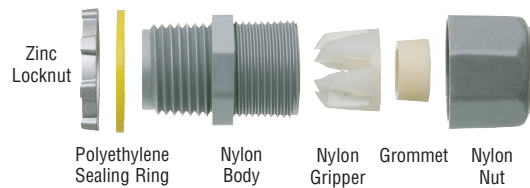

LPCG50 Exploded View




To order white, add suffix 'W' to catalog number

ZINC DIECAST LOW PROFILE, STRAIN-RELIEF CORD CONNECTORS

CATALOG NUMBER	UPC/DCI/NAED MFG #01 8997	TRADE SIZE	CORD RANGE (DIA.)	UNIT PKG	STD PKG
LPCG503Z*	50352	1/2"	.100 to .360 Dia.	25	100
LPCG50Z*	36110	1/2"	.200 to .485 Dia.	25	100
LPCG507Z	50356	1/2"	.385 to .600 Dia.	25	100
LPCG753Z*	36105	3/4"	.100 to .360 Dia.	10	50
LPCG754Z	50764	3/4"	.200 to .485 Dia.	10	50
LPCG757Z	50766	3/4"	Grommet A .385 to .600 Grommet B .600 to .750	10	50

* UL listing not applicable for cords under .200" diameter.
Wire strength will not meet UL 35 lb test requirements for the fitting.

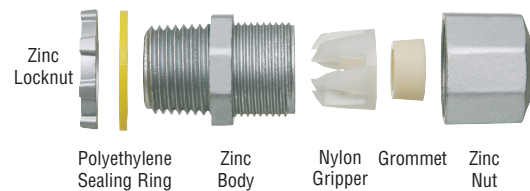

LPCG50Z Exploded View



Distributed by