




## MC/AC CABLE TO FLANGE CLIP, BOTTOM MOUNT, 1/8"–1/4" FLANGE, 14-2 TO 10-3 MC/AC

### CATALOG NUMBER

**MAC224**

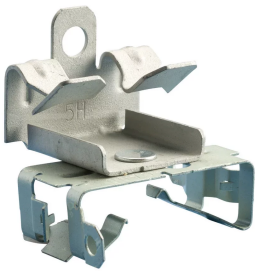

### CERTIFICATIONS



### FEATURES

Compliant with NEC® Article 300.4(d), allowing cable to be positioned a minimum of 1-1/4" from face of stud

Compliant with CEC Rule 12-618 for support of MC/AC cable

### PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

Flange Thickness: 1/8"

MC/AC Cable Size: 14-2 to 10-3

Outer Diameter: 0.6" Max

### ADDITIONAL PRODUCT DETAILS

Assemblies allow for support from most main and substructures.

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500




Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



## MC/AC CABLE TO FLANGE CLIP, BOTTOM MOUNT, 1/8"–1/4" FLANGE, 14-2 TO 10-3 MC/AC

### CATALOG NUMBER

**MAC224**

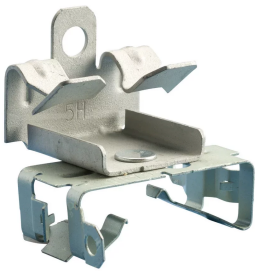

### CERTIFICATIONS



### FEATURES

Compliant with NEC® Article 300.4(d), allowing cable to be positioned a minimum of 1-1/4" from face of stud

Compliant with CEC Rule 12-618 for support of MC/AC cable

### PRODUCT ATTRIBUTES

Material: Spring Steel

Finish: nVent CADDY Armour

Flange Thickness: 1/8"

MC/AC Cable Size: 14-2 to 10-3

Outer Diameter: 0.6" Max

### ADDITIONAL PRODUCT DETAILS

Assemblies allow for support from most main and substructures.

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**