




**METALLIC LOW PROFILE WIU COVERS**

**Single Gang Metal Low Profile WhileInUse Covers Extra Duty®  
Vertical 8-in-1 Deep**

**C11**

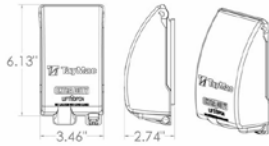

Catalog #: MX5280S

**APPLICATIONS**

Designed for use whenever weatherproof protection is required while an outlet is in use.

**PRODUCT FEATURES**

- Revolutionary patented design expands from 2-1/2 in. to 4-1/2 in. for in-use needs
- Heavy duty die-cast metal construction
- Patented QuickFit™ keyhole mounting system allows installation in under a minute.
- Pre-configured for GFCI with patented Knockout technology for alternate devices
- Includes attached gasket and mounting hardware
- Lockable tab
- Premium Powder Coat

**UL LISTED**

File E212332

**NEMA**

3R Rated

**NEC**

2014 Compliant (article 406.9A & B) Extra Duty Rated

**US PATENTS**

8,314,334; 8,259,253 B1; 6,420,654; 8,106,295 B1

**GENERAL PRODUCT INFORMATION**

Color: Gray

**CONFIGURATION**

Gangs: 1

**PRODUCT MEASUREMENTS**

Depth: 2-1/2 in. to 4-1/2 in.  
Wt. Ea. (Lbs.): 0.900

**PACKAGING**


Package Type: Shrink  
 Std. Pkg.: 2  
 Product UPC-A Labeled: Yes  
 Weight (Lbs. Per/C): 90.00  
 Ship Carton Length (in.): 6.13  
 Ship Carton Width (in.): 4.13  
 Ship Carton Height (in.): 7.13  
 Ctn Weight (Lbs.): 1.80  
 Pallet Qty: 620  
 UPC Number: 092326101356  
 I2of5: 30092326101357



**METALLIC LOW PROFILE WIU COVERS**

**Single Gang Metal Low Profile WhileInUse Covers Extra Duty®  
Vertical 8-in-1 Deep**

**C11**

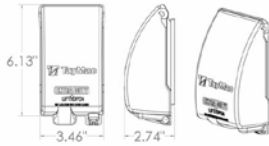

Catalog #: MX5280S

**APPLICATIONS**

Designed for use whenever weatherproof protection is required while an outlet is in use.

**PRODUCT FEATURES**

- Revolutionary patented design expands from 2-1/2 in. to 4-1/2 in. for in-use needs
- Heavy duty die-cast metal construction
- Patented QuickFit™ keyhole mounting system allows installation in under a minute.
- Pre-configured for GFCI with patented Knockout technology for alternate devices
- Includes attached gasket and mounting hardware
- Lockable tab
- Premium Powder Coat

**UL LISTED**

File E212332

**NEMA**

3R Rated

**NEC**

2014 Compliant (article 406.9A & B) Extra Duty Rated

**US PATENTS**

8,314,334; 8,259,253 B1; 6,420,654; 8,106,295 B1

**GENERAL PRODUCT INFORMATION**

Color: Gray

**CONFIGURATION**

Gangs: 1

**PRODUCT MEASUREMENTS**

Depth: 2-1/2 in. to 4-1/2 in.  
Wt. Ea. (Lbs.): 0.900

**PACKAGING**

Package Type: Shrink  
 Std. Pkg.: 2  
 Product UPC-A Labeled: Yes  
 Weight (Lbs. Per/C): 90.00  
 Ship Carton Length (in.): 6.13  
 Ship Carton Width (in.): 4.13  
 Ship Carton Height (in.): 7.13  
 Ctn Weight (Lbs.): 1.80  
 Pallet Qty: 620  
 UPC Number: 092326101356  
 I2of5: 30092326101357