


NMLT90125

90 Degree Non-Metallic Connectors

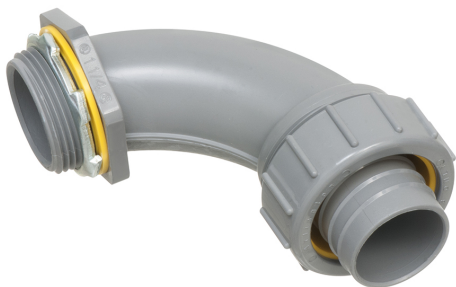

90 Degree Non-Metallic Connector

Country of Origin: USA

Weight: 0.320 lbs/each

Height: 4.650"

Width: 3.420"

Material(s): UV-Rated Plastic

Conduit Type: Non-Metallic Liquid Tight Conduit, Type B Only

Knockout Size(s): 1-1/4"

Trade Size: 1-1/4"

Packaging

Unit: 5 pcs

Standard: 25 pcs




Arlington[®]

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com

NMLT90125

90 Degree Non-Metallic Connectors

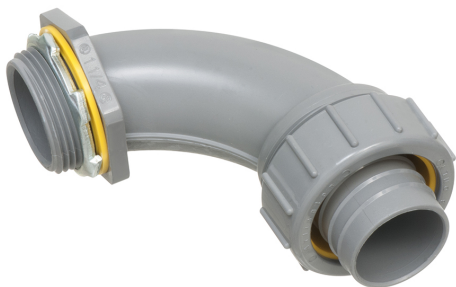

90 Degree Non-Metallic Connector

Country of Origin: USA

Weight: 0.320 lbs/each

Height: 4.650"

Width: 3.420"

Material(s): UV-Rated Plastic

Conduit Type: Non-Metallic Liquid Tight Conduit, Type B Only

Knockout Size(s): 1-1/4"

Trade Size: 1-1/4"

Packaging

Unit: 5 pcs

Standard: 25 pcs



Arlington®

1 Stauffer Industrial Park
Scranton, PA 18517
800/233.4717
Fax 570/562.0646
www.aifittings.com