


| | | | | | |
|-------------|--|-----------|--|------|--|
| Project | | Catalog # | | Type | |
| Prepared by | | Notes | | Date | |

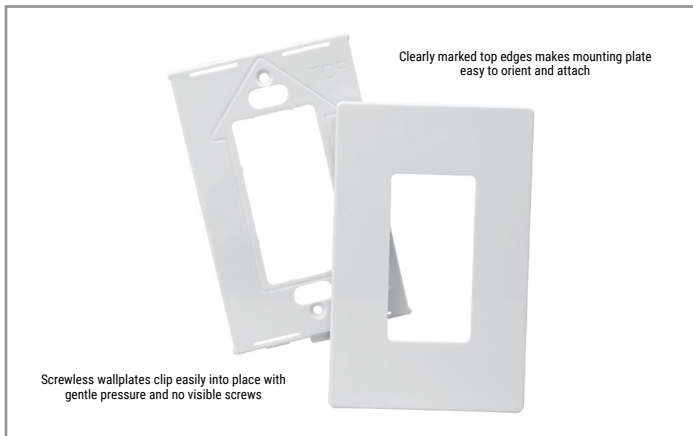

Greengate

Screwless wallplates

System accessory for Greengate wall box devices

Typical Applications
Office • Education • Healthcare • Hospitality • Retail • Industrial • Manufacturing


Interactive Menu

- Order Information page 2
- Additional Resources page 3
- Product Warranty


Top Product Features

- The wallplate fits a standard decorator opening or toggle opening and provides a contemporary, sleek design
- Screwless Wallplates clip easily into place with gentle pressure
- Virtually unbreakable polycarbonate construction
- Mid-sized to cover wall imperfections and large wallboard openings
- Available in multi-gang configurations
- Available in a variety of colors
- Meets flammability requirements per UL 94, V2 rated

Dimensional Details

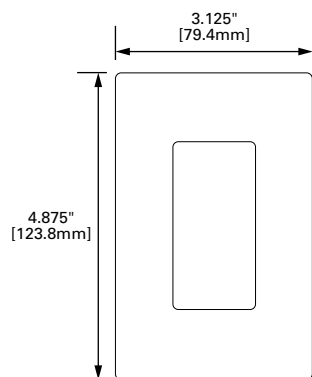


Decorator Wallplates can be used with:
Occupancy and Vacancy sensors, GDS, GMDS,
Automatic Turn-Off switches and 0-10V slide dimmers

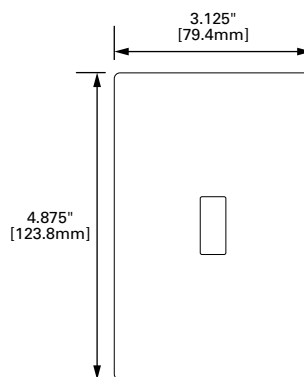

Toggle Wallplates can be used with:
Momentary toggle switches,
Automatic Turn-Off switches

Mounting Height

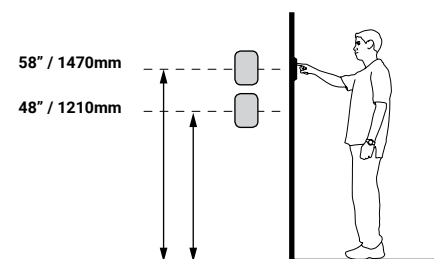

[additional product diagrams](#)

Order Information

This is an accessory for the Greengate Lighting Control System.

Decorator Wallplates

Can be used with: Occupancy and Vacancy sensors, GDS, GMDS, Automatic Turn-Off switches and 0-10V slide dimmers

Catalog Number

| Catalog Number | Gang | Color | Description |
|----------------|--------|-------|--|
| PJS26W | 1-Gang | White | Single Gang, Screwless Decorator Wallplate |
| PJS26V | 1-Gang | Ivory | Single Gang, Screwless Decorator Wallplate |
| PJS26GY | 1-Gang | Gray | Single Gang, Screwless Decorator Wallplate |
| PJS26BK | 1-Gang | Black | Single Gang, Screwless Decorator Wallplate |
| PJS262W | 2-Gang | White | Two Gang, Screwless Decorator Wallplate |
| PJS262V | 2-Gang | Ivory | Two Gang, Screwless Decorator Wallplate |
| PJS262BK | 2-Gang | Black | Two Gang, Screwless Decorator Wallplate |
| PJS263W | 3-Gang | White | Three Gang, Screwless Decorator Wallplate |
| PJS263V | 3-Gang | Ivory | Three Gang, Screwless Decorator Wallplate |
| PJS263BK | 3-Gang | Black | Three Gang, Screwless Decorator Wallplate |
| PJS264W | 4-Gang | White | Four Gang, Screwless Decorator Wallplate |
| PJS264V | 4-Gang | Ivory | Four Gang, Screwless Decorator Wallplate |
| PJS264BK | 4-Gang | Black | Four Gang, Screwless Decorator Wallplate |
| PJS265W | 5-Gang | White | Five Gang, Screwless Decorator Wallplate |
| PJS265V | 5-Gang | Ivory | Five Gang, Screwless Decorator Wallplate |
| PJS265BK | 5-Gang | Black | Five Gang, Screwless Decorator Wallplate |
| PJS266W | 6-Gang | White | Six Gang, Screwless Decorator Wallplate |
| PJS266V | 6-Gang | Ivory | Six Gang, Screwless Decorator Wallplate |
| PJS266BK | 6-Gang | Black | Six Gang, Screwless Decorator Wallplate |

Toggle Wallplates

Can be used with: Momentary toggle switches, Automatic Turn-Off switches

Catalog Number

| Catalog Number | Gang | Color | Description |
|----------------|--------|-------|---|
| PJS1W | 1-Gang | White | Single Gang, Screwless Toggle Wallplate |
| PJS1V | 1-Gang | Ivory | Single Gang, Screwless Toggle Wallplate |
| PJS2W | 2-Gang | White | Two Gang, Screwless Toggle Wallplate |
| PJS2V | 2-Gang | Ivory | Two Gang, Screwless Toggle Wallplate |
| PJS3W | 3-Gang | White | Three Gang, Screwless Toggle Wallplate |
| PJS3V | 3-Gang | Ivory | Three Gang, Screwless Toggle Wallplate |
| PJS4W | 4-Gang | White | Four Gang, Screwless Toggle Wallplate |
| PJS4V | 4-Gang | Ivory | Four Gang, Screwless Toggle Wallplate |

Product Specifications

Key Features

- Screwless wallplates appear to float freely on the surface of the wall and are designed for easy and fast installation
- Mounting plate attaches to the device and the wallplate is simply pressed into place

Mechanical

Size:

- **Decorator Opening Dimensions:** 2.64"H x 1.31"W (67.1mm x 33.3mm)
- **Toggle Opening Dimensions:** 1"H x 0.5"W (25.4mm x 12.7mm)

- **1-Gang:** 4.88"H x 3.13"W (123.8mm x 79.4mm)
- **2-Gang:** 4.88"H x 4.95"W (123.8mm x 125.4mm)
- **3-Gang:** 4.88"H x 6.76"W (123.8mm x 171.4mm)
- **4-Gang:** 4.88"H x 8.57"W (123.8mm x 217.5mm)
- **5-Gang:** 4.88"H x 10.38"W (123.8mm x 263.5mm)
- **6-Gang:** 4.88"H x 12.19"W (123.8mm x 309.5mm)

Environment:

- **Operating temperature:** -40°F to 149°F (-40°C to 65°C)
- For indoor use only

Mounting: This system accessory will require wall mounting at the site.

Color: White, Ivory, Gray & Black

Housing: Polycarbonate

Standards/Ratings

Flammability:

- Meets UL 94 requirements
- V2 rated

Warranty

Consult website for warranty information



Control Systems

- Greengate