




# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

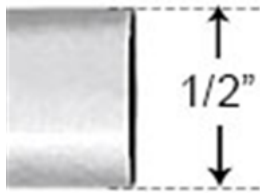

## PVC12 SCH 40 1/2" 10' PVC Conduit

*Heritage Plastics*

Catalog Number	PVC12
Manufacturer	Heritage Plastics
Description	PVC Conduit, Underground or Aboveground Application, Gray Color, 0.578 In Conduit Inner Diameter, 0.840 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 6000 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 1/2 In Trade Size, 0.109 In Wall Thickness, 0.162 LB Weight
Weight per unit	0.1620 (lbs/each)
Product Category	PVC Conduit, Fittings, & Boxes

### Dimensions and Weight

Diameter	1/2"
Size	1/2

### Descriptions

Description	SCH 40 1/2" 10' PVC CONDUIT
-------------	-----------------------------

### Taxonomies, Classifications, and Categories

Category Description	Conduit & Raceways - Pvc Conduit, Fittings, & Boxes PVC Schedule 40 Conduit
----------------------	--------------------------------------------------------------------------------

### Availability

minimum qty	10
-------------	----

### Packaging

Carton	100
Package	6000
Weight Per foot	0.162