




ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

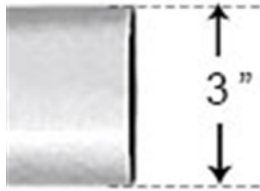

PVC3 SCH 40 3" 10' PVC Conduit

Heritage Plastics

| | |
|------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Catalog Number | PVC3 |
| Manufacturer | Heritage Plastics |
| Description | PVC Conduit, Underground or Aboveground Application, Gray Color, 3.008 In Conduit Inner Diameter, 3.500 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 880 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 3 In Trade Size, 0.216 In Wall Thickness, 1.45 LB Weight |
| Weight per unit | 1.5 (lbs/each) |
| Product Category | PVC Conduit, Fittings, & Boxes |

Dimensions and Weight

| | |
|----------|----|
| Diameter | 3" |
|----------|----|

Descriptions

| | |
|-------------|---------------------------|
| Description | SCH 40 3" 10' PVC CONDUIT |
|-------------|---------------------------|

Taxonomies, Classifications, and Categories

| | |
|----------------------|--------------------------------------------------------------------------------|
| Category Description | Conduit & Raceways - Pvc Conduit, Fittings, & Boxes PVC Schedule 40 Conduit |
|----------------------|--------------------------------------------------------------------------------|

Availability

| | |
|-------------|----|
| minimum qty | 10 |
|-------------|----|

Packaging

| | |
|-----------------|------|
| Carton | 10 |
| Package | 880 |
| Weight Per foot | 1.45 |