



## SINGLE PIECE STRUT CLAMP FOR CONDUIT, STEEL, EG, 3/4" EMT, 3/4" RIGID/PIPE

### CATALOG NUMBER

**SK125I**



### CERTIFICATIONS



### FEATURES

One piece break apart strut clamp for EMT and Rigid conduit

Includes thread impression and captured screw

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

EMT Conduit Size: 3/4"


Rigid Conduit/Pipe Size: 3/4"

Outer Diameter (OD): 0.920" - 1.05"

Width (W): 1 1/4"

Static Load (F): 200lb

DIAGRAMS

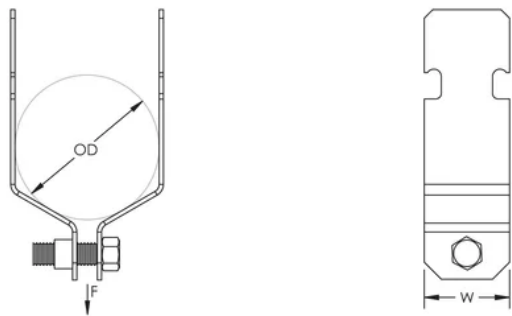

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



## SINGLE PIECE STRUT CLAMP FOR CONDUIT, STEEL, EG, 3/4" EMT, 3/4" RIGID/PIPE

### CATALOG NUMBER

**SK125I**



### CERTIFICATIONS



### FEATURES

One piece break apart strut clamp for EMT and Rigid conduit

Includes thread impression and captured screw

### PRODUCT ATTRIBUTES

Material: Steel

Finish: Electrogalvanized

EMT Conduit Size: 3/4"


Rigid Conduit/Pipe Size: 3/4"

Outer Diameter (OD): 0.920" - 1.05"

Width (W): 1 1/4"

Static Load (F): 200lb

DIAGRAMS

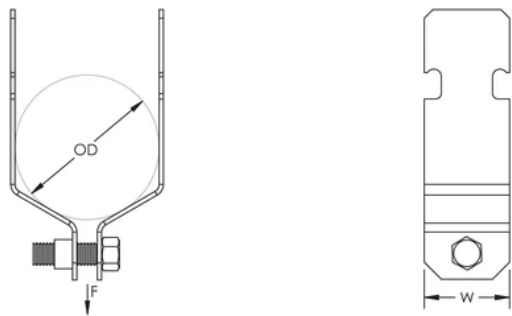

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**  
+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

**Europe**  
Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**  
Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**  
Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**