


## Features

- Ideal for highly corrosive environments
- Non-magnetic
- Protective plastic film helps to prevent scratches and damage
- 2-Single 2.16 in. (54.9) Diameter Openings

## Ordering Information

Description	Catalog Number	UPC
2-Gang, 1 Single Receptacle Opening, 2.16" (54.9) Dia. Hole	<b>SS703</b>	883778201134

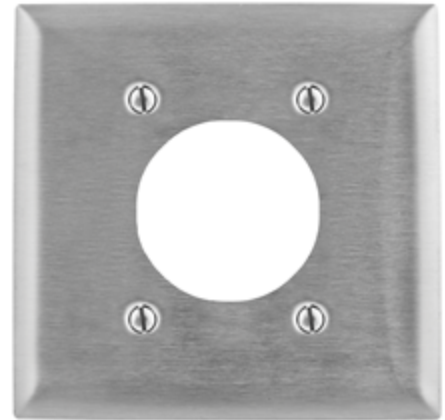

## Listings

UL Listed  
CSA Certified

## Specifications

Plate Material	Stainless steel 302/304
Thickness	.035 in. (0.9) nominal
Hole Diameter	2.16 in. (54.9)
Size	2-Gang
Mounting Screw	302/304 Stainless steel

## Online Resources

[eCatalog](#)

## Features

- Ideal for highly corrosive environments
- Non-magnetic
- Protective plastic film helps to prevent scratches and damage
- 2-Single 2.16 in. (54.9) Diameter Openings

## Ordering Information

Description	Catalog Number	UPC
2-Gang, 1 Single Receptacle Opening, 2.16" (54.9) Dia. Hole	<b>SS703</b>	883778201134



## Listings

UL Listed  
CSA Certified

## Specifications

Plate Material	Stainless steel 302/304
Thickness	.035 in. (0.9) nominal
Hole Diameter	2.16 in. (54.9)
Size	2-Gang
Mounting Screw	302/304 Stainless steel

## Online Resources

[eCatalog](#)