

Sunnata touch dimmer with LED+ technology

Next generation in design and technology

Features

- Intuitive design matches frequently used paddle switches
- Touch anywhere on the lightbar to turn on or dim instantly
- Soft glow helps you find control in the dark
- Simple MyLevel programming to adjust low-end trim, preset levels, or lightbar brightness



Learn more about Sunnata



	STCL-153M-XX	ST-PRO-N-XX
Description	LED+ Dimmer	LED+ PRO Phase Selectable Dimmer
Rating/load type	150W LED 600W Incandescent/Halogen	250W LED 500W ELV/Incandescent/Halogen 400VA MLV
Neutral required	No	Yes
Companion	ST-AS	ST-RD
Number of locations	10 (9 accessory switches + dimmer)	5 (4 companions + dimmer)
Identical companion functionality	No <ul style="list-style-type: none"> • Tap once for preset • Tap again for 100% • Hold 1s for a 30s fade-to-off 	Yes <ul style="list-style-type: none"> • Touch light bar or tap once for preset • Double tap for 100% • Hold 1s for a 30s fade-to-off
Dim from all locations	No (No light bar on accessory switches)	Yes (light bar syncs across Sunnata dimmers in circuit)
Advanced programming	<ul style="list-style-type: none"> • Low-end/high-end trim • Preset light level • Light bar brightness • Light bar status • Reset 	<ul style="list-style-type: none"> • Phase select • Low-end/high-end trim • Preset light level • Light bar brightness • Light bar status • Reset

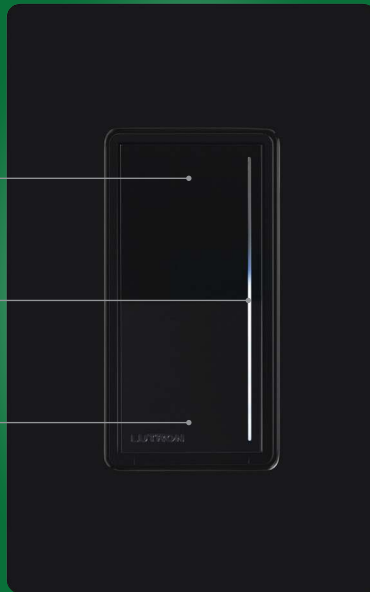
Single-location dimming with accessory switches

Dim from LED+ Dimmer

Tap once to go to preset level; tap again for full brightness

Touch or swipe the light bar to turn on the lights and adjust the brightness

Tap for off; hold for 1s to activate a 30s delayed fade-to-off



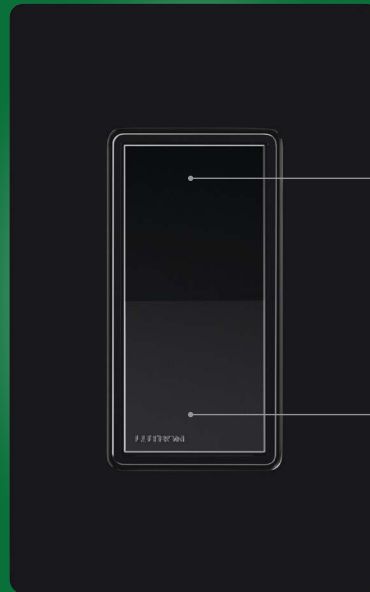
STCL-153M-XX

+

Add accessory switches to switch on/off from up to 10 locations

Tap once to go to preset level; tap again for full brightness

Tap for off; hold for 1s to activate a 30s delayed fade-to-off



ST-AS-XX

Multi-location dimming with companions

Dim from PRO dimmer

Tap once to go to preset level, tap again for full brightness

Touch or swipe the light bar to turn on the lights and adjust the brightness

Tap for off; hold for 1s to activate a 30s delayed fade-to-off



ST-PRO-N-XX

+

Add companions to dim from up to 5 locations

Mimics PRO dimmer functionality

 
 

Light bar syncs across all Sunnata dimmers in circuit






 
 


 
 
 
 
 
 
 






ST-RD-XX

Colors

Gloss Finishes

Swatches	Colors	STCL-153M-XX / ST-AS-XX	ST-PRO-N-XX / ST-RD-XX
	Almond (AL)	-	-
	Black (BL)	•	•
	Brown (BR)	-	-
	Gray (GR)	-	-
	Light Almond (LA)	•	•
	Ivory (IV)	•	•
	White (WH)	•	•

Satin Finishes

Swatches	Colors	STCL-153M-XX / ST-AS-XX	ST-PRO-N-XX / ST-RD-XX
	Biscuit (BI)	-	•
	Brilliant White (BW)	-	•
	Cobblestone (CS)	-	•
	Clay (CY)	-	•
	Deep Sea (DE)	-	•
	Espresso (EP)	-	•
	Glacier White (GL)	-	•
	Lunar Gray (LG)	-	•
	Mist (MI)	-	•
	Midnight (MN)	-	•
	Pebble (PB)	-	•
	Pumice (PM)	-	•
	Architectural White (RW)	-	•
	Sage (SA)	-	•
	Sand (SD)	-	•
	Slate (SL)	-	•
	Snow White (SW)	-	•
	Signal Red (SR)	-	•
	Truffle (TF)	-	•
	Taupe (TP)	-	•