


Eaton TP224

Catalog Number: TP224

Eaton Crouse-Hinds series Switch Box, (1) 1/2", Hold-Tite, Conduit (no clamps), 2-1/2", (1) 1/2", Steel, Ears, Gangable, 12.5 cubic inch capacity

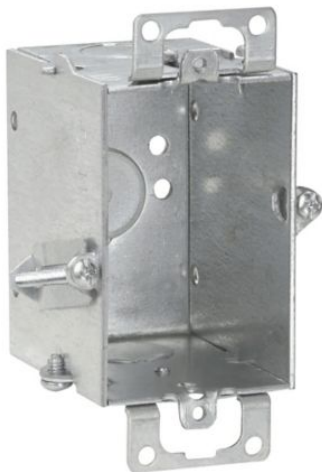

General specifications

| | |
|--------------------------------------|----------------------|
| Product Name | Catalog Number |
| Eaton Crouse-Hinds series switch box | TP224 |
| UPC | Product Length/Depth |
| 786189102246 | 2 in |
| Product Height | Product Width |
| 3 in | 2.5 in |
| Product Weight | |
| 0.61 lb | |

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

Product specifications

Depth

2-1/2"

Type

Gangable

Capacity

12.5 cubic in

Conduit/cable

Conduit (no clamps)

Bracket style

Hold-Tite

End Knockouts

(1) 1/2 in

Bottom Knockouts

(1) 1/2 in

Material

Steel

Special features

Ears

Resources

Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

Certification reports

[Steel Switch Boxes Canadian certification](#)

[Steel Switch Boxes UL certification](#)

Specifications and datasheets

[Eaton Specification Sheet - TP224](#)

[Steel Outlet Boxes for Electrical Systems](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.




[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

Eaton TP224

Catalog Number: TP224

Eaton Crouse-Hinds series Switch Box, (1) 1/2", Hold-Tite, Conduit (no clamps), 2-1/2", (1) 1/2", Steel, Ears, Gangable, 12.5 cubic inch capacity

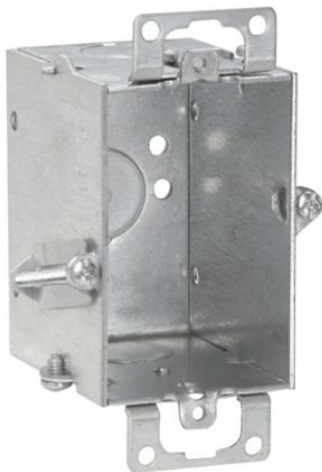

General specifications

| | |
|--------------------------------------|-----------------------------|
| Product Name | Catalog Number |
| Eaton Crouse-Hinds series switch box | TP224 |
| UPC | Product Length/Depth |
| 786189102246 | 2 in |
| Product Height | Product Width |
| 3 in | 2.5 in |
| Product Weight | |
| 0.61 lb | |

Certifications and compliances

Area classification

Ordinary/Non-Hazardous Locations

Standards type

NEC/CEC

Product specifications

Depth

2-1/2"

Type

Gangable

Capacity

12.5 cubic in

Conduit/cable

Conduit (no clamps)

Bracket style

Hold-Tite

End Knockouts

(1) 1/2 in

Bottom Knockouts

(1) 1/2 in

Material

Steel

Special features

Ears

Resources

Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

Certification reports

[Steel Switch Boxes Canadian certification](#)

[Steel Switch Boxes UL certification](#)

Specifications and datasheets

[Eaton Specification Sheet - TP224](#)

[Steel Outlet Boxes for Electrical Systems](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)