


Specifications

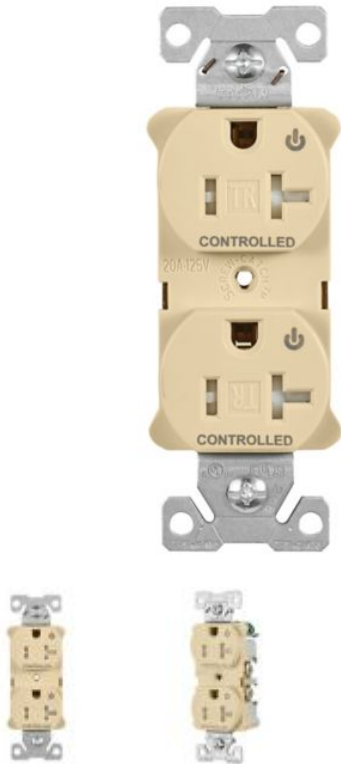

Eaton TR5362CDV

Eaton Arrow Hart heavy duty industrial specification grade duplex receptacle, Tamper resistant, auto-grounding, Dual control, #14-10 AWG, 20A, Flush, 125V, Ivory, Brass, Impact-resistant thermoplastic face, PVC body, 5-20R, 2-pole, 3-wire, ,

General specifications

PRODUCT NAME	Eaton Arrow Hart heavy-duty industrial specification grade duplex receptacle
CATALOG NUMBER	TR5362CDV
UPC	032664744655
PRODUCT LENGTH/DEPTH	1.3 in
PRODUCT HEIGHT	4.19 in
PRODUCT WIDTH	0.84 in
PRODUCT WEIGHT	0.22 lb
CERTIFICATIONS	cULus Listed

Product specifications	
DEVICE TYPE	Receptacle
TYPE	Dual control
AMPERAGE RATING	20A
VOLTAGE RATING	125V
CONTACT MATERIAL	Brass
FEATURES	Tamper resistant Auto-grounding Dual-controlled
APPLICATION	Industrial
DEVICE GRADE	Construction
WIRING METHOD	Back and side
NUMBER OF WIRES	Three-wire
MOUNTING METHOD	Flush
NUMBER OF POLES	Two-pole
STYLE TYPE	Standard
COLOR	Ivory
CONNECTION TYPE	Screw
ALLOWABLE WIRE SIZE	#14-10 AWG
NEMA CONFIGURATION	5-20R
TORQUE RATING	14 lbf-inch
DESIGN TYPE	Straight blade
FACE/BODY MATERIAL	PVC Body Impact-resistant thermoplastic face
RECEPTACLE TYPE	Duplex

Resources	
BROCHURES	Spec grade receptacles brochure
	Controlled receptacles sell sheet
MULTIMEDIA	Residential straight blade receptacles
SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - TR5362CDV

PROJECT NAME:
PROJECT NUMBER:
PREPARED BY:
DATE:



Eaton Corporation plc

Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights
Reserved.


Eaton is a registered trademark.

All other trademarks are property of
their respective owners.

Follow us on social media to get the latest
product and support information.



Specifications

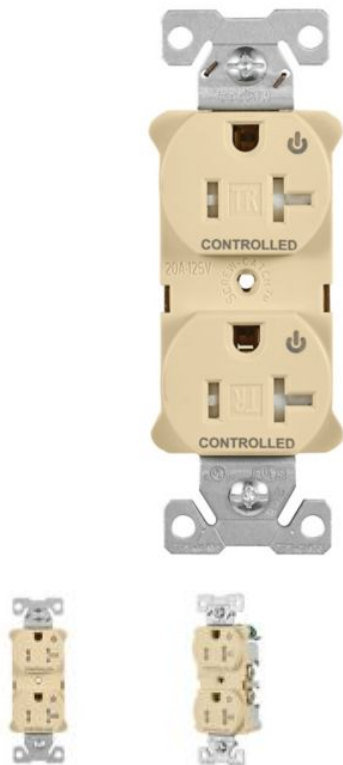

Eaton TR5362CDV

Eaton Arrow Hart heavy duty industrial specification grade duplex receptacle, Tamper resistant, auto-grounding, Dual control, #14-10 AWG, 20A, Flush, 125V, Ivory, Brass, Impact-resistant thermoplastic face, PVC body, 5-20R, 2-pole, 3-wire, ,

General specifications

PRODUCT NAME	Eaton Arrow Hart heavy-duty industrial specification grade duplex receptacle
CATALOG NUMBER	TR5362CDV
UPC	032664744655
PRODUCT LENGTH/DEPTH	1.3 in
PRODUCT HEIGHT	4.19 in
PRODUCT WIDTH	0.84 in
PRODUCT WEIGHT	0.22 lb
CERTIFICATIONS	cULus Listed

Product specifications	
DEVICE TYPE	Receptacle
TYPE	Dual control
AMPERAGE RATING	20A
VOLTAGE RATING	125V
CONTACT MATERIAL	Brass
FEATURES	Tamper resistant Auto-grounding Dual-controlled
APPLICATION	Industrial
DEVICE GRADE	Construction
WIRING METHOD	Back and side
NUMBER OF WIRES	Three-wire
MOUNTING METHOD	Flush
NUMBER OF POLES	Two-pole
STYLE TYPE	Standard
COLOR	Ivory
CONNECTION TYPE	Screw
ALLOWABLE WIRE SIZE	#14-10 AWG
NEMA CONFIGURATION	5-20R
TORQUE RATING	14 lbf-inch
DESIGN TYPE	Straight blade
FACE/BODY MATERIAL	PVC Body Impact-resistant thermoplastic face
RECEPTACLE TYPE	Duplex

Resources	
BROCHURES	Spec grade receptacles brochure
	Controlled receptacles sell sheet
MULTIMEDIA	Residential straight blade receptacles
SPECIFICATIONS AND DATASHEETS	Eaton Specification Sheet - TR5362CDV

PROJECT NAME:
PROJECT NUMBER:
PREPARED BY:
DATE:



Eaton Corporation plc

Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2025 Eaton. All Rights
Reserved.

Eaton is a registered trademark.

All other trademarks are property of
their respective owners.

Follow us on social media to get the latest
product and support information.

