

## FEATURES & SPECIFICATIONS

### INTENDED USE

Ideal for mounting above entryways and loading docks.

### CONSTRUCTION

Rugged, corrosion-resistant die-cast aluminum back housing and hinged door frame. Castings are sealed with a one-piece gasket to inhibit the entrance of external contaminants. Finish is bronze polyester powder paint for lasting durability.

### ELECTRICAL

Ballast is constant wattage autotransformer. Ballast is 100% factory-tested.

Metal halide: super CWA pulse start ballasts, 88% efficient and EISA compliant, are required for 250-400W (must order SCWA option) for US shipments only. CSA required for pulse start shipments to Canada. 250M and 400M do not comply with California Title 20 regulations.

Socket: Mogul-base socket, nickel-plated screw shell and center contact.

### OPTICS

Refractor is prismatic borosilicate glass. Reflector is die-formed anodized stippled aluminum.

Mogul-base lamp included in carton.

### INSTALLATION

Housing is configured for mounting directly over a standard 4" outlet box or for surface wiring via any of three convenient 1/2" threaded conduit entry hubs.

### LISTING

UL Listed to US and Canadian safety standards (see Options). Suitable for wet locations (25°C maximum ambient temperature).

### WARRANTY

2-year limited warranty. Complete warranty terms located at:

[www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

**Note:** Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Catalog Number
Notes
Type

Wall Packs

# TWR2


METAL HALIDE: 250-400W



TWR2 250W



TWR2 400W

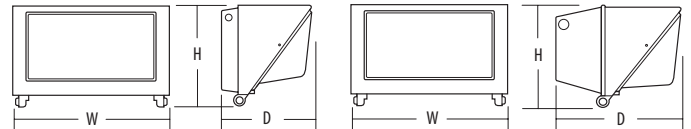

TWR2 250W

TWR2 400W

#### Specifications

Height: 9-1/4 (23.5)  
 Width: 17-7/8 (45.4)  
 Depth: 9-3/8 (23.8)  
 \*Weight: 26 lbs/ 11.8 kg

#### Specifications

Height: 9-1/4 (23.5)  
 Width: 17-7/8 (45.4)  
 Depth: 12-1/2 (31.8)  
 \*Weight: 31 lbs/ 14.07 kg

All dimensions shown in inches (centimeters) unless otherwise noted.

\*Weight as configured in example below.

### ORDERING INFORMATION

**Example:** TWR2 400M TB SCWA LPI


Catalog Number	Wattage	Voltage	Photocell included	Lamp included	Available in Canada
Metal halide					
TWR2 250M 120/347 LPI CSA	250	120/347	N	Y	Y
TWR2 250M TB SCWA LPI	250	120/208/240/277	N	Y	N
TWR2 320M TB SCWA LPI	320	120/208/240/277	N	Y	N
TWR2 400M TB SCWA LPI	400	120/208/240/277	N	Y	N

<b>Accessories:</b> Order as separate catalog number. Shipped separately	
TWR2WG U	Wireguard

# TWR2 Metal Halide Wall Pack

TWR2 250M

Test No. LTL10414

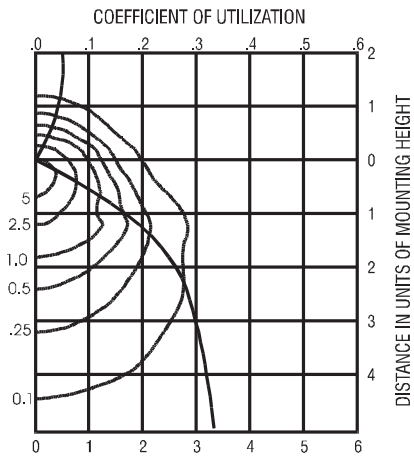

250W Metal Halide lamp, 20000 rated lumens. Footcandle values based on 20' mounting height, Distribution.

## FEATURES & SPECIFICATIONS

### INTENDED USE

Ideal for mounting above entryways and loading docks.

### CONSTRUCTION

Rugged, corrosion-resistant die-cast aluminum back housing and hinged door frame. Castings are sealed with a one-piece gasket to inhibit the entrance of external contaminants. Finish is bronze polyester powder paint for lasting durability.

### ELECTRICAL

Ballast is constant wattage autotransformer. Ballast is 100% factory-tested.

Metal halide: super CWA pulse start ballasts, 88% efficient and EISA compliant, are required for 250-400W (must order SCWA option) for US shipments only. CSA required for pulse start shipments to Canada. 250M and 400M do not comply with California Title 20 regulations.

Socket: Mogul-base socket, nickel-plated screw shell and center contact.

### OPTICS

Refractor is prismatic borosilicate glass. Reflector is die-formed anodized stippled aluminum.

Mogul-base lamp included in carton.

### INSTALLATION

Housing is configured for mounting directly over a standard 4" outlet box or for surface wiring via any of three convenient 1/2" threaded conduit entry hubs.

### LISTING

UL Listed to US and Canadian safety standards (see Options). Suitable for wet locations (25°C maximum ambient temperature).

### WARRANTY

2-year limited warranty. Complete warranty terms located at:

[www.acuitybrands.com/CustomerResources/Terms\\_and\\_conditions.aspx](http://www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx)

**Note:** Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

Catalog Number
Notes
Type

### Wall Packs

# TWR2


METAL HALIDE: 250-400W



TWR2 250W



TWR2 400W

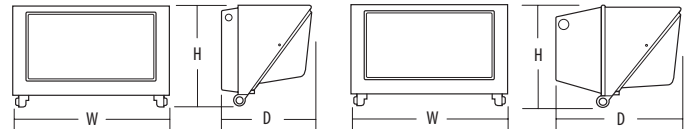

TWR2 250W

TWR2 400W

#### Specifications

Height: 9-1/4 (23.5)  
 Width: 17-7/8 (45.4)  
 Depth: 9-3/8 (23.8)  
 \*Weight: 26 lbs/ 11.8 kg

#### Specifications

Height: 9-1/4 (23.5)  
 Width: 17-7/8 (45.4)  
 Depth: 12-1/2 (31.8)  
 \*Weight: 31 lbs/ 14.07 kg

All dimensions shown in inches (centimeters) unless otherwise noted.

\*Weight as configured in example below.

### ORDERING INFORMATION

**Example:** TWR2 400M TB SCWA LPI

Catalog Number	Wattage	Voltage	Photocell included	Lamp included	Available in Canada
Metal halide					
TWR2 250M 120/347 LPI CSA	250	120/347	N	Y	Y
TWR2 250M TB SCWA LPI	250	120/208/240/277	N	Y	N
TWR2 320M TB SCWA LPI	320	120/208/240/277	N	Y	N
TWR2 400M TB SCWA LPI	400	120/208/240/277	N	Y	N


**Accessories:** Order as separate catalog number.  
 Shipped separately

TWR2WG U Wireguard

# TWR2 Metal Halide Wall Pack

TWR2 250M

Test No. LTL10414

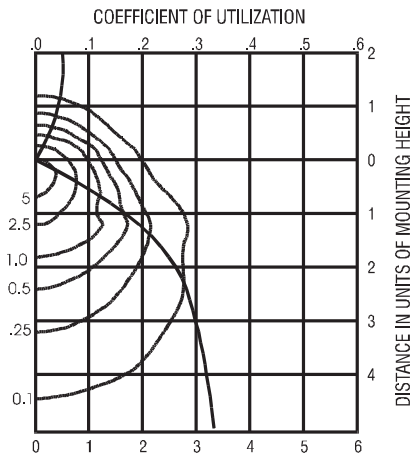

250W Metal Halide lamp, 20000 rated lumens. Footcandle values based on 20' mounting height, Distribution.