




Beam Clamps

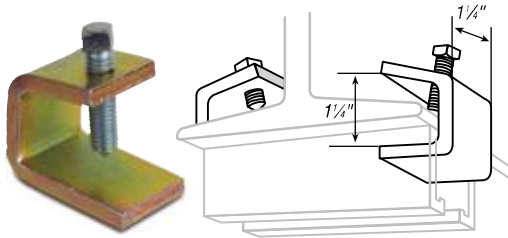


U514
 $\frac{3}{8}$ " x $1\frac{1}{2}$ " set screw included.
 Design load 750 lbs./per pair.

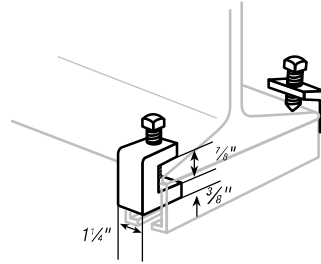



U514A
 $\frac{3}{8}$ " x $1\frac{1}{2}$ " set screw included.
 Design load 1,650 lbs./per pair.

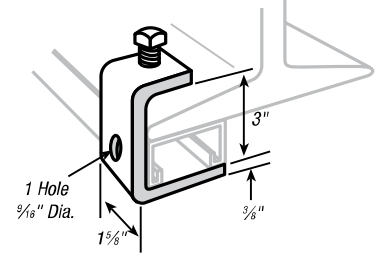

U515
 For all "A" series channel.
 $\frac{1}{2}$ " x $1\frac{1}{2}$ " set screw included.
 Design load 800 lbs.

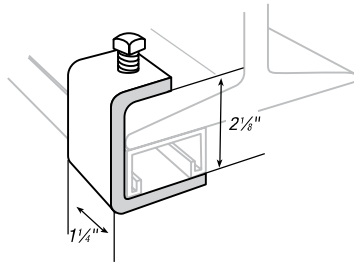

U515B
 For all "B" series channel.
 $\frac{1}{2}$ " x $1\frac{1}{2}$ " set screw included.
 Design load 800 lbs.

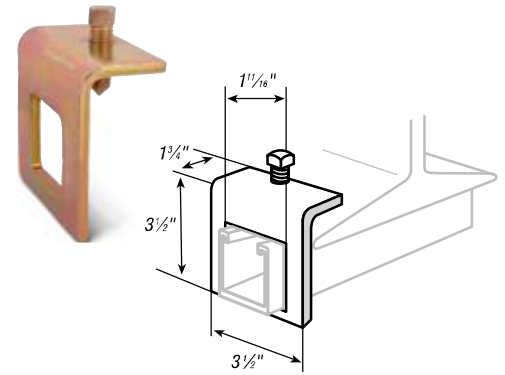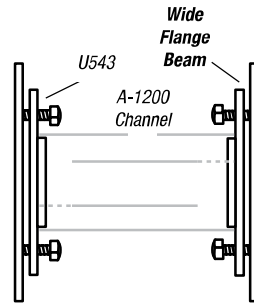


A-597
 Standard Finish — GoldGalv® brand.
 Channel Series A
 Design load 800 lbs./ea.

CAT. NO.	FLANGE WIDTH* (IN.)	A (IN.)	DESIGN LOAD LBS.	STD. CTN.
U-520	2 $\frac{3}{8}$ –4 $\frac{1}{2}$	8 $\frac{3}{4}$	2,000	10
U-521	3 $\frac{3}{4}$ –5 $\frac{3}{4}$	10	1,300	10
U-522	5 $\frac{5}{8}$ –7 $\frac{5}{8}$	11 $\frac{1}{8}$	900	10

*When ordering specify flange width.

Standard Finish — GoldGalv®, unless otherwise stated.

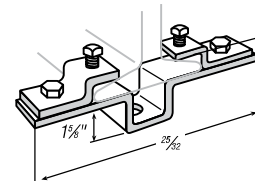

U520, U-521 & U-522
 Standard Finish — GoldGalv® brand.
 Nuts, cap screws and set screws included.