

0-10V Slide Dimmer Wallstation

Catalog#	Prepared by
Project	Date
Comments	Type

Overview

The 0-10 Volt Slide Dimmer provides full-range classic linear-slide dimming for 0-10V compatible dimmable light sources. These units are ideal for light commercial applications and are compatible with decorator style devices and wallplates. The preset "ON/OFF" switch automatically returns controlled light(s) to a preset level without disturbing the brightness level. The device is designed for both Single-pole (one location) and 3-way (multi-location) applications.

Features

- Preset feature allows user to return to previous light level when turning lights ON
- Integrated full-slide control for easy, precise operation
- Can be wired as Single-pole or 3-way
- Neutral is not required for installation of device
- Adjustable high-level trim setting for optimal lamp compatibility



August 2016

Specifications

Switch Type	Single-pole and 3-way
Dimming Control	0-10 VDC: 200mA Sink Sink Dimming
Electrical Ratings	120 VAC: Max. Load: 10 amps, 1200W, 60 Hz 277 VAC: Max Load: 6 amps, 1660W, 60 Hz
Light Intensity Control	Full-range, continuously variable dimming Adjustable High-level trim setting
Power Failure Memory	Light returns to same level prior to power interruption
Wiring Type	Back & side wiring terminals; 12-14 AWG (Copper wire) 0-10V wire leads; 16 AWG
Flammability	Meets UL 94 requirements, V2 rated
Temperature	-4°F to 158°F (-20°C to 70°C)

Wiring Diagrams

FIGURE 1: SINGLE-POLE WIRING DIAGRAM


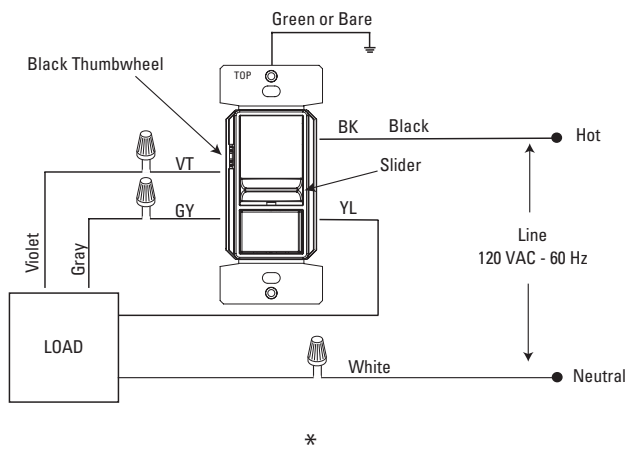


FIGURE 2: 3-WAY WIRING DIAGRAM

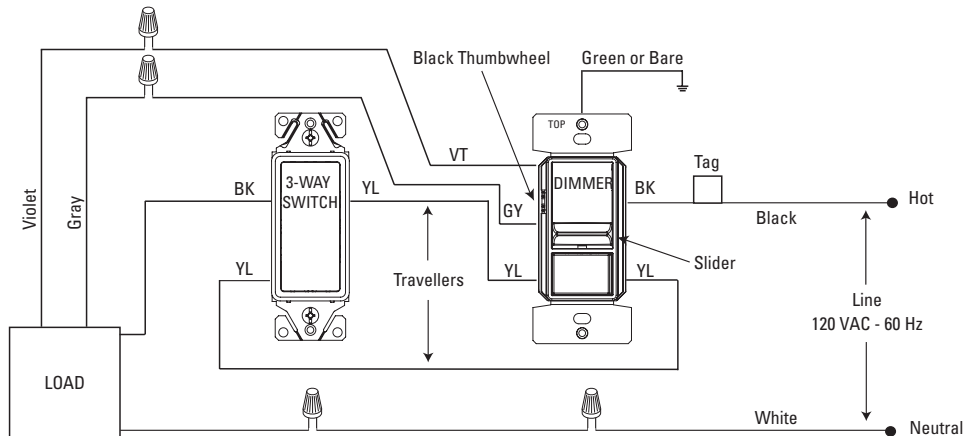

*Can be installed on load or line side in 3-way applications

Visit our website for additional wiring details at www.cooperlighting.com

August 2016

Ordering

*Wallplate not included

This is an accessory for the Greengate Lighting Control System. When ordering, specify the 0-10V slide dimming wallstation as a separate system accessory.

Catalog #	Description	Colors
WBSD-010SLD-LA	Dimmer Slider 0-10V, 120/277 VAC	Light Almond
WBSD-010SLD-BK	Dimmer Slider 0-10V, 120/277 VAC	Black
WBSD-010SLD-GY	Dimmer Slider 0-10V, 120/277 VAC	Gray
WBSD-010SLD-V	Dimmer Slider 0-10V, 120/277 VAC	Ivory
WBSD-010SLD-W	Dimmer Slider 0-10V, 120/277 VAC	White

* Refer to Screwless Wallplate Spec Sheet for ordering information at www.cooperlighting.com.

Note: Custom engraving is not available on 0-10V dimming wallstations.

Cooper Lighting Solutions
 1121 Highway 74 South
 Peachtree City, GA 30269
 P: 770-486-4800
www.cooperlighting.com

© 2020 Cooper Lighting Solutions
 All Rights Reserved
 Printed in USA
 Publication No. TD503061EN
 August 18, 2016

Cooper Lighting Solutions is a registered trademark.

All other trademarks are property of their respective owners.