

Wall Light

43 Watt LED

Classic Series LED
TRADITIONAL HID REPLACEMENT

Glare Free



Design is Protected by U.S. Patent No. 9,482,395



WLM43LED

WATTS: 43

CCT: 4500K

CCT: 3000K

LUMENS: 4,350

LUMENS: 3,908

LPW: 107 CRI: 82

LPW: 96 CRI: 81

DIMMING: 10-100%

DIMMING: 10-100%

Ordering Information

CATALOG #	DESCRIPTION	VOLTS	COLOR TEMP
WLM43LED	43W LED Wall Light	120-277	4500K
WLM43LED3K	43W LED Wall Light	120-277	3000K

Options

ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol
EB	Emergency Back-Up
4	480V Driver

Note: Atlas uses only premium LED compatible photocontrols

Performance

- 95% Efficient Reflector Targets the Light
- Eliminates Glare & Offensive Light
- Less Wasted Light
- More Footcandles on the Ground
- Creates a Smooth & Uniform Light Pattern


Dimensions and Specifications

Overall Height: 9.02"


Depth: 7.85"

Overall Width: 14.2"

Weight: 9.2 lbs.

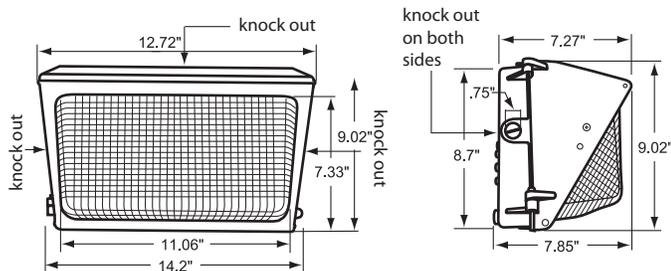

Recommended Mounting Height - 12-14 ft.

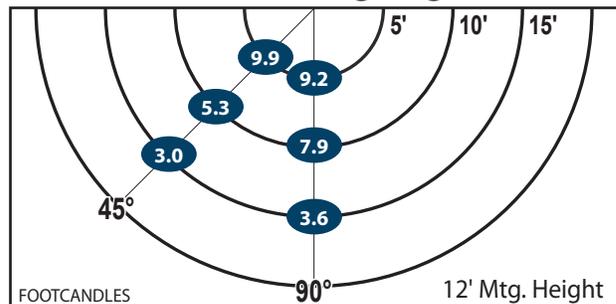

Mtg. Hgt.	FOOTCANDLES ON THE GROUND						Avg. FCs 450 SQ. FT.
	90°			45°			
	5'	10'	15'	5'	10'	15'	
12'	9.2	7.9	3.6	9.9	5.3	3.0	6.5
14'	8.0	4.4	3.0	7.6	6.1	3.7	5.5

200,000+ HOURS



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

