

Glare Free



WATTS: 64

WLM64LED

CCT: 4500K

CCT: 3000K

LUMENS: 6,349

LUMENS: 5,699

LpW: 101 CRI: 83

LpW: 92 CRI: 81

DIMMING: 10-100%

DIMMING: 10-100%

Design is Protected by U.S. Patent No. 9,482,395



Ordering Information


| CATALOG # | DESCRIPTION | VOLTS | COLOR TEMP |
|-------------------|--------------------|---------|------------|
| WLM64LED | 64W LED Wall Light | 120-277 | 4500K |
| WLM64LED3K | 64W LED Wall Light | 120-277 | 3000K |

Options

| ADD SUFFIX # | DESCRIPTION |
|--------------|-----------------------|
| PC | 120V Photocontrol |
| PM | 208-277V Photocontrol |
| EB | Emergency Back-Up |
| 4 | 480V Driver |

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 16-18 ft.

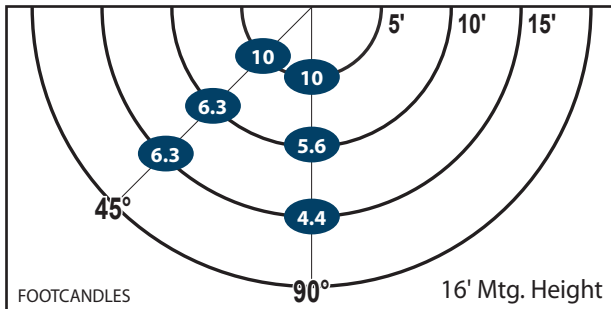

| Mtg. Hgt. | FOOTCANDLES ON THE GROUND | | | | | | Avg. FCs 450 SQ. FT. |
|-----------|---------------------------|-----|-----|------|-----|-----|-------------------------|
| | 90° | | | 45° | | | |
| | 5' | 10' | 15' | 5' | 10' | 15' | |
| 16' | 10.0 | 6.3 | 6.3 | 10.0 | 5.6 | 4.4 | 7.1 |
| 18' | 8.5 | 5.3 | 5.0 | 8.3 | 5.0 | 3.8 | 6.0 |

Performance

- **95% Efficient Reflector Targets the Light**
- **Eliminates Glare & Offensive Light**
- **Less Wasted Light**
- **More Footcandles on the Ground**
- **Creates a Smooth & Uniform Light Pattern**

 

Dimensions and Specifications

Overall Height: 9.02"

Depth: 7.85"

Overall Width: 14.2"

Weight: 9.2 lbs.

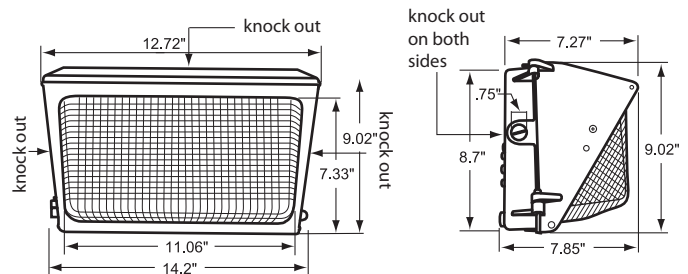

*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components



Glare Free



WATTS: 64

WLM64LED

CCT: 4500K

CCT: 3000K

LUMENS: 6,349

LUMENS: 5,699

LPW: 101 CRI: 83

LPW: 92 CRI: 81

DIMMING: 10-100%

DIMMING: 10-100%

Design is Protected by U.S. Patent No. 9,482,395



Ordering Information


| CATALOG # | DESCRIPTION | VOLTS | COLOR TEMP |
|-------------------|--------------------|---------|------------|
| WLM64LED | 64W LED Wall Light | 120-277 | 4500K |
| WLM64LED3K | 64W LED Wall Light | 120-277 | 3000K |

Options

| ADD SUFFIX # | DESCRIPTION |
|--------------|-----------------------|
| PC | 120V Photocontrol |
| PM | 208-277V Photocontrol |
| EB | Emergency Back-Up |
| 4 | 480V Driver |

Note: Atlas uses only premium LED compatible photocontrols

Recommended Mounting Height - 16-18 ft.

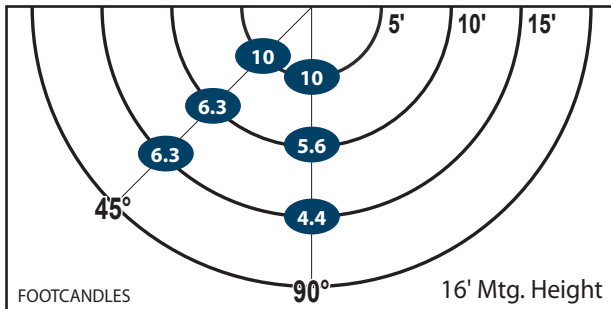

| Mtg. Hgt. | FOOTCANDLES ON THE GROUND | | | | | | Avg. FCs 450 SQ. FT. |
|-----------|---------------------------|-----|-----|------|-----|-----|-------------------------|
| | 90° | | | 45° | | | |
| | 5' | 10' | 15' | 5' | 10' | 15' | |
| 16' | 10.0 | 6.3 | 6.3 | 10.0 | 5.6 | 4.4 | 7.1 |
| 18' | 8.5 | 5.3 | 5.0 | 8.3 | 5.0 | 3.8 | 6.0 |

Performance

- **95% Efficient Reflector Targets the Light**
- **Eliminates Glare & Offensive Light**
- **Less Wasted Light**
- **More Footcandles on the Ground**
- **Creates a Smooth & Uniform Light Pattern**

 

Dimensions and Specifications

Overall Height: 9.02"

Depth: 7.85"

Overall Width: 14.2"

Weight: 9.2 lbs.

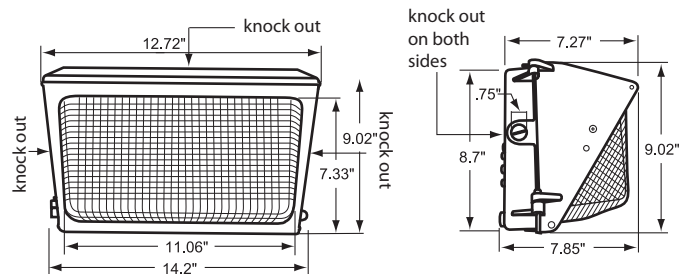

*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

