 


Roof Caps

 
Model 634 Roof Cap*

- For 3-1/4" x 10" or up to 8" round duct
- Built-in backdraft damper and bird screen
- Steel baked black enamel finish



Model 636 Roof Cap*

- For 3" or 4" round duct
- Built-in backdraft damper and bird screen
- Steel baked black enamel finish




Model 636AL Roof Cap*

- Same as Model 636, except aluminum natural finish

Wall Caps

Model 639 Wall Cap*

 - Spring-loaded backdraft damper
- For 3-1/4" x 10" duct
- Built-in bird screen
- Steel baked black enamel finish




Model 649 Wall Cap*

- Same as Model 639, except aluminum natural finish



Model 641 Wall Cap*

 - For 6" round duct
- Aluminum natural finish
- Built-in backdraft damper & bird screen



Model 843BL Wall Cap*

- For 6" round duct
- Built-in backdraft damper and bird screen
- Steel baked black enamel finish




Model 643 Wall Cap*

- For 8" round duct
- Aluminum natural finish



Model 885BL Wall Cap*

- For 3" or 4" round duct
- 3" to 4" round transition included
- Steel baked black enamel finish
- Spring operated built-in backdraft damper and bird screen

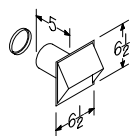

Model 885AL Wall Cap*

- Aluminum finish
- All other features same as 885BL

Model WC650 Wall Cap

 
- 4" round duct
- Includes rigid through-wall duct collar
- White plastic finish



Transitions

Model 886 Transition

- Converts 7" round to 3-1/4" x 10" duct



Model 475 Transition

- Converts 6" round duct to 4" round duct reducer
- Available in 6 Pack (475B)

Model 413 Transition


- Converts 3-1/4" x 10" duct to 8" round duct



Ducting, Elbows, Dampers

Model 839 Elbow

- 90° turn
- For use with 3-1/4" x 10" duct

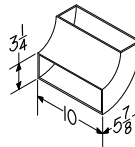

Model 97 Damper

- 7" spring-loaded, In-Line damper.



Model BP87 Damper

- 7" vertical discharge damper.



Model 407 Round Duct

- 7" round duct
- 2' galvanized section

Model 410 Round Duct

- 10" round duct
- 2' galvanized section


Model 889

- 3-1/4" x 10" duct

Adapter Kits

Model RVK1A

- Complete kit designed to vent kitchen or bath exhaust fan through a slanted roof
- Works with 3" and 4" ducts
- 8' in length

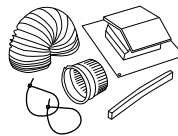

Model WVK2A*

Flexible Wall Ducting Kit

- Includes white polymeric wall cap
- 4" diameter metal duct connector
- 2 duct clamps
- 4" to 3" reducer
- 5' of 4" flexible aluminum ducting



Adapters

Model FY6

- 6" x 6" x 6" Y adapter

Model FY86

- 8" x 6" x 6" Y adapter



Sleeves

Model CVLD4

- 4" sleeve with damper

Model CVLD5

- 5" sleeve with damper

Model CVLD6

- 6" sleeve with damper



 
Grilles

Model S97011308

- Metal Grille kit—10-1/4" x 10-1/4"
- Steel baked white enamel finish
- Fits fan models 695, 696N, 690RMTLA and 696MTL


Model CVG4

- 4" round grille
- Backdraft damper sold separately



Model CVG6

 
- 6" round grille
- Backdraft damper sold separately



Replacement Filters


Model 834 Filter

 - For 8" fans



Model 854 Filter

 - Aluminum-mesh grease filter
- For 10" fans



Insulated Flexible Duct

Models 804DU, DT6W

- 4" (804DU) or 6" (DT6W) round
- 25' standard length



*Not for use with dryers.