

**BURNDY Catalog Number** YA312LH93TN  
**UPC Number** 7818100857388  
**Description** CUHYSEALUG 350KCMIL TIN PLATED  
**Status** Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Tongue Angle Straight  
 B Length (Fraction) 1-1/8  
 Length (in) 6.00  
 Barrell Style Shrouded  
 Bolt Hole Size (in) 0.52  
 Barrel Type Standard  
 Thickness 0.18  
 E - in 1.75

**General**

Number of Holes 2  
 Product Description Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

**Conductor(s)**

Copper Solid Size (Range) N/A  
 Copper Stranded (Range) 250 kcmil

**Physical**

Type of Plating Tin - Electro Plated  
 Bolt Hole Size 1/2  
 Plated (Yes or No) Y  
 Product Material Copper

**Approvals / Certifications**

UL Listed N  
 CSA Certified N  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N


**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**  
 47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**  
 47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

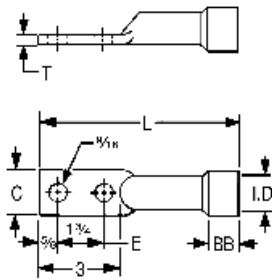

**BURNDY Catalog Number** YA312LH93TN  
**UPC Number** 7818100857388  
**Description** CUHYSEALUG 350KCMIL TIN PLATED  
**Status** Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Tongue Angle Straight  
 B Length (Fraction) 1-1/8  
 Length (in) 6.00  
 Barrell Style Shrouded  
 Bolt Hole Size (in) 0.52  
 Barrel Type Standard  
 Thickness 0.18  
 E - in 1.75

**General**

Number of Holes 2  
 Product Description Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

**Conductor(s)**

Copper Solid Size (Range) N/A  
 Copper Stranded (Range) 250 kcmil

**Physical**

Type of Plating Tin - Electro Plated  
 Bolt Hole Size 1/2  
 Plated (Yes or No) Y  
 Product Material Copper

**Approvals / Certifications**

UL Listed N  
 CSA Certified N  
 ROHS Compatible Compliant  
 UL Recognized N  
 CULUS N

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**  
 47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**  
 47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175