




BURNDY Catalog Number
UPC Number
Description
Status

YAV26LTC14FX
 7818100226588
 CUCOMP TERM 2/0 FLEX 1/4
 Active

Web Use
 BURNDY Product Line

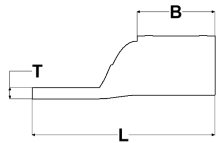

Tongue Angle
 Length (in)
 Tongue Type
 Barrell Style
 Bolt Hole Size (in)
 Barrel Type
 Thickness
 B Length (in)
 Pad Width (in)
 Strip Length

Dimensional

Straight
 1.92
 Standard
 Chamfered
 0.27
 Standard
 0.13
 0.81
 0.93
 13/16

Number of Holes
 Product Description

General

1
 Copper Compression Lug, 1 Hole
 w/ Inspection Window, 2/0 Flex,
 1/4" Stud, Short Barrel, Tin Plated

Flex (Class G) Size - Range
 Flex (Class H) Size - Range
 Flex (Class I) Size - Range
 Copper Solid Size (Range)
 DLO Size (Range)
 Copper Stranded (Range)

Conductor(s)

2/0 AWG
 2/0 AWG
 2/0 AWG
 N/A
 2/0 (375/#24) DLO
 2/0 AWG

Type of Plating
 Bolt Hole Size
 Color Code
 Plated (Yes or No)
 Index Number
 Product Material

Physical

Tin
 1/4
 Black
 Y
 13
 Copper

UL Listed
 CSA Certified
 ROHS Compatible
 UL Recognized
 CULUS

Approvals / Certifications

Y
 Y
 Compliant
 N
 N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175